

General ordering data

Order No.	9508570000
Part designation	NexT 50/35/16 2gp ss
Version	Ex enclosure, 160 mm, 500 mm, 350 mm, Stainless steel 1.4404
EAN	4008190480509
Qty.	1 pc(s).

Dimensions

Fixing dimension, height	350 mm
Fixing dimension, width	406 mm
Height	160 mm
Length	500 mm
Width	350 mm

General details

Cover fixing	Removable cover + M6 screws
Enclosure fixing	Outside mounting with 10 mm holes
Integral fixing	4 x 10 mm spacers
Sealing material	Chloroprene (cover & flange)
Version cover	closed
Colour	Miscellaneous
Surface finish	polished, chemically immersed
Class of protection to EN 60529	IP 66
Weight	10,500 g
Ambient temperature, min.	-40 °C
Ambient temperature, max.	85 °C

Screwed cable glands top/bottom

M 12	54
M 16	36
M 20	20
M 25	16
M 32	6
M 40	5

Screwed cable glands top/bottom

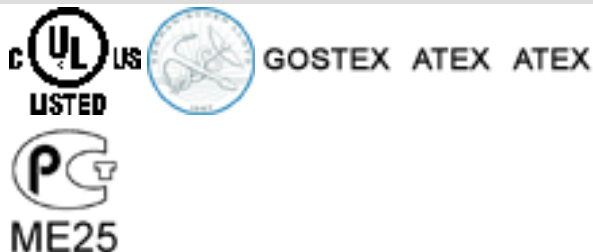
M 50	4
Side of enclosure	Top / Bottom

Screwed cable glands, left/right

M12	54
M16	36
M20	20
M25	16
M32	6
M40	5
M50	4
On housing side	left / right

Approvals

Approvals institutes

**Classifications**

ETIM 2.0	EC000049
ETIM 3.0	EC000049
eClass 4.1	27-14-12-06
eClass 5.0	27-18-05-02
eClass 5.1	27-18-05-02

Similar products

Order No.	Part designation	Version
9523610000	NexT 50/35/16 0gp 7032	Ex enclosure, 160 mm, 500 mm, 350 mm, Sheet steel 1.5 mm (16 SWG)
9523470000	NexT 50/35/16 0gp ss	Ex enclosure, 160 mm, 500 mm, 350 mm, Stainless steel 1.4404
9522910000	NexT 50/35/16 1gp 7032	Ex enclosure, 160 mm, 500 mm, 350 mm, Sheet steel 1.5 mm (16 SWG)
9522630000	NexT 50/35/16 1gp ss	Ex enclosure, 160 mm, 500 mm, 350 mm, Stainless steel 1.4404
9507760000	NexT 50/35/16 2gp 7032	Ex enclosure, 160 mm, 500 mm, 350 mm, Sheet steel 1.5 mm (16 SWG)
9522770000	NexT 50/35/16 3gp ss	Ex enclosure, 160 mm, 500 mm, 350 mm, Stainless steel 1.4404
9507830000	NexT 50/35/16 4gp 7032	Ex enclosure, 160 mm, 500 mm, 350 mm, Sheet steel 1.5 mm (16 SWG)
9508640000	NexT 50/35/16 4gp ss	Ex enclosure, 160 mm, 500 mm, 350 mm, Stainless steel 1.4404