

General ordering data

Order No.	9508740000
Part designation	NexT 86/64/20 2gp ss
Version	Ex enclosure, 205 mm, 860 mm, 640 mm, Stainless steel 1.4404
EAN	4008190857134
Qty.	1 pc(s).

Dimensions

Fixing dimension, height	570 mm
Fixing dimension, width	696 mm
Height	205 mm
Length	860 mm
Width	640 mm

General details

Cover fixing	Removable cover + M6 screws
Enclosure fixing	Outside mounting with 10 mm holes
Integral fixing	4 x 10 mm spacers
Sealing material	Chloroprene (cover & flange)
Version cover	closed
Colour	Miscellaneous
Surface finish	polished, chemically immersed
Class of protection to EN 60529	IP 66
Weight	29,000 g
Ambient temperature, min.	-40 °C
Ambient temperature, max.	85 °C

Screwed cable glands top/bottom

M 12	165
M 16	120
M 20	76
M 25	48
M 32	24
M 40	20

Screwed cable glands top/bottom


M 50	8
M 63	6
M 75	5
Side of enclosure	Top / Bottom

Screwed cable glands, left/right

M12	162
M16	120
M20	76
M25	48
M32	24
M40	20
M50	8
M63	6
M75	4
On housing side	left / right

Approvals

Approvals institutes

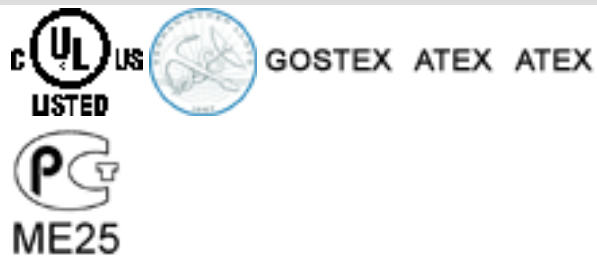

Classifications

ETIM 2.0	EC000049
ETIM 3.0	EC000049
eClass 4.1	27-14-12-06
eClass 5.0	27-18-05-02
eClass 5.1	27-18-05-02

Similar products

Order No.	Part designation	Version
9523710000	NexT 86/64/20 0gp 7032	Ex enclosure, 205 mm, 860 mm, 640 mm, Sheet steel 2.02 mm (14 SWG)
9523570000	NexT 86/64/20 0gp ss	Ex enclosure, 205 mm, 860 mm, 640 mm, Stainless steel 1.4404
9523010000	NexT 86/64/20 1gp 7032	Ex enclosure, 205 mm, 860 mm, 640 mm, Sheet steel 2.02 mm (14 SWG)
9522730000	NexT 86/64/20 1gp ss	Ex enclosure, 205 mm, 860 mm, 640 mm, Stainless steel 1.4404
9507930000	NexT 86/64/20 2gp 7032	Ex enclosure, 205 mm, 860 mm, 640 mm, Sheet steel 2.02 mm (14 SWG)
9522870000	NexT 86/64/20 5gp ss	Ex enclosure, 205 mm, 860 mm, 640 mm, Stainless steel 1.4404
9508000000	NexT 86/64/20 6gp 7032	Ex enclosure, 205 mm, 860 mm, 640 mm, Sheet steel 2.02 mm (14 SWG)