
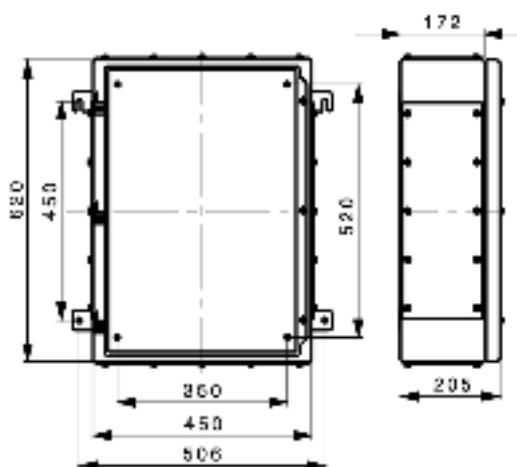


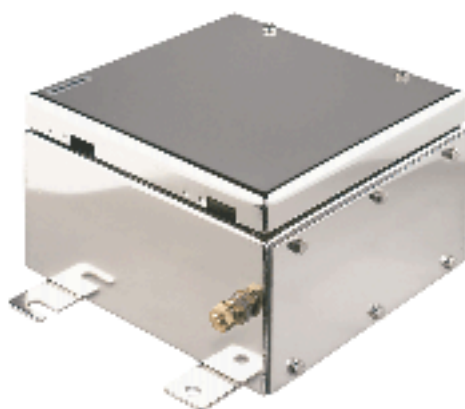

General ordering data

Order No.	9508790000
Part designation	NexT 62/45/20 4gp ss
Version	Ex enclosure, 205 mm, 620 mm, 450 mm, Stainless steel 1.4404
EAN	4008190857103
Qty.	1 pc(s).

Dimensions

Fixing dimension, height	450 mm
Fixing dimension, width	506 mm
Height	205 mm
Length	620 mm
Width	450 mm

General details

Cover fixing	Removable cover + M6 screws
Enclosure fixing	Outside mounting with 10 mm holes
Integral fixing	4 x 10 mm spacers
Sealing material	Chloroprene (cover & flange)
Version cover	closed
Colour	Miscellaneous
Surface finish	polished, chemically immersed
Class of protection to EN 60529	IP 66
Weight	17,600 g
Ambient temperature, min.	-40 °C
Ambient temperature, max.	85 °C

Screwed cable glands top/bottom

M 12	111
M 16	80
M 20	52
M 25	30
M 32	16
M 40	12

Screwed cable glands top/bottom


M 50	5
M 63	4
M 75	3
Side of enclosure	Top / Bottom

Screwed cable glands, left/right

M12	111
M16	80
M20	52
M25	30
M32	16
M40	12
M50	5
M63	4
M75	3
On housing side	left / right

Approvals

Approvals institutes

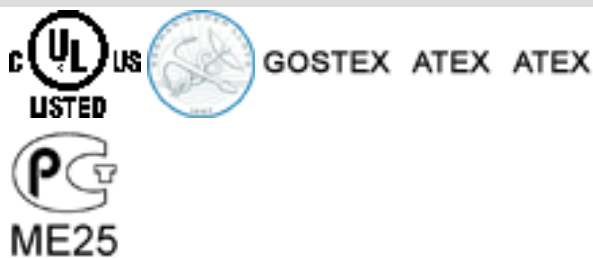**Classifications**

ETIM 2.0	EC000049
ETIM 3.0	EC000049
eClass 4.1	27-14-12-06
eClass 5.0	27-18-05-02
eClass 5.1	27-18-05-02

Similar products

Order No.	Part designation	Version
9522990000	NexT 62/45/20 1gp 7032	Ex enclosure, 205 mm, 620 mm, 450 mm, Sheet steel 2.02 mm (14 SWG)
9522710000	NexT 62/45/20 1gp ss	Ex enclosure, 205 mm, 620 mm, 450 mm, Stainless steel 1.4404
9507910000	NexT 62/45/20 2gp 7032	Ex enclosure, 205 mm, 620 mm, 450 mm, Sheet steel 2.02 mm (14 SWG)
9508720000	NexT 62/45/20 2gp ss	Ex enclosure, 205 mm, 620 mm, 450 mm, Stainless steel 1.4404
9523130000	NexT 62/45/20 3gp 7032	Ex enclosure, 205 mm, 620 mm, 450 mm, Sheet steel 2.02 mm (14 SWG)
9522850000	NexT 62/45/20 3gp ss	Ex enclosure, 205 mm, 620 mm, 450 mm, Stainless steel 1.4404
9507980000	NexT 62/45/20 4gp 7032	Ex enclosure, 205 mm, 620 mm, 450 mm, Sheet steel 2.02 mm (14 SWG)