


Quick access

- Device connectivity - OMNIMATE
- PCB connectors - OMNIMATE Signal
- Pitch 5.00 mm (0.197 inch) - Series B
- Female plugs - clamping yoke screw
- BLZP 5.00HC/90/270
- BLZP 5.00HC/270 SN


Online Catalogue > Device connectivity - OMNIMATE > PCB connectors - OMNIMATE Signal > Pitch 5.00 mm (0.197 inch) - Series BL/SL 5.00 > Female plugs - clamping yoke screw connection > BLZP 5.00HC/90/270 > BLZP 5.00HC/270 SN

BLZP 5.00HC/11/270 SN BK BX

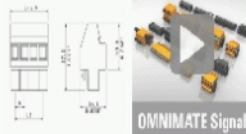

OMNIMATE® sample service

[More information](#)

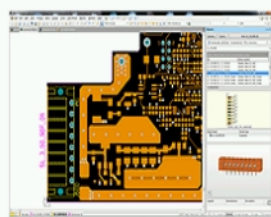

OMNIMATE component libraries

Complete component libraries for your PCB design software

[More information](#)



| General ordering data | |
|------------------------------------|--|
| Available until | 2016-04-08 |
| Type | BLZP 5.00HC/11/270 SN BK BX |
| Order No. | 1959010000 |
| Version | PCB plug-in connector, female plug, 5.00 mm, No. of poles: 11, 90°, Clamping yoke connection, Clamping range, rated connection, max.: 4 mm², Box |
| GTIN (EAN) | 4032248637942 |
| Qty. | 30 pc(s). |
| Product data | IEC: 400 V / 23 A / 0.2 - 4 mm² UL: 300 V / 20 A / AWG 30 - AWG 12 |
| Packaging | Box |
| Dimensions and weights | |
| System parameters | |
| Material data | |
| Conductors suitable for connection | |
| Rated data acc. to IEC | |
| Rated data acc. to CSA | |
| Rated data acc. to UL 1059 | |
| Downloads | |
| Classifications | |
| Notes | |
| Approvals | |
| Accessories | |
| Related products | |

- [Add to inquiry list](#)
- [PDF data sheet](#)
- [Product configurator](#)
- [CAD model](#)
- [Counterpart](#)
- [Accessories](#)
- [Related products](#)
- [Print view](#)
- [Help](#)

Follow us on:

[Print page](#) [Error message](#)