


RIM 5 6/230VAC**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

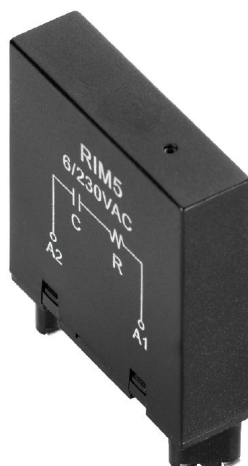Product image

Pluggable protective modules for the D-SERIES relay sockets, with optional protective functions.

- With free-wheeling diode or RC filter

General ordering data

Version	D-SERIES, RC filter, Rated control voltage: 6...230 V AC, Plug-in connection
Order No.	1174670000
Type	RIM 5 6/230VAC
GTIN (EAN)	4032248971312
Qty.	10 items

RIM 5 6/230VAC

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

Approvals



ROHS Conform

UL File Number Search [UL Website](#)

Certificate No. (cURus) E312083

Dimensions and weights

Depth	44 mm	Depth (inches)	1.7323 inch
Height	10 mm	Height (inches)	0.3937 inch
Width	35 mm	Width (inches)	1.378 inch
Net weight	5.7 g		

Temperatures

Storage temperature Operating temperature

Environmental Product Compliance

RoHS Compliance Status Compliant without exemption
 REACH SVHC No SVHC above 0.1 wt%

Rated data UL

Certificate No. (cURus) E312083

Control side

Rated control voltage 6...230 V AC Status indicator No
 Protective circuit RC element RC filter 4.7 kΩ / 10 nF

General data

Colour black
 UL94 flammability rating component Component Housing
 UL94 flammability rating V-2

Further details of approvals / standards

Certificate No. (CSA) 80107692 Certificate No. (cURus) E312083

Connection data

Wire connection method Plug-in connection

Classifications


ETIM 6.0	EC002586	ETIM 7.0	EC002586
ETIM 8.0	EC002586	ETIM 9.0	EC002586
ETIM 10.0	EC002586	ECLASS 9.1	27-37-10-10
ECLASS 10.0	27-37-10-10	ECLASS 11.0	27-37-16-92

Technical data

ECLASS 12.0	27-37-16-92	ECLASS 13.0	27-37-16-92
ECLASS 14.0	27-37-16-92	ECLASS 15.0	27-37-16-92

Drawings

Wiring diagram

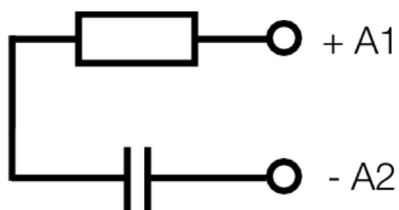

Dimensional drawing

