


CB 360/4,5 NC

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

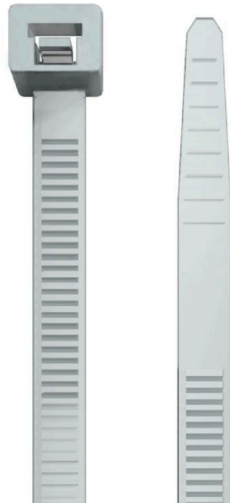

CB cable ties for the fastening of cables and markers.

- They are particularly suitable for fastening CLI M, SFX, WKM and WKS cable markers
- IEC 62275: 2006-conformant
- Fracture-resistant polyamide PA 6.6 with flammability rating V2 to UL-94

General ordering data

Version	Cable ties, 4,5 x 360 mm, Polyamide 66, 220 N
Order No.	1279000000
Type	CB 360/4,5 NC
GTIN (EAN)	4008 19003 1459
Qty.	100 items

Technical data

Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate No. (UR)	E317499

Dimensions and weights

Depth	1.8 mm	Depth (inches)	0.0709 inch
Height	360 mm	Height (inches)	14.1732 inch
Width	4.5 mm	Width (inches)	0.1772 inch
Net weight	2.38 g		

Temperatures

Operating temperature range	-40...85 °C
-----------------------------	-------------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Installation materials

UV-resistant	No	For re-opening	No
UL 94 flammability rating	V-2	Operating temperature range, max.	85 °C
Operating temperature range, min.	-40 °C	Halogen	No
Cable diameter, max.	103 mm	Basic material	Polyamide 66
Tensile strength	220 N	Bundle diameter, max.	100 mm
Tensile strength (Pound-force)	49 lbf	Bundle diameter, min.	3.5 mm

Classifications

ETIM 6.0	EC000046	ETIM 7.0	EC000046
ETIM 8.0	EC000046	ETIM 9.0	EC000046
ETIM 10.0	EC000046	ECLASS 9.0	27-14-07-02
ECLASS 9.1	27-14-07-02	ECLASS 10.0	27-14-07-02
ECLASS 11.0	27-14-07-02	ECLASS 12.0	27-14-07-02
ECLASS 13.0	27-14-07-02	ECLASS 14.0	27-14-07-02
ECLASS 15.0	27-14-07-02		

Drawings

