


**PAC-UNIV-HE10-F-3M**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com

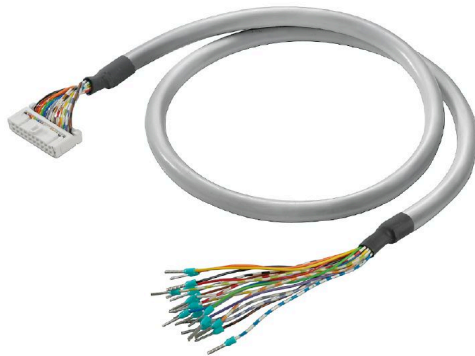

Similar to illustration

**General ordering data**

Version	Pre-assembled cable, PAC
Order No.	<a href="#">1349730030</a>
Type	PAC-UNIV-HE10-F-3M
GTIN (EAN)	4032248177165
Qty.	1 items

## PAC-UNIV-HE10-F-3M

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Technical data

## Approvals

ROHS	Conform
------	---------

## Dimensions and weights

Net weight	125.1 g
------------	---------

## Temperatures

Storage temperature	-10...60 °C	Operating temperature	-10...50 °C
---------------------	-------------	-----------------------	-------------

## Environmental Product Compliance

RoHS Compliance Status	Compliant
REACH SVHC	No SVHC above 0.1 wt%

## General Data

Cable length	3 m	Suitable for	Digital signals
Basic material	PVC	Cable	Cable LiYY
Interface connector	FLAT CABLE CONECTOR HE10 10P	Number of poles, min.	10-pole
Outer diameter	7 ± 1 mm	Connector PLC side	H0.14/10 (FERRULES 0.14mm <sup>2</sup> )
Wire cross-section	0.14 mm <sup>2</sup>		

## Electrical Data

Total current, max.	3 A	Permissible current strength per path, max.	1 A
Rated voltage	≤ 60 V DC ≤ 25 V AC	Resistance	≤ 150 mΩ/m
Operating voltage	≤ 60 V DC ≤ 25 V AC	Capacity wire / wires	300 pF/m
Capacity wire / shield	300 pF/m		

## Classifications

ETIM 6.0	EC000237	ETIM 7.0	EC000237
ETIM 8.0	EC000237	ETIM 9.0	EC000237
ETIM 10.0	EC000237	ECLASS 9.0	27-24-22-20
ECLASS 9.1	27-24-22-20	ECLASS 10.0	27-24-22-20
ECLASS 11.0	27-24-22-20	ECLASS 12.0	27-24-22-20
ECLASS 13.0	27-24-22-20	ECLASS 14.0	27-24-22-20
ECLASS 15.0	27-24-22-20		