

TCC 12.8/26 OR**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Product image**Adjustable cross-connections**

Increase the flexibility of your cross-connections. The TERMSERIES CROSS-CONNECTION (TCC) enables individually adjustable cross-connections with up to 51 poles. The maximum number of pluggable poles has been increased to 32 poles. The strip material can be shortened to the required length very easily. The cross-connectors convince thanks to their easy handling and visibility as well as their universal connection possibilities. An additional web prevents the spring from deforming during assembly.

- Individually adjustable cross-connection with 51 poles
- Additional bar to avoid deformation of the spring
- Increased cross-connection – up to 32 poles possible
- Vibration resistance

General ordering data

| | |
|------------|-----------------------------|
| Version | TERMSERIES, Cross-connector |
| Order No. | 2556380000 |
| Type | TCC 12.8/26 OR |
| GTIN (EAN) | 4050118566697 |
| Qty. | 10 items |

TCC 12.8/26 OR

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

| | |
|------|---------|
| ROHS | Conform |
|------|---------|

Dimensions and weights

| | | | |
|------------|----------|-----------------|--------------|
| Depth | 4.8 mm | Depth (inches) | 0.189 inch |
| Height | 13.1 mm | Height (inches) | 0.5157 inch |
| Width | 323.4 mm | Width (inches) | 12.7323 inch |
| Net weight | 9.7 g | | |

Temperatures

| | | | |
|-----------------------|----------------|---------------------|----------------|
| Storage temperature | -40 °C...85 °C | Ambient temperature | -40 °C...60 °C |
| Operating temperature | | | |

Environmental Product Compliance

| | |
|------------------------|-----------------------------|
| RoHS Compliance Status | Compliant without exemption |
| REACH SVHC | No SVHC above 0.1 wt% |

Cross-connection data

| | | | |
|------------------|---------|-------------------------------------|----------------------|
| Rated voltage | 300 V | Rated current | 17.5 A |
| Insulation | Yes | Touch-safe protection | Yes |
| Colour | orange | Number of cross-connected terminals | 16 |
| Number of poles | 26 | Pitch in mm (P) | 12.80 mm |
| Type of mounting | Plugged | Version | can be cut to length |

Rated data UL

| | |
|--------------------|------|
| Rated current (UL) | 10 A |
|--------------------|------|

General data

| | | | |
|------------------------------------|--------------------------|---------|--|
| Version | can be cut to length | | |
| Colour | orange | | |
| UL94 flammability rating component | Component | Housing | |
| | UL94 flammability rating | V-0 | |

Insulation coordination

| | |
|---------------|-------|
| Rated voltage | 300 V |
|---------------|-------|

Connection data


| | |
|-----------------|----------|
| Pitch in mm (P) | 12.80 mm |
|-----------------|----------|

Classifications


| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 6.0 | EC002586 | ETIM 7.0 | EC002586 |
| ETIM 8.0 | EC002586 | ETIM 9.0 | EC002586 |
| ETIM 10.0 | EC002586 | ECLASS 9.1 | 27-37-16-92 |
| ECLASS 10.0 | 27-37-16-92 | ECLASS 11.0 | 27-37-16-92 |
| ECLASS 12.0 | 27-37-16-92 | ECLASS 13.0 | 27-37-16-92 |
| ECLASS 14.0 | 27-37-16-92 | ECLASS 15.0 | 27-37-16-92 |

Drawings

Product image

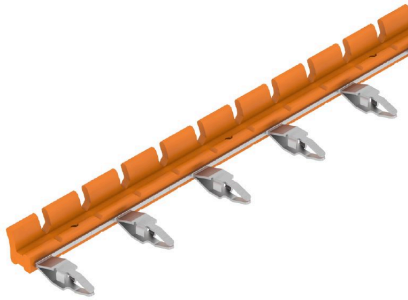


Dimensional drawing

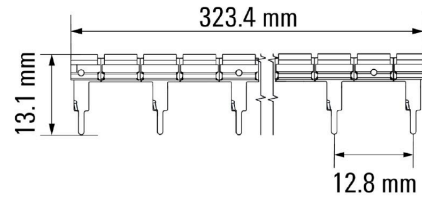

Drawings

Miscellaneous

Type code TERMSERIES accessories

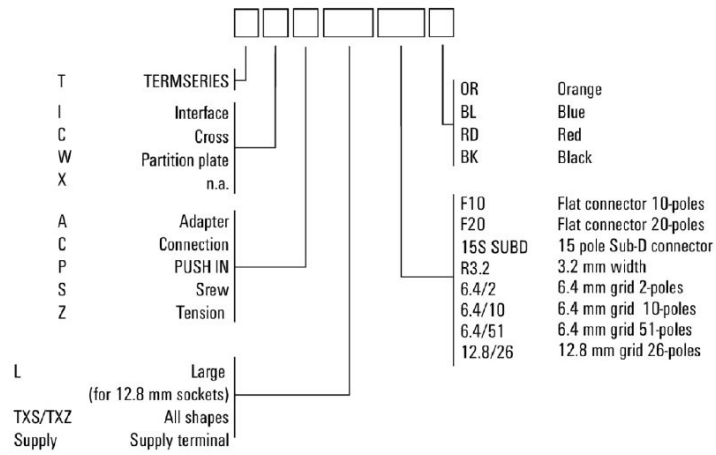

Type codes