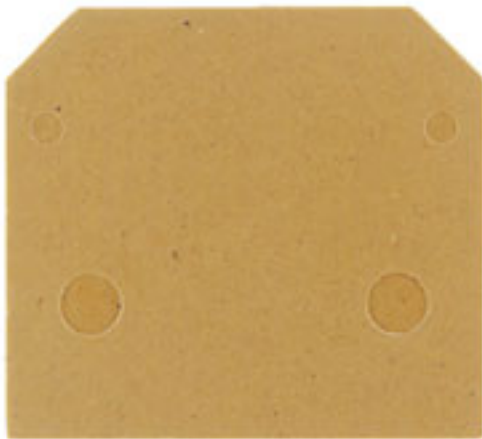


SAK Series
AP 70 SAK70 KRG

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Product image

Similar to illustration

Klippon® Connect with clamping yoke Technology

The high reliability and variety of designs of the terminal blocks with clamping yoke connections make planning easier and optimises operational safety. Klippon® Connect provides a proven response to a range of different requirements.

General ordering data

Delivery status	This article will no longer be available in the future.
Available until	2020-12-31
Type	AP 70 SAK70 KRG
Order No.	0340920000
Version	SAK Series, End plate, 4 mm, dark beige, yellow, Direct mounting
GTIN (EAN)	4008190154684
Qty.	10 pc(s).
Alternative product	0340960000

Creation date April 27, 2020 5:00:35 AM CEST

SAK Series
AP 70 SAK70 KRG

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Technical data**Dimensions and weights**

Width	4 mm	Width (inches)	0.157 inch
Height	75 mm	Height (inches)	2.953 inch
Depth	64 mm	Depth (inches)	2.52 inch
Net weight	25.3 g		

Temperatures

Storage temperature, max.	40 °C	Storage temperature, min.	10 °C
Storage temperature	10 °C...40 °C	Continuous operating temp., min.	-60 °C
Continuous operating temp., max.	130 °C		

Material data

Material	KrG	Colour	dark beige, yellow
UL 94 flammability rating	V-0		

System specifications

Version	End plate
---------	-----------

Additional technical data

Installation advice	Direct mounting	Snap-on	Yes
---------------------	-----------------	---------	-----

Classifications

ETIM 6.0	EC000886	ETIM 7.0	EC000886
eClass 9.1	27-14-11-33	eClass 10.0	27-14-11-33
UNSPSC	30-21-18-27		

Approvals

ROHS	Conform
------	---------

Downloads

Engineering Data	EPLAN, WSCAD
User Documentation	StorageConditionsTerminalBlocks