


**Connecting elements
H50,0/36 OLIV**

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

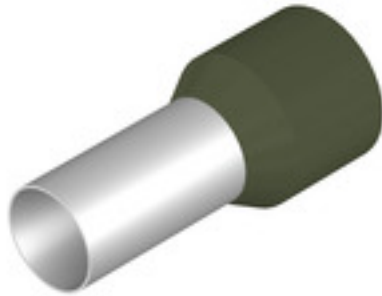

- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code

General ordering data

Type	H50,0/36 OLIV
Order No.	0444200000
Version	Wire-end ferrule, insulated, 26 mm, 20 mm, Olive green
GTIN (EAN)	4008190110284
Qty.	50 pc(s).
Packaging	loose

Data sheet

**Connecting elements
H50,0/36 OLIV**

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Technical data

Dimensions and weights

Width	36 mm	Width (inches)	1.417 inch
Net weight	2.8 g		

Technical data

Version	insulated
---------	-----------

Wire-end ferrules

Collar diameter (D2)	15 mm	Colour code	Weidmüller
Conductor cross-section	50 mm ²	Contact surface diameter (D1)	10.3 mm
Contact surface length (L2)	20 mm	L1 in mm	36 mm
Metal sleeve thickness (S1)	0.3 mm	Plastic collar thickness (S2)	0.5 mm
Stripping length	26 mm	Wire connection cross section AWG, max.	AWG 1

Classifications

ETIM 6.0	EC000005	ETIM 7.0	EC000005
eClass 9.0	27-40-02-01	eClass 9.1	27-40-02-01
eClass 10.0	27-40-02-01	UNSPSC	31-16-31-02

Approvals

Approvals



ROHS	Conform
------	---------

Downloads

Brochure/Catalogue	CAT 6 TOOLS 15/16 EN
Engineering Data	EPLAN, WSCAD, Zuken E3.S
Engineering Data	STEP

Data sheet

Connecting elements
H50,0/36 OLIV

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

Drawings

Drawing

