 


Printed Circuit Board Terminal Blocks

 
LP Series

5.08/6.35 mm Pitch


LP 2HR/5.08
Double-level
90° orientation
High profile/offset right



LP 3R/5.08
Triple-level
90° orientation
without test points



LLP 6.35
Single-level
90° orientation
with test points

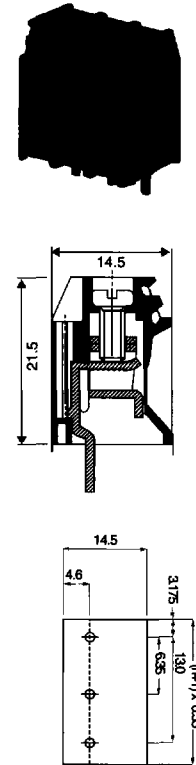

Rated Voltage	300 V	300 V	250 V	300 V	300 V	250 V	250 V	300 V	320 V
Rated Current	10 A	10 A	24 A	10 A	10 A	22 A	25 A	25 A	24 A
Wire Size	#26...12 AWG	#26...12 AWG	2.5 mm²	#26...12 AWG	#26...12 AWG	2.5 mm²	#22...10 AWG	#20...10 AWG	0.5...6 mm²
Strip Length	7 mm	7 mm	7 mm	7 mm	7 mm	7 mm	6 mm	6 mm	6 mm
Torque Nm (lb. in.)	0.5 (4.4)	0.5 (4.4)	0.5 (4.4)	0.5 (4.4)	0.5 (4.4)	0.5 (4.4)	0.6 (5.0)	-	-
Pin Length	4.5 mm	4.5 mm	4.5 mm	4.5 mm	4.5 mm	4.5 mm	5.0 mm	5.0 mm	5.0 mm

4	LP 2HR/5.08/4 OG	163629	6	LP 3R/5.08/6 OG	165394	2	LLP 6.35/90/2 BK	950969
6	LP 2HR/5.08/6 OG	163630	9	LP 3R/5.08/9 OG	159633	3	LLP 6.35/90/3 BK	950970
8	LP 2HR/5.08/8 OG	163631	12	LP 3R/5.08/12 OG	159635	4	LLP 6.35/90/4 BK	996749
10	LP 2HR/5.08/10 OG	163632	15	LP 3R/5.08/15 OG	159637	5	LLP 6.35/90/5 BK	996750
12	LP 2HR/5.08/12 OG	166964	18	LP 3R/5.08/18 OG	159639	6	LLP 6.35/90/6 BK	996751
14	LP 2HR/5.08/14 OG	166965	21	LP 3R/5.08/21 OG	163301	7	LLP 6.35/90/7 BK	996752
16	LP 2HR/5.08/16 OG	163633	24	LP 3R/5.08/24 OG	159641	8	LLP 6.35/90/8 BK	996753
18	LP 2HR/5.08/18 OG	166966	27	LP 3R/5.08/27 OG	163302	9	LLP 6.35/90/9 BK	996754
20	LP 2HR/5.08/20 OG	163634	30	LP 3R/5.08/30 OG	159643	10	LLP 6.35/90/10 BK	996755
22	LP 2HR/5.08/22 OG	166967	33	LP 3R/5.08/33 OG	163303	11	LLP 6.35/90/11 BK	996756
24	LP 2HR/5.08/24 OG	163635	36	LP 3R/5.08/36 OG	163304	12	LLP 6.35/90/12 BK	996757
26	LP 2HR/5.08/26 OG	166968	39	LP 3R/5.08/39 OG	163305	13	LLP 6.35/90/13 BK	996758
28	LP 2HR/5.08/28 OG	166969	42	LP 3R/5.08/42 OG	163306	14	LLP 6.35/90/14 BK	996759
30	LP 2HR/5.08/30 OG	163636	45	LP 3R/5.08/45 OG	163307	15	LLP 6.35/90/15 BK	996760
32	LP 2HR/5.08/32 OG	166970	48	LP 3R/5.08/48 OG	163308	16	LLP 6.35/90/16 BK	996761
34	LP 2HR/5.08/34 OG	166971	51	LP 3R/5.08/51 OG	163309	17	LLP 6.35/90/17 BK	996762
36	LP 2HR/5.08/36 OG	166972	54	LP 3R/5.08/54 OG	163310	18	LLP 6.35/90/18 BK	996763
38	LP 2HR/5.08/38 OG	166973	57	LP 3R/5.08/57 OG	163311	19	LLP 6.35/90/19 BK	996764
40	LP 2HR/5.08/40 OG	166974	60	LP 3R/5.08/60 OG	163312	20	LLP 6.35/90/20 BK	996765
42	LP 2HR/5.08/42 OG	166975	63	LP 3R/5.08/63 OG	163313	21	LLP 6.35/90/21 BK	996766
44	LP 2HR/5.08/44 OG	166976	66	LP 3R/5.08/66 OG	163314	22	LLP 6.35/90/22 BK	996767
46	LP 2HR/5.08/46 OG	166977	69	LP 3R/5.08/69 OG	163315	23	LLP 6.35/90/23 BK	996768
48	LP 2HR/5.08/48 OG	166978	72	LP 3R/5.08/72 OG	163316	24	LLP 6.35/90/24 BK	996769

*Pending

Notes: Other solder pin lengths are available upon request.
See pages 6/21-24 for marking materials and other accessories.