



2017

Like Us On facebook



Tools that work for you

# Professional Screwdrivers & Nut Drivers



## Screwdrivers & Nut Drivers



## Wiha SoftFinish® CushionGrip Screwdrivers

Description	Page
SoftFinish® Slotted/Phillips Drivers	4-7
Stubby Slotted/Phillips Drivers	7
SoftFinish® Square Drivers	7
SoftFinish® Pozidriv® Drivers	8
SoftFinish® Spanner Drivers	8
Torx®/TR Torx® Screwdrivers	9-10
SoftFinish® TorxPlus® Drivers	11
SoftFinish® MagicSpring Drivers	9
SoftFinish® MagicRing Drivers	12-13
Measuring Scale Screwdrivers	8

## Wiha Screw Holding Screwdrivers

Description	Page
Screw Holding Screwdrivers	9

## Wiha 3K Series Screwdrivers

Description	Page
3K Series Slotted/Phillips	15-16
3K Series Torx Drivers	17
3K Series Pozidriv® Drivers	17
3K Series Bit Holders	15
3K Series Hex Inch & Metric	18

## Wiha Drive-Loc VI Tools

Description	Page
Drive-Loc VI Handles	19
Drive-Loc VI Blades	19-20

## Wiha Drive-Loc VI Sets

Description	Page
Drive-Loc VI Blade Sets	20-21

## Wiha MicroFinish Non-Slip Grip Drivers

Description	Page
MicroFinish Slotted Drivers	21-22
MicroFinish Phillips Drivers	21-22
MicroFinish Torx Drivers	22
MicroFinish Bit Holder	21

## Wiha Powerhandle Screwdrivers

Description	Page
Powerhandle Torx® Drivers	23

## Wiha Protorn Screwdrivers

Description	Page
Protorn Torx® Drivers	23

## Wiha Dynamic Screwdrivers

Description	Page
Dynamic Slotted/Phillips Drivers	14

## Wiha Square Handle Screwdrivers

Description	Page
Slotted & Phillips Drivers	24


## Wiha Offset Screwdrivers

Description	Page
Slotted & Phillips Offset Drivers	24
TORX Offset Screwdrivers	24



## Wiha Power Blades & Sets

Description	Page
CentroFix Blade Holder	25
90mm Power Blades	25-26
Power Blade Sets	26


### Wiha Magnetizer/Demagnetizer

Description	Page
 Magnetizer/Demagnetizer	33



### Wiha Precision Screwdrivers

Description	Page
 Precision Slotted Drivers	27-28
Precision Phillips Drivers	27-28
Precision Pozidriv® Drivers	28
Precision Hex Drivers	28
Precision Ball End Drivers	29
Precision Torx® Drivers	29
Precision Pentalobe Drivers	30
 Precision Chip Lifters	27
 Precision Screwdriver Sets	30


### Wiha Precision PicoFinish Drivers

Description	Page
 PicoFinish Screwdrivers	31-32
Slotted, Phillips, Torx, TorxPlus, Hex, MagicSpring, Ball End Hex, Chip Lifter	



### Wiha Protturn Precision Screwdrivers

Description	Page
 Protturn Precision Screwdrivers	33
Slotted & Phillips	
 Protturn Precision Blade Sets	33







 
### Wiha ESD Safe Precision Handles/Blades

Description	Page
 SYSTEM 4 Handles/Blades	34-35
SYSTEM 4 Sets	36-37

### Wiha ESD Safe Precision Handle & Blades

Description	Page
 SYSTEM 4 Drive-Loc Handle & Blades	35
 SYSTEM 4 Drive-Loc Set	35

### Wiha Nut Drivers

Description	Page
 SoftFinish® Nut Drivers	38-39
 Hollow Shaft Nut Drivers	40
 T-handle Nut Drivers	41
 Drive-Loc VI Nut Drivers	42
 Precision Nut Drivers	43
 PicoFinish® Nut Drivers	42
 SYS 4 Nut Driver Blades/Sets	44

### Wiha Insulated Screwdrivers



- Insulated Slotted
- Insulated Phillips
- Insulated Terminal Block Xeno
- Insulated Square Drivers
- Insulated Hex Metric Drivers
- Insulated Torx® Drivers
- Insulated Nut Drivers
- Insulated Torque Drivers
- Insulated *SlimLine* Drivers

### Wiha ESD Safe Screwdrivers

ESD Safe SoftFinish® Drivers  
Slotted/Phillips/Torx

ESD Safe Precision Drivers  
Slotted/Phillips/Torx®/  
TorxPlus®/Hex/Nut Drivers/  
Chip Lifter

ESD Safe Ceramic Drivers

ESD Safe SYSTEM 4  
Handles/Blades/Sets

ESD Safe Drive-Loc VI  
Handles/Blades/Sets








**SoftFinish® Extra Heavy Duty**




**53097 7 Pc. Slotted & Phillips Set - Extra Heavy Duty**

Item	Slotted:	
No.	5.5, 6.5, 8.0, 10.0mm	lbs.
53097	Phillips: #1, 2, 3	3.15



**53099 10 Piece Slotted & Phillips Set - Extra Heavy Duty**

Item	Slotted: 3.5, 4.5, 5.5,	
No.	6.5, 8.0, 10.0, 12.0mm	lbs.
53099	Phillips: #1, 2, 3	4.20

**SoftFinish® Slotted & Phillips**



**30276 7 Pc. Slotted & Phillips Set CVM**  
steel, hardened, hard chromed. Wiha-Chromtop tips. Handle, multi-component, cushion grip.



 
 
 



 





 

 
 
Item No. 30276	Tip Size	Blade	Tip Style		lbs.
30816	1/4"	4" Hex	Keystone		1.87
30825	5/16"	6" Hex	Keystone		
30218	3/16"	3" Round	Cabinet		
30219	3/16"	6" Round	Cabinet		
30222	1/4"	4" Round	Cabinet		
31110	#1	3" Round	Phillips		
31115	#2	4" Round	Phillips		

**Wiha SoftFinish® Heavy Duty Screwdriver**



**308 Slotted Screwdriver, Wiha-SoftFinish® Cushion Grip Handle**


 

 


 
 





 
 
 
 
Hex blade high alloy CVM steel, hardened, hard chromed. Wiha-Chromtop finish on tips. Hex bolster for additional torque (No Bolster 30813 & 30814)

Item																		
No.	mm	Inch	mm	Inch	mm	Inch	mm	Inch	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.		
30813	3.5	.137	75	2.9	0.6	.023	186	7.3	4.0	5/32	30	1.18	.16	10				
30814	4.5	.177	90	3.5	0.8	.032	201	7.9	4.0	5/32	30	1.18	.17	10				
30815	5.5	.216	100	3.9	1.0	.039	213	8.4	5.0	13/64	36	1.42	.19	10				
30816	6.5	.216	100	3.9	1.2	.047	213	8.4	6.0	1/4	36	1.42	.22	10				
30817	6.5	.255	125	5.0	1.2	.047	238	9.4	6.0	1/4	36	1.42	.23	10				
30820	7.0	.275	125	5.0	1.1	.043	238	9.4	6.0	1/4	36	1.42	.23	10				
30825	8.0	.315	150	5.9	1.2	.047	271	10.7	8.0	5/16	41	1.61	.37	10				
30830	10.0	.393	175	7.0	1.6	.063	296	11.7	8.0	5/16	41	1.61	.40	10				
30835	12.0	.472	200	8.0	2.0	.079	321	12.6	10.0	25/64	41	1.61	.58	10				




**312 Phillips Screwdriver, Wiha-SoftFinish® Cushion Grip Handle**

Hex blade high alloy CVM steel, hardened, hard chromed. Wiha-Chromtop finish on tips. Hex bolster for additional torque.

Item																	
No.	Size	mm	Inch	mm	Inch	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.				
31201	1	80	3.1	5.0	3/16	186	7.3	30	1.18	.13	10						
31202	2	100	3.9	6.0	7/32	213	8.4	36	1.42	.21	10						
31203	3	150	5.9	8.0	5/16	271	10.7	41	1.61	.37	10						




**30892 5 Piece Slotted & Phillips Set**

Item	Slotted:	
No.	5.5, 7.0, 8.0mm	lbs.
30892	Phillips: #1, 2	1.33



**30898 8 Piece Slotted & Phillips Set**

Item	Slotted: 5.5, 6.5,	
No.	7.0, 8.0, 10.0mm	lbs.
30898	Phillips: #1, 2, 3	2.52



**30896 6 Piece Slotted & Phillips Set**

Item	Slotted: 3.5, 4.5,	
No.	5.5, 7.0mm	lbs.
30896	Phillips: #1, 2	1.34



## Wiha SoftFinish® Handle - Standard Series



**302 Slotted Screwdriver, With Wiha-SoftFinish® Handle** Round blade, high alloy CVM, hardened, hard chromed. Wiha-Chromtop tips. Handle, multi-component, cushion grip.

Item No.	↓	↓	←	←	⊕	⊕	←	←	⊕	⊕	↶	↷	lbs.	pkg.
	mm	Inch	mm	Inch	mm	Inch	mm	Inch	mm	Inch	mm	Inch		
30202*	2.0	.079	65	2.6	0.4	.016	169	6.7	23	.91	.05		10	
30203*	2.5	.098	75	3.0	0.4	.016	179	7.0	23	.91	.05		10	
30204*	3.0	.118	80	3.1	0.5	.020	184	7.2	23	.91	.06		10	
30205*	3.0	.118	100	3.9	0.5	.020	204	8.0	23	.91	.06		10	
30206*	3.0	.118	150	5.9	0.5	.020	254	10.0	23	.91	.07		10	
30208*	3.0	.118	200	8.0	0.5	.020	304	12.0	23	.91	.07		10	
30210*	3.5	.139	100	3.9	0.6	.024	204	8.0	23	.91	.07		10	
30212*	3.5	.139	200	8.0	0.6	.024	304	12.0	23	.91	.09		10	
30215*	4.0	.157	100	3.9	0.8	.031	211	8.3	30	1.18	.11		10	
30217*	4.0	.157	150	5.9	0.8	.031	261	10.3	30	1.18	.12		10	
30216*	4.0	.157	200	8.0	0.8	.031	311	12.2	30	1.18	.14		10	
30218*	4.5	.187	80	3.1	0.8	.031	191	7.5	30	1.18	.11		10	
30211*	4.5	.187	125	5.0	0.8	.031	236	9.3	30	1.18	.12		10	
30219*	4.5	.187	150	5.9	0.8	.031	261	10.2	30	1.18	.12		10	
30220*	5.5	.216	125	5.0	1.0	.039	236	9.3	30	1.18	.15		10	
30238*	5.5	.216	300	11.8	1.0	.039	411	16.1	30	1.18	.24		10	
30221*	5.5	.216	200	8.0	1.0	.039	311	12.2	30	1.18	.20		10	
30222	6.0	.250	100	3.9	1.2	.047	218	8.6	36	1.42	.17		10	
30223	6.5	.255	100	3.9	1.0	.039	218	8.6	36	1.42	.20		10	
30225	6.5	.255	150	5.9	1.2	.047	268	10.6	36	1.42	.22		10	
30226	6.5	.255	200	8.0	1.2	.047	318	12.5	36	1.42	.22		10	
30227	8.0	.315	150	5.9	1.2	.047	274	10.8	41	1.61	.29		10	
30230	8.0	.315	175	7.0	1.2	.047	299	11.8	41	1.61	.30		10	
30232	8.0	.315	300	11.8	1.2	.047	424	16.7	41	1.61	.36		10	
30235	10.0	.393	200	8.0	1.6	.063	324	12.8	41	1.61	.36		10	
30236	12.0	.472	250	9.8	2.0	.078	374	14.7	41	1.61	.52		10	

\*Cabinet Tips



**311 Phillips Screwdriver, With Wiha-SoftFinish® Handle** Round blade, high alloy CVM steel, hardened, hard chromed. Wiha-Chromtop tips. Handle, multi-component, cushion grip.


Item No.	⊕	←	←	↓	↓	←	←	⊕	⊕	↶	↷	lbs.	pkg.
	Size	mm	Inch	mm	Inch	mm	Inch	mm	Inch	mm	Inch		
31105	0	60	2.4	3.0	.118	164	6.5	23	.91	.06		10	
31110	1	80	3.1	4.5	.177	191	7.5	30	1.18	.11		10	
31112	1	200	8.0	4.5	.177	311	12.3	30	1.18	.15		10	
31114	1	300	12.0	4.5	.177	411	16.2	30	1.18	.18		10	
31115	2	100	3.9	6.0	.236	218	8.6	36	1.42	.20		10	
31117	2	200	8.0	6.0	.236	318	12.5	36	1.42	.25		10	
31118	2	300	12.0	6.0	.236	418	16.5	36	1.42	.30		10	
31120	3	150	5.9	8.0	.315	274	10.8	41	1.61	.33		10	
31125	4	200	8.0	10.0	.393	323	12.7	41	1.61	.51		10	



**30294 6 Pc. Slotted/Phillips Screwdriver Set**

Item No.	↓	←	⊕	←	↶	↷	lbs.
	mm	mm	Size	mm			
30294	4.0	100	1	80			1.29
	6.5	150	2	100			
	8.0	150					
	4.0*	25					

\*Stubby screwdriver with Wiha SoftFinish® handle

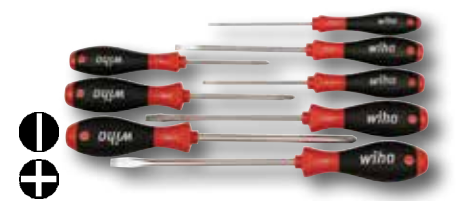

**30298 8 Pc. Slotted/Phillips Screwdriver Set**

Item No.	↓	←	⊕	←	↶	↷	lbs.
	mm	mm	Size	mm			
30298	3.0	100	1	80			1.87
	4.0	100	2	100			
	5.5	125	3	150			
	6.5	150					
	8.0	175					



**30297 12 Piece Slotted & Phillips Screwdriver Set**

Item No.	↓	←	⊕	←	↶	↷	lbs.
	mm	mm	Size	mm			
30297	3.0	100	0	60			2.48
	4.0	100	1	80			
	5.5	125	2*	25			
	6.5	150	2	100			
	6.5*	25	3	150			
	8.0	175					
	10	200					

\*Stubby screwdriver with Wiha SoftFinish® handle

**Wiha SoftFinish® Handle - Stubby Screwdrivers**



**302 Stubby Slotted Screwdriver, With Wiha-SoftFinish® Handle**

Item													
No.	mm	Inch	mm	Inch	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.	
30239	4.0	.157	25	1.0	0.8	.031	75	2.95	34	1.34	.09	10	
30255	5.5	.216	25	1.0	1.0	.039	75	2.95	34	1.34	.09	10	
30265	6.5	.255	25	1.0	1.2	.047	75	2.95	34	1.34	.10	10	



**311 Stubby Phillips Screwdriver, With Wiha-SoftFinish® Handle**

Item												
No.	Size	mm	Inch	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.	
31135	1	25	1.0	4.5	.177	75	3.0	34	1.34	.09	10	
31140	2	25	1.0	6.0	.236	75	3.0	34	1.34	.10	10	



**31193 2 Pc. Slotted Stubby Screwdriver Set**

Item					
No.	mm	mm	mm	mm	lbs.
31193	4.0	25	6.5	25	.24



**31192 2 Pc. Phillips Stubby Screwdriver Set**

Item					
No.	Size	mm	Size	mm	lbs.
31192	1	25	2	25	.24



**31190 2 Piece Slotted & Phillips Stubby Screwdriver Set**

Item					
No.	mm	mm	Size	mm	lbs.
31190	4.0	25	1	25	.24



**31191 2 Piece Slotted & Phillips Stubby Screwdriver Set**

Item					
No.	mm	mm	Size	mm	lbs.
31191	6.5	25	2	25	.24

**Wiha SoftFinish® Handle - Square Drivers**



**358 Square Screwdriver, With Wiha-SoftFinish® Handle**

Round blade high alloy chrome-vanadium-molybdenum steel, hardened, hard chromed. Wiha-Chromtop finish on tips. Wiha-SoftFinish® handle, multi-component, cushion grips.

Item											
No.	Size	mm	Inch	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.
35800	0	80	3.1	4.0	5/32	191	7.5	30	1.18	.11	10
35801	1	100	3.9	4.5	5/32	210	8.2	30	1.18	.12	10
35802	2	150	5.9	6.0	1/4	268	10.5	36	1.42	.19	10
35803	3	150	5.9	6.0	1/4	268	10.5	36	1.42	.22	10



**35894 4 Pc. SoftFinish® Square Tip Screwdriver Set**


Round blade high alloy CVM steel, hardened, hard chromed.

Item				
No.	Size	mm	Size	mm
35894	0	80	2	150
	1	100	3	150



**30290 10 Piece Slotted, Phillips & Square Cushion Grip Drivers**

Item	Slotted: 3.0, 3.5, 4.5, 6.5mm	
No.	Phillips: 0, 1, 2	lbs.
30290	Square: 1, 2, 3	1.54

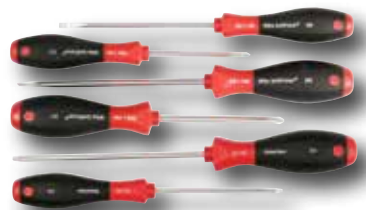

**30291 6 Piece Slotted, Phillips & Square Cushion Grip Drivers**

Item	Slotted: 4.5, 6.5mm	
No.	Phillips: 1, 2	lbs.
30291	Square: 1, 2	1.00





## Wiha SoftFinish® Pozidriv®



### 313 Pozidriv® Screwdriver, With Wiha-SoftFinish® Handle

Round blade high alloy chrome-vanadium-molybdenum steel, hardened, hard chromed. Wiha-Chromtop finish on tips. Wiha-SoftFinish® handle, multi-component, cushion grips.

Item No.	Symbol	Size	mm	Inch	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.
31305	⊕	0	60	2.4	3.0	.118	164	6.5	23	.91	.06	10
31310	⊕	1	80	3.1	4.5	.177	191	7.5	30	1.18	.11	10
31312	⊕	1	200	8.0	4.5	.177	311	12.3	30	1.18	.15	10
31315	⊕	2	100	3.9	6.0	.236	218	8.6	36	1.42	.20	10
31320	⊕	3	150	5.9	8.0	.315	274	10.8	41	1.61	.33	10

## Wiha SoftFinish® Slotted Spanner Nut Drivers



### 305 Slotted Spanner Nut Drivers, With Wiha-SoftFinish® Handle

Round blade high alloy chrome-vanadium-molybdenum steel, hardened, hard chromed. Wiha-Chromtop finish on tips. Wiha-SoftFinish® handle, multi-component, cushion grips.

Item No.	Symbol	Size	mm	Inch	mm	mm	Inch	mm	Inch	mm	Inch	pkg.
30517	⊕	M1.7	80	3.1	0.5	4.0	184	7.2	23	.91		1
30520	⊕	M2	80	3.5	1.0	4.5	184	7.2	23	.91		1
30523	⊕	M2.3	90	3.5	1.0	5.0	201	7.9	30	1.18		1
30526	⊕	M2.6	100	3.9	1.2	5.5	201	7.9	30	1.18		1
30530	⊕	M3	100	3.9	1.2	6.0	211	8.3	30	1.18		1
30535	⊕	M3.5	100	3.9	1.4	7.0	218	8.6	36	1.42		1
30540	⊕	M4	100	3.9	1.4	8.0	218	8.6	36	1.42		1
30550	⊕	M5	125	4.9	2.0	10.0	243	9.6	36	1.42		1
30560	⊕	M6	125	4.9	2.5	11.0	243	9.6	36	1.42		1
30580	⊕	M8	150	5.9	3.0	14.0	274	10.8	41	1.61		1

## Wiha SoftFinish® CushionGrip Drivers

### With Inch & MM Scale on Blades



Inch and Metric

- Perfect for measuring small parts on the go
- Quickly check drilled hole depths & diameters
- Patented design with permanent laser marking
- Chrome-vanadium-molybdenum tool steel shafts
- Hardened & tempered for long life performance
- Precision machined exact fit tips
- Hard chrome surfaces for incredible wear resistance



### 31194 2 Pc Slotted & Phillips Measuring Scale Screwdriver Set

Item No.	Symbol	mm	mm	Size	mm	lbs.
31194	⊕	5.5	125	2	100	.37

Inch & Metric scales



### 302 Measuring Scale Slotted Screwdriver, With Wiha-SoftFinish® Cushion Grip Handle

Item No.	Symbol	mm	Inch	mm	Inch	mm	Inch	mm	Inch	mm	Inch	Scale	lbs.	pkg.
30237	⊕	5.5	7/32	125	5.0	1.0	.039	236	9.3	30	1.18	30-110	.16	10

Inch & Metric scales



### 311 Measuring Scale Phillips Screwdriver, With Wiha-SoftFinish® Cushion Grip Handle

Item No.	Symbol	Size	mm	Inch	mm	Inch	mm	Inch	mm	Inch	Scale	lbs.	pkg.
31137	⊕	2	100	3.9	6.0	1/4	218	8.6	36	1.42	20-90	.21	10

## Wiha SoftFinish® Handle - Standard Series Sets



### 30299 20 Piece Slotted, Phillips, TORX®, Square & Pozidriv® Set

Item No.	Symbol	Slotted:	Phillips:	TORX®:	Square:	Pozidriv®:	lbs.
30299	⊕	3.0, 4.0, 5.5, 6.5, 8.0mm	0, 1, 2	T6, T8, T10, T15, T20, T25, T30	1, 2, 3	1, 2	3.27



\*Inch & Metric scale on #2 Phillips



Perfect for measuring small parts on the go

### 30295 5 Piece Slotted & Phillips Screwdriver Set

Item No.	Symbol	mm	mm	Size	mm	lbs.
30295	⊕	3.0	100	1	80	1.02
	⊕	4.0	100	2*	100	
	⊕	6.5	150			



**Wiha Screw Holding Screwdrivers**



**Clamping sleeve to hold screw**

**398 Slotted Screw Holding Screwdriver, With Wiha-SoftFinish® Handle** Blade CVM steel, hardened, black finish. Clamping sleeve polyamide. SoftFinish® handle cushion grip, impact resistant.

Item No.	Size	mm	Inch	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.
39825	2.5	.10	75	3.0	160	6.3	30	1.18	.09	10	
39830	3.0	.12	100	3.9	195	7.6	30	1.18	.19	10	
39840	4.0	.16	125	5.0	230	9.0	36	1.42	.27	10	
39850	5.0	.20	150	5.9	265	10.4	36	1.42	.27	10	
39860	6.0	.24	175	6.9	290	11.4	36	1.42	.32	10	



**Clamping sleeve to hold screw**

**397 Phillips Screw Holding Screwdriver, With Wiha-SoftFinish® Handle** Blade CVM steel, hardened, black finish. Clamping sleeve polyamide. SoftFinish® handle cushion grip, impact resistant.

Item No.	Size	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.
39700	0	100	3.9	195	7.6	30	1.18	.13	10
39701	1	125	5.0	230	9.0	36	1.42	.27	10
39702	2	175	7.0	290	11.4	36	1.42	.32	10

**Wiha Screw Holding TORX® Tools**

- Laser welded assembly
- Holds screws securely
- Won't damage screws
- Doesn't weaken tool
- Exact fit tips
- Hardened tool steel blades
- Holds standard Torx screws\*
- Stainless rotary spring

**Screw Holding TORX®**

Laser Welded MagicSpring Assembly



**362 MagicSpring Screw Holding TORX® Screwdriver, With Wiha-SoftFinish® Handle**

Round blade high alloy chrome-vanadium-molybdenum steel, hardened, hard chromed. Wiha-Chromtop finish on tips. Wiha-SoftFinish® handle, multi-component, cushion grips.

Item No.	Size	mm	Inch	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.
36202	T6	60	2.4	3.5	.139	164	6.5	23	.91	.07	10
36203	T7	60	2.4	3.5	.139	164	6.5	23	.91	.07	10
36207	T8	60	2.4	3.5	.139	164	6.5	23	.91	.07	10
36234	T9	60	2.4	4.0	.157	171	6.7	30	1.18	.11	10
36244	T10	80	3.1	4.0	.157	191	7.5	30	1.18	.11	10
36249	T15	80	3.1	4.0	.157	191	7.5	30	1.18	.11	10
36254	T20	100	3.9	4.0	.157	211	8.3	36	1.42	.16	10
36256	T25	100	3.9	4.5	.177	211	8.3	36	1.42	.17	10
36257	T27	115	4.5	5.5	.216	233	9.2	36	1.42	.20	10
36258	T30	115	4.5	6.0	.236	233	9.2	36	1.42	.21	10



**39892 5 Piece Screw Holding Slotted & Phillips Screwdriver Set**

Item No.	Slotted: 2.5x75mm,	lbs.
39892	3.0x100mm, 4.0x125mm	lbs.
	Phillips: 0x100mm, 1x125mm	1.36



**39896 8 Piece Screw Holding Slotted & Phillips Screwdriver Set**

Item No.	Slotted: 2.5x75mm,	lbs.
39896	3.0x100mm, 4.0x125mm,	lbs.
	5.0x150mm, 6.0x175mm	1.80
	Phillips: 0x100mm, 1x125mm,	
	2x175mm	



**36290 Set 6 Pcs. MagicSpring Screw Holding TORX® SoftFinish Screwdrivers**

Round blade high alloy CVM steel, hardened, hard chromed. Wiha-Chromtop finish on tips. Wiha-SoftFinish® handle, multi-component, cushion grips. Molded on.

Item No.	Size	mm	Size	mm	lbs.
36290	T8	60	T20	100	.98
	T10	80	T25	100	
	T15	80	T30	115	

\*MagicSpring tools will hold Torx® screws made to CamCar Textron Torx® specifications



## Wiha TORX® SoftFinish® Screwdrivers



### 362 TORX® Screwdriver, With Wiha-SoftFinish® Handle

Round blade high alloy chrome-vanadium-molybdenum steel, hardened, hard chromed. Wiha-Chromtop finish on tips. Wiha-SoftFinish® handle, multi-component, cushion grips.

Item	⚙️	—	—	⬇️	⬇️	—	—	—	—	⚖️	📦
No.	Size	mm	Inch	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.
36264	T5	60	2.4	2.5	.098	164	6.5	23	.91	.05	10
36266	T6	60	2.4	3.5	.139	164	6.5	23	.91	.06	10
36268	T7	60	2.4	3.5	.139	164	6.5	23	.91	.06	10
36270	T8	60	2.4	3.5	.139	164	6.5	23	.91	.06	10
36272	T9	60	2.4	4.0	.157	171	6.7	30	1.18	.10	10
36274	T10	80	3.1	4.0	.157	191	7.5	30	1.18	.11	10
36276	T15	80	3.1	4.0	.157	191	7.5	30	1.18	.11	10
36278	T20	100	3.9	4.0	.157	211	8.3	36	1.42	.11	10
36280	T25	100	3.9	4.5	.177	211	8.3	36	1.42	.12	10
36282	T27	115	4.5	5.5	.216	233	9.2	36	1.42	.19	10
36284	T30	115	4.5	6.0	.236	233	9.2	36	1.42	.20	10
36286	T40	130	5.1	7.0	.275	254	10.0	41	1.61	.27	10
36288	T45	130	5.1	8.0	.315	254	10.0	41	1.61	.31	10



#36291



### 36291 6 Piece TORX® SoftFinish® -

Cusion Grip Set Round blade high alloy CVM steel, hardened, hard chromed. Wiha-Chromtop finish on tips. Wiha-SoftFinish® handle, multi-component.

Item	⚙️	—	⚙️	—	⚖️
No.	Size	mm	Size	mm	lbs.
36291	T6	60	T9	60	.77
	T7	60	T10	80	
	T8	60	T15	80	

### 36201 Set 6 Pcs. TORX®

Item	⚙️	—	⚙️	—	⚖️
No.	Size	mm	Size	mm	lbs.
36201	T6	60	T15	80	.83
	T8	60	T20	100	
	T10	80	T25	100	



### 36294 8 Piece TORX® Set

Item	TORX®:	⚖️
No.	T6, T8, T10, T15,	lbs.
36294	T20, T25, T27, T30	1.24



### 36267 12 Piece TORX® Set

Item	TORX®:	⚖️
No.	T5, T6, T7, T8, T9,	lbs.
36267	T10, T15, T20, T25, T27, T30, T40	2.03

## Wiha Security TORX® Screwdrivers



**362 Security TORX® Screwdriver With Wiha-SoftFinish® Handle** Round blade high alloy chrome-vanadium-molybdenum steel, hardened, hard chromed. Wiha-Chromtop finish on tips. Wiha-SoftFinish® handle, multi-component, cushion grips.

Item	⚙️	—	—	⬇️	⬇️	—	—	—	—	⚖️	📦
No.	Size	mm	Inch	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.
36269	T7s	60	2.4	3.5	.139	164	6.5	23	.91	.06	10
36271	T8s	60	2.4	3.5	.139	164	6.5	23	.91	.06	10
36273	T9s	60	2.4	4.0	.157	171	6.7	23	.91	.10	10
36275	T10s	80	3.1	4.0	.157	191	7.5	30	1.18	.11	10
36277	T15s	80	3.1	4.0	.157	191	7.5	30	1.18	.11	10
36279	T20s	100	3.9	4.0	.157	211	8.3	30	1.18	.11	10
36281	T25s	100	3.9	4.5	.177	211	8.3	30	1.18	.11	10
36283	T27s	115	4.5	5.5	.216	233	9.2	36	1.42	.19	10
36285	T30s	115	4.5	6.0	.236	233	9.2	36	1.42	.20	10
36287	T40s	130	5.1	7.0	.275	254	10.0	41	1.61	.28	10



### 36298 Set 7 Pcs. Security

Item	Security TORX®:	⚖️
No.	T7s, T8s, T9s, T10s,	lbs.
36298	T15s, T20s, T25s	.95



### 36259 Set 10 Pcs. Security TORX®

Item	Security TORX®:	⚖️
No.	T7s, T8s, T9s, T10s,	lbs.
36259	T15s, T20s, T25s, T27s, T30s, T40s	1.5

**Wiha TORXPlus® Cushion Grip Drivers**



Not for use in standard Torx fasteners


**362 TORXPlus® Screwdriver With Wiha SoftFinish® Handle**

Round blade high alloy Chrome-vanadium-molybdenum tool steel, hardened, hard chromed. Wiha-Chromtop finish on tips.

Item No.	Size	mm	Inch	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.
36211	IP6	60	2.4	3.5	.139	164	6.5	23	.91	.06	10
36223	IP7	60	2.4	3.5	.139	164	6.5	23	.91	.06	10
36228	IP8	60	2.4	4.0	.157	171	6.7	23	.91	.10	10
36229	IP9	60	2.4	4.0	.157	171	6.7	30	1.18	.11	10
36233	IP10	80	3.1	4.0	.157	191	7.5	30	1.18	.11	10
36238	IP15	80	3.1	4.0	.157	191	7.5	30	1.18	.11	10
36239	IP20	100	3.9	4.5	.177	211	8.3	36	1.42	.11	10
36243	IP25	100	3.9	5.5	.216	211	8.3	36	1.42	.19	10
36248	IP27	115	4.5	6.0	.236	233	9.2	36	1.42	.20	10
36253	IP30	115	4.5	7.0	.275	233	9.2	36	1.42	.28	10
36255	IP40	130	5.1	7.0	.275	254	10.0	41	1.61	.28	10

**Soft Grip BiCut SuperCut & Screwdriver Set**



**32644 7 Pc. Soft Grip BiCut SuperCut & Screwdriver Set**  lbs. 1.78

Item No.	BiCut SuperCut:
32644	8.0"/200mm BiCut SuperCut
	<b>Screwdrivers:</b> Phillips: #0, #1, #2
	Slotted: 3.0, 4.0, 6.5mm

**Industrial BiCut SuperCut & Screwdriver Set**



**30942 7 Pc. Industrial BiCut SuperCut & Screwdriver Set**  lbs. 1.86

Item No.	BiCut SuperCut:
30942	8.0"/200mm BiCut SuperCut
	<b>Screwdrivers:</b> Phillips: #0, #1, #2
	Slotted: 3.0, 4.0, 6.5mm



**36297 Set 8 Pcs. TORXPlus® Blade** high alloy CVM steel, hardened, hard chromed.

Wiha-SoftFinish handle, multi-component.

Item No.	Size	mm	Size	mm	lbs.
36297	IP6	60	IP10	80	1.35
	IP7	60	IP15	80	
	IP8	60	IP20	100	
	IP9	60	IP25	100	



**36296 Set 6 Pcs. TORXPlus® Blade** high alloy CVM steel, hardened, hard chromed.

Wiha-SoftFinish handle, multi-component.

Item No.	Size	mm	Size	mm	lbs.
36296	IP6	60	IP9	60	.72
	IP7	60	IP10	80	
	IP8	60	IP15	80	



**36299 Set 7 Pcs. TORXPlus® Blade** high alloy CVM steel, hardened, hard chromed.

Wiha-SoftFinish handle, multi-component.

Item No.	Size	mm	Size	mm	lbs.
36299	IP8	60	IP25	100	1.36
	IP10	80	IP30	115	
	IP15	80	IP40	130	
	IP20	100			

**Wiha Magnetizer/Demagnetizer**

Magnetize or Demagnetize tools and small parts instantly

Shatterproof Box is made from high quality plastic

Uses 2 C8 industrial permanent magnets



(+) to Magnetize

(-) to Demagnetize

**40010 Magnetizer and Demagnetizer**

To magnetize and demagnetize steel screwdriver blades, tweezers and similar tools. Box high quality plastic, shock-resistant, green, cadmium free.

**Application:**

To magnetize, lead tool slowly through the (+) opening, to demagnetize guide tool slowly through the (-) opening.

Item No.	Dimensions	lbs.
40010	2.1" x 2.0" x 1.1"	.30

(Parts under 1" Length or 1/8" Diameter may not demagnetize)





## Wiha MagicRing SoftFinish® Hex Drivers

### Screw Holding Hex Tools



**Don't Drop That Screw!**  
**Save Valuable Time!**  
**Improve Productivity!**  
**Make The Job Easy!**



### 36791 13 Piece MagicRing Inch Ball

**End Screwdriver Set** Hex blade chrome-vanadium-molybdenum steel, hardened, hard chromed. Wiha-SoftFinish® handle, multi-component, cushion grip.

Item No.	Hex	Ball	Hex	Ball	lbs.
36791	.050*	3.0	5/32	5.0	2.58
	1/16*	3.0	3/16	6.0	
	5/64*	4.0	7/32	6.0	
	3/32*	4.0	1/4	6.0	
	7/64*	4.0	5/16	8.0	
	1/8	4.0	3/8	8.0	
	9/64	4.0			

\* Standard Ball - No Ring

**367 MagicRing Ball End Hex-Driver Inch, With Wiha-SoftFinish® Handle** Hex blade, high alloy CVM steel, hardened, hard chromed. SoftFinish® handle, multi-component, cushion grip.

Item No.	Hex	Ball	Hex	Ball	Hex	Ball	Hex	Ball	lbs.	pkg.
36710*	.050	3.1	80	179	7.0	23	.91	.06	10	
36713*	1/16	3.1	80	204	8.0	23	.91	.06	10	
36716*	5/64	3.9	100	204	8.0	23	.91	.07	10	
36719*	3/32	3.9	100	204	8.0	23	.91	.07	10	
36723*	7/64	3.9	100	211	8.3	23	.91	.07	10	
<b>With MagicRing</b>										
36726	1/8	3.9	100	243	9.6	30	1.18	.12	10	
36728	9/64	3.9	100	243	9.6	30	1.18	.12	10	
36732	5/32	5.0	125	271	10.7	30	1.18	.12	10	
36734	3/16	6.0	150	271	10.7	30	1.18	.16	10	
36736	7/32	6.0	150	271	10.7	36	1.42	.23	10	
36738	1/4	6.0	150	271	10.7	36	1.42	.25	10	
36742	5/16	8.0	200	271	10.7	36	1.42	.37	10	
36744	3/8	8.0	200	271	10.7	41	1.61	.54	10	


\* Standard Ball - No Ring



### 36793 8 Piece MagicRing Inch Ball End

**Screwdriver Set** Hex blade CVM steel, hardened, hard chromed. Wiha-SoftFinish® handle, multi-component, cushion grip.

Item No.	Hex	Ball	Hex	Ball	lbs.
36793	1/8	4.0	7/32	6.0	2.25
	9/64	4.0	1/4	6.0	
	5/32	5.0	5/16	8.0	
	3/16	6.0	3/8	8.0	

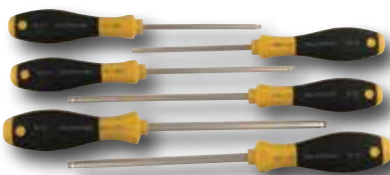

### 36794 6 Piece MagicRing Inch Ball End

**Screwdriver Set** Hex blade CVM steel, hardened, hard chromed. Wiha-SoftFinish® handle, multi-component, cushion grip.

Item No.	Hex	Ball	Hex	Ball	lbs.
36794	1/8	4.0	3/16	6.0	1.34
	9/64	4.0	7/32	6.0	
	5/32	5.0	1/4	6.0	

**Wiha MagicRing SoftFinish® Hex Drivers**

**Screw Holding Hex Tools**



**Don't Drop That Screw!**  
**Save Valuable Time!**  
**Improve Productivity!**  
**Make The Job Easy!**



**367 MagicRing Ball End Hex Driver Metric, With Wiha-SoftFinish® Handle** Hex blade, high alloy CVM steel, hardened, hard chromed. Wiha-SoftFinish® handle, multi-component, cushion grip.

Item No.	mm	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.
36715*	1.5	75	3.0	179	7.0	23	.91	.06	10
36720*	2.0	100	3.9	204	8.0	23	.91	.07	10
36725*	2.5	100	3.9	204	8.0	23	.91	.07	10
<b>With MagicRing</b>									
36730	3.0	100	3.9	204	8.0	23	.91	.07	10
36740	4.0	125	5.0	211	8.3	30	1.18	.12	10
36750	5.0	150	5.0	243	9.6	30	1.18	.16	10
36760	6.0	150	5.0	243	9.6	36	1.42	.23	10
36780	8.0	200	8.0	268	10.6	36	1.42	.37	10
36786	10.0	200	8.0	271	10.7	41	1.61	.54	10

\* Standard Ball - No Ring

Hardened spring steel retaining ring holds screws on

Hard chrome super durable corrosion resistant finish

Precision machined for exact fit

Made from Wiha exclusive CVM hardened tool steel

**36790 9 Piece MagicRing Metric Ball End Hex Screwdriver Set** Hex blade CVM steel, hardened, hard chromed. Wiha-SoftFinish® handle, multi-component, cushion grip.

Item No.	mm	mm	mm	mm	lbs.
36790	1.5*	75	5.0	150	2.06
	2.0*	100	6.0	150	
	2.5*	100	8.0	200	
	3.0	100	10.0	200	
	4.0	125			

\* Standard Ball - No Ring



**36792 6 Piece MagicRing Metric Ball End Hex Screwdriver Set** Hex blade chrome-vanadium-molybdenum steel, hardened, hard chromed. Wiha-SoftFinish® handle, multi-component, cushion grip.

Item No.	mm	mm	mm	mm	lbs.
36792	3.0	100	6.0	150	1.86
	4.0	125	8.0	200	
	5.0	150	10.0	200	



## Wiha SoftFinish® Bit Holders

Magnetic



Retainer out of stainless steel

**384 1/4" Magnetic Bit Holding Drivers, With Wiha SoftFinish® Handle** Ergonomic cushion grip, magnetic, holds bit and screw. Shaft CVM steel, nickel-plated. Pkg. 1

Item	Size	mm	Inch	mm	Inch	lbs.
<b>38450</b>	1/4"	125	5.0	240	9.46	.23
<b>38460</b>	1/4"	300	11.8	400	15.69	.37



For working in confined spaces

**28103 Magnetic 1/4" Bit Holder With Wiha SoftFinish® Stubby Handle** Stainless steel with strong magnet. Wiha-SoftFinish® handle multi-component, cushion grips.

Item	Inch	mm	Inch	lbs.	pkg.
<b>28103</b>	1/4"	57	2.2	.11	1



Plastic coated flexible metal

Stainless steel with retaining ring

**38600 Bit Holder 1/4" with Retaining Ring With Flexible Shaft** Wiha-SoftFinish® handle multi-component, cushion grips.

Item	Inch	mm	Inch	mm	Inch	lbs.	pkg.
<b>38600</b>	1/4"	150	5.9	268	10.6	.30	1

Adjustable Blade Length  
Magnetic Bit Holder



**28489 Drive-Loc VI Bit Holder**

High alloy CVM steel, through hardened, hard chrome finish. Wiha-SoftFinish® handle multi-component, cushion grips.

Item	Inch	Extends	lbs.	pkg.
<b>28489</b>	1/4"	1-3/4" to 4-7/8"	.36	1

## Wiha Interchangeable Tools Magnetize & Demagnetize




**48190 4 Piece Slotted & Phillips Interchangeable Blade Set, In Durable Pouch** Set includes Magnetizer/Demagnetizer handle & 3 interchangeable blades.

Item	lbs.
<b>No. 48190</b>	.62

**Slotted:** 3.0, 4.0, 6.0mm **Phillips:** 0, 1, 2  
Wiha Magnetizer/Demagnetizer Handle

## Switch Cabinet Keys

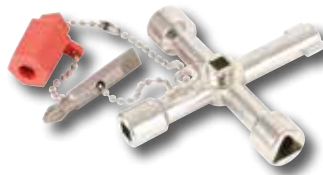

**21103 Switch Cabinet Key** For applications with all common switch cabinets and locking systems. Diecast Zinc

Item No.	mm	Inch	Pkg.	lbs.
<b>21103</b>	76	3.0"	1	.22



**21105 Pen Style Control Cabinet Key**

For applications with all common switch cabinets and locking systems. Diecast Zinc, polished finish. Includes: Square 5, 6, 7, 8mm, Triangular 9mm, Double Bit Key 5mm/Internal & 9mm/External, Universal 1/4" Bit Adapter, Magnetic Bit Holder & 2 Double Insert Bits: Slotted 7mm / Phillips #2 / TORX T20/T25

Item No.	mm	Inch	Pkg.	lbs.
<b>21105</b>	140	5.5"	1	.30


## Dynamic Series Drivers Slotted & Phillips



**Rotating cap** prevents user discomfort and blisters - even at high pressure and high torque

Allows rapid rotation

**Ergonomic Handle shape** for user comfort

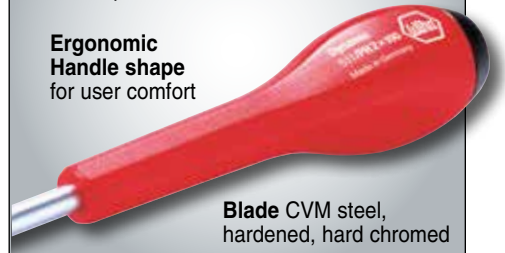

**Blade CVM steel, hardened, hard chromed**



**51099 11 Piece Slotted & Phillips Set, Wiha-Dynamic Handle**

Item	Slotted:	Phillips:	lbs.
<b>No.</b>	2.0, 2.5, 3.0, 3.5, 4.0, 5.5, 6.5, 8.0mm	0, 1, 2	1.3



**Wiha 3K Series Screwdrivers and Sets**

**3K Ergonomic Series Screwdrivers & Sets**

Blades made of CVM tool steel, chromed shaft

Exact fit precision machined black tips

Hole in handle for hanging

Dual material handle has molded soft grip panels



Dual material handle has molded soft grip panels



 
 
 


 

Blades made of CVM tool steel, chromed shaft

Exact fit precision machined black tips

**Wiha 3K Series Bit Holder**






**48401 1/4" Bit holding Screwdriver, With Wiha-Ergo 3K Handle** Magnetic, holds bit & screw. Retainer out of stainless steel. Shaft CVM tool steel, nickel plated.

Item									
No.	Size	mm	Inch	mm	Inch	lbs.	pkg.		
48401	1/4"	125	5.0	211	8.3	.24	1		








**46790 30 Piece Ball End Hex & TORX®, Workstation Screwdriver Set** Blade CVM steel, hardened. Steel stand

Item		Ball End Hex Inch:
No.		1/4, 5/64, 3/32, 7/64, 1/8, 9/64,
46790		5/32, 3/16, 7/32, 1/4, 5/16"
Item		Ball End Hex Metric:
lbs.		1.5, 2.0, 2.5, 3.0, 4.0, 5.0,
8.96		6.0, 8.0, 10.0mm
		TORX®: T6, T7, T8, T9, T10, T15, T20, T25, T27, T30



 

 

 
 
 


**46099 40 Piece Slotted, Phillips, TORX®, Pozidriv®, Bit Holder & Folding Ruler** Blade CVM steel, hardened. With 16" tool box

Item		Slotted:
No.		2.5, 3.0, 3.5, 4.0, 4.5x100,
46099		4.5x150, 4.5x200, 5.5, 6.0x100,
		6.0x150, 6.0x200, 6.5x40,
lbs.		6.5x150, 8.0, 10mm
10.4		Phillips: 0x60, 1x80, 1x200,
		2x100, 2x150, 2x200, 2x40, 3x150
		TORX®: T6, T7, T8, T9, T10, T15,
		T20, T25, T27, T30, T40, T45, T50
		Pozidriv®: 1x80, 2x100
		3K 1/4" Magnetic Bit Holder
		61601 Folding Ruler

**Wiha 3K Series Square Tip Screwdrivers**




**458 Square Tip Screwdriver, With Wiha-3K Series Handle** Blade CVM steel, hard chromed shaft. Wiha-3k Ergo handle, cushion grip. Black tip.

Item									
No.	Size	mm	Inch	mm	Inch	lbs.	lbs.		
45831	1	80	3.1	187	7.3	.14			
45832	2	100	3.9	210	8.3	.16			
45833	3	150	5.9	271	10.7	.24			



**45891 3 Pc. Square Tip 3K Driver Set** Blade CVM, chrome nickel-plated. Wiha-3k Ergo handle, cushion grip. Precision black tips.

Item	Slotted:		lbs.
No. 45891	#1, 2, 3		.52



## Wiha 3K Series Screwdrivers and Sets



**450 Slotted Screwdriver, With Wiha-3K Series Handle** Blade chrome-vanadium-molybdenum steel, chrome nickel-plated. Wiha-3K Ergo handle, cushion grip. Precision black tips.

Item No.	mm	Inch	mm	Inch	mm	Inch	mm	Inch	lbs.	Pkg.
45040**	2.5	.10	75	3.0	0.4	.02	161	6.3	.06	10
45050**	3.0	.12	100	3.9	0.5	.02	185	7.3	.07	10
45052**	3.5	.14	100	3.9	0.6	.02	197	7.7	.09	10
45054**	4.0	.16	100	3.9	0.8	.03	206	8.1	.12	10
45055	4.5	.18	100	3.9	1.0	.04	207	8.1	.13	10
45056	4.5	.18	150	5.9	1.0	.04	257	10.1	.14	10
45057	4.5	.18	200	8.0	1.0	.04	306	12.0	.15	10
45058	5.5	.22	125	5.0	1.0	.04	243	9.5	.19	10
45060	6.0	.24	100	3.9	0.9	.04	218	8.5	.20	10
45061	6.0	.24	150	5.9	0.9	.04	268	10.5	.23	10
45062	6.0	.24	200	8.0	0.9	.04	318	12.5	.25	10
45064*	6.5	.24	40	1.6	1.2	.05	90	3.5	.08	10
45065	6.5	.24	150	5.9	1.2	.05	268	10.5	.23	10
45067	8.0	.32	150	5.9	1.2	.05	268	10.5	.26	10
45069	10.0	.39	200	8.0	1.6	.06	318	12.5	.35	10

\* Stubby screwdriver with Wiha Powerhandle - 45064  
 \*\* Cabinet Tip



**451 Phillips Screwdriver, With Wiha-3K Series Handle** pkg. 10

Item No.	mm	mm	Inch	mm	Inch	lbs.
45135	0	60	2.4	145	5.7	.06
45137	1	80	3.1	187	7.3	.13
45140	1	200	8.0	307	12.0	.16
45142	2	100	3.9	218	8.5	.21
45144	2	150	5.9	268	10.5	.23
45147	2	200	8.0	318	12.5	.25
45150*	2	40	1.6	90	3.5	.08
45152	3	150	5.9	268	10.5	.31

\* Stubby screwdriver with Wiha Powerhandle - 45150

1/4" Insert Bits



**45190 18 Pc. Phillips 3K Driver & Bit Set**

**Item No. Screwdrivers:** #0x60, #1x80, #1x200, #2x100, #2x150, #2x200, #3x150mm  
**Insert Bits:** #0(2), #1(2), #2(4), #3(2)  
 lbs. 1.62 **Stubby Phillips:** #2x40mm



**46098 4 Pc. Slotted/Phillips 3K Driver Set**  
 Blade CVM, chrome nickel-plated. Wiha-3K Ergo handle, cushion grip. Precision black tips.

Item No.	Slotted:	lbs.
46098	4.5, 6.0mm	.83

Phillips: #1, 2



**46095 5 Pc. Slotted/Phillips 3K Driver Set**

Item No.	Slotted:	lbs.
46095	4.5, 6.0mm	1.04

Phillips: #0, 1, 2



**46094 6 Pc. Slotted/Phillips 3K Driver Set**

Item No.	Slotted:	lbs.
46094	3.0, 4.5, 5.5, 6.5mm	.91

Phillips: #1, 2



**46097 8 Pc. Slotted/Phillips 3K Driver Set**

Item No.	Slotted:	lbs.
46097	3.0, 4.5, 6.0, 8.0mm	1.70

Phillips: #1, 2, 3  
 Stubby Phillips: #2

**Wiha TORX® 3K Series Drivers and Sets**



**455 TORX® Screwdriver, With Wiha-3K Series Handle** Blade high alloy CVM steel, hardened, precision black tip. Molded on ergonomic Wiha-3K Series handle, impact resistant.

Item No.	Size	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.
45504	T6	60	2.4	3.2	9/64	145	5.7	.06	10
45507	T7	60	2.4	3.5	9/64	129	5.1	.05	10
45508	T8	60	2.4	3.5	9/64	139	5.5	.06	10
45509	T9	60	2.4	4.0	5/32	149	5.8	.08	10
45510	T10	80	3.1	4.0	5/32	170	6.7	.10	10
45515	T15	80	3.1	4.0	5/32	190	7.5	.11	10
45520	T20	100	3.9	5.5	7/32	215	8.4	.11	10
45525	T25	100	3.9	6.0	1/4	215	8.4	.20	10
45527	T27	115	4.5	7.0	9/32	240	9.4	.28	10
45530	T30	115	4.5	6.0	1/4	233	9.1	.21	10
45540	T40	130	5.1	7.0	9/32	248	9.7	.25	10
45545	T45	130	5.1	8.0	5/16	249	9.8	.30	10
45550	T50	130	5.1	9.0	3/8	249	9.8	.33	10



**45593 5 Pc. TORX® Set** Blade CVM steel, hardened, precision black tip. Wiha-3k Ergo handle, cushion grip.

Item No.	TORX® :	lbs.
45593	T8, T10, T15, T20, T25	.86



**45597 11 Pc. TORX® Screwdriver Set**

Item No.	TORX®:	lbs.
45597	T6, T7, T8, T9, T10, T15, T20, T25, T27, T30, T40	1.88



**45595 8 Pc. TORX® Screwdriver Set**

Item No.	TORX®:	lbs.
45595	T8, T9, T10, T15, T20, T25, T27, T30	1.36



**45598 6 Pc. TORX® Screwdriver Set**

Item No.	TORX®:	lbs.
45598	T6, T7, T8, T9, T10, T15	.88

**Wiha 3K Series Pozidriv® Screwdrivers**



**452 Pozidriv® Screwdriver, With Wiha-3K Series Handle** Blade CVM steel, hard chromed shaft. Wiha-3k Ergo handle, cushion grip. Black tip.

Item No.	Size	mm	Inch	mm	Inch	lbs.	pkg.
45205	0	60	2.4	146	5.7	.06	10
45207	0	100	3.9	186	7.3	.07	10
45215	1	80	3.1	187	7.3	.13	10
45220	1	100	3.9	207	8.1	.14	10
45225	2	100	3.9	219	8.6	.21	10
45230	2	150	5.9	269	10.6	.23	10
45235	3	150	5.9	269	10.6	.31	10





## Wiha Ball End 3K Series Screwdrivers & Sets



Fast angle entry

- Soft panel grip
- Convenient hang hole
- Hardened CVM tool steel
- Exact fit precision machined tips

Yellow = Inch  
Red = Metric



### 467 Ball End Hex Metric Screwdriver, With Wiha-3K Ergo Handle

Blades of CVM special steel, hardened, black finish. Molded on Wiha-3K Ergo soft grip handles.


Item	Hex	mm	Inch	mm	Inch	lbs.	pkg.
46715	1.5	75	3.0	161	6.3	.07	10
46720	2.0	100	3.9	186	7.3	.07	10
46725	2.5	100	3.9	186	7.3	.07	10
46730	3.0	100	3.9	186	7.3	.07	10
46740	4.0	100	3.9	197	7.8	.11	10
46750	5.0	100	3.9	197	7.8	.13	10
46760	6.0	150	5.9	257	10.1	.21	10
46780	8.0	200	8.0	307	12.1	.34	10
46786	10.0	200	8.0	319	12.6	.52	10



### 467 Ball End Hex Inch Drivers, With 3K Ergo Soft Grip Handles

Blades of CVM special steel, hardened, black finish. Molded on Wiha-3K Ergo soft grip handles.


Item	Hex	Inch	mm	Inch	mm	lbs.	pkg.
46702	.050	2.9	75	6.3	160	.07	10
46704	1/16	2.9	75	6.3	160	.07	10
46706	5/64	3.9	100	7.3	185	.07	10
46708	3/32	3.9	100	7.3	185	.07	10
46710	7/64	3.9	100	7.3	185	.07	10
46712	1/8	3.9	100	7.7	196	.09	10
46714	9/64	3.9	100	7.7	196	.10	10
46716	5/32	3.9	100	7.7	196	.11	10
46718	3/16	3.9	100	7.7	196	.12	10
46722	7/32	5.9	150	10.0	254	.19	10
46724	1/4	5.9	150	10.0	254	.22	10
46726	5/16	7.9	200	12.0	305	.34	10
46728	3/8	7.9	200	12.5	318	.48	10

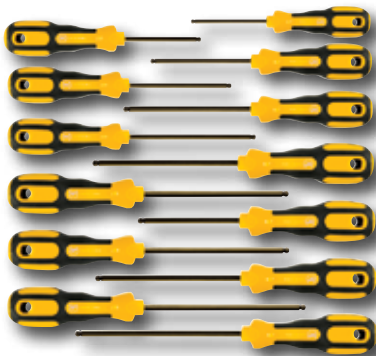

### 46797 13 Piece 3K Ergo Inch Ball End Hex Screwdriver Set


Blades of CVM special steel, hardened, black finish. Molded on Wiha-3K Ergo soft grip handles.

Item	Hex Inch:	lbs.
No.	1/16, 5/64, 3/32, 7/64	2.40
46797	1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	2.40

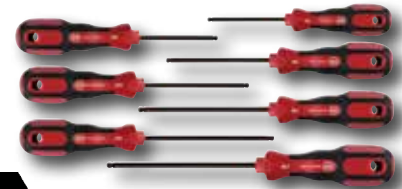


### 46796 7 Piece Metric Ball End Hex Screwdriver Set

Item	Metric Hex:	lbs.
No.	1.5, 2.0, 2.5, 3.0,	1.15
46796	4.0, 5.0, 6.0mm	1.15

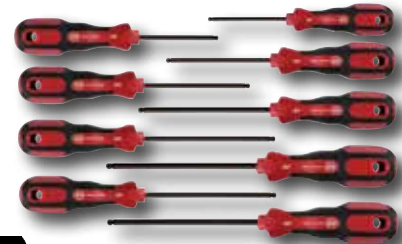

### 46799 9 Piece Metric Ball End Hex Screwdriver Set

Item	Hex Metric:	lbs.
No.	1.5, 2.0, 2.5, 3.0, 4.0,	1.93
46799	5.0, 6.0, 8.0, 10.0mm	1.93

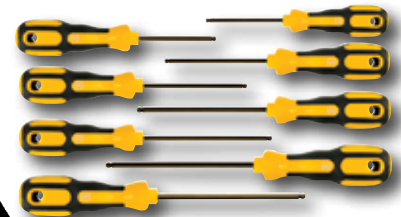

### 46793 8 Piece 3K Ergo Inch Ball End Hex Screwdriver Set

Item	Hex Inch:	lbs.
No.	.050, 1/16, 5/64, 3/32,	1.19
46793	7/64, 1/8, 9/64, 5/32"	1.19



### 46794 6 Piece 3K Ergo Inch Ball End Hex Screwdriver set

Item	Hex Inch:	lbs.
No.	1/8, 9/64, 5/32,	.97
46794	3/16, 7/32, 1/4"	.97

Wiha Drive-Loc VI Handles & Blades

For Adjustable Length Locking Blades



Ergonomic handles in ESD Safe, cushioned & non-slip grip

See Drive-Loc VI Nut drivers on Page 42

Blade length can be adjusted from 1.7 to 4.7" in 1/8" increments

Blades high quality CVM steel, hard chrome finish

Adjust interchangeable blades from 40 to 120mm

Drive-Loc mechanism guarantees a secure hold & rapid blade exchange



28488 Drive-Loc VI Cushion Grip Handle

Wiha-SoftFinish® impact resistant, with roll off protection.

Item						
No.	mm	mm	Inch	mm	Inch	lbs.
28488	6.0	115	4.5	36.0	1.41	.26



28486 ESD Safe Drive-Loc VI Cushion Grip Handle Wiha-SoftFinish® impact resistant, with roll off protection.

Item						
No.	mm	mm	Inch	mm	Inch	lbs.
28486	6.0	115	4.5	36.0	1.41	.21



28487 Drive-Loc VI MicroFinish Non-Slip Grip Handle Wiha-MicroFinish handle, won't peel, crack or deteriorate when exposed to petroleum solvents.

Item						
No.	mm	mm	Inch	mm	Inch	lbs.
28487	6.0	115	4.5	36.0	1.41	.20



10810 Drive-Loc VI Standard Narrow Profile Tech Handle Dynamic non-locking, impact resistant, friction hold. Fits all Drive-Loc blades. Does not have locking feature.

Item						
No.	mm	mm	Inch	mm	Inch	lbs.
10810	6.0	135	5.3	15.2	.60	.16



281 Slotted Drive-Loc VI Interchangeable Blade

High alloy CVM steel, through hardened, hard chrome finish. OAL 150mm/5.9". Blades fit all Drive-Loc VI handles.

Item				
No.	mm + mm	lbs.	pkg.	
28106	3.5 4.5	.10	1	
28108	5.5 6.5	.10	1	



281 Slotted & Phillips Drive-Loc VI Interchangeable Blade High alloy CVM steel, through hardened, hard chrome finish. OAL 150mm/5.9". Blades fit all Drive-Loc VI handles.

Item				
No.	mm + Size	lbs.	pkg.	
28107	3.0 0	.10	1	
28109	4.0 1	.10	1	
28110	6.0 2	.10	1	



28112 Phillips Drive-Loc VI Interchangeable Blade High alloy CVM steel, through hardened, hard chrome finish. OAL 150mm/5.9". Blades fit all Drive-Loc VI handles.

Item				
No.	Size + Size	lbs.	pkg.	
28112	1 2	.10	1	



28137 Square Drive-Loc VI Interchangeable Blade High alloy CVM steel, through hardened, hard chrome finish. OAL 150mm/5.9". Blades fit all Drive-Loc VI handles.

Item				
No.	Size + Size	lbs.	pkg.	
28137	1 2	.10	1	



28114 Pozidriv® Drive-Loc VI Interchangeable Blade High alloy CVM steel, through hardened, hard chrome finish. OAL 150mm/5.9". Blades fit all Drive-Loc VI handles.

Item				
No.	Size + Size	lbs.	pkg.	
28114	1 2	.10	1	



281 Tri-wing® Drive-Loc VI Interchangeable Blade High alloy CVM steel, through hardened, hard chrome finish. OAL 150mm/5.9". Blades fit all Drive-Loc VI handles.

Item				
No.	Size + Size	lbs.	pkg.	
28138	0 1	.10	1	
28139	2 3	.10	1	
28140	4 5	.10	1	



281 Torq Set® Drive-Loc VI Interchangeable Blade High alloy CVM steel, through hardened, hard chrome finish. OAL 150mm/5.9". Blades fit all Drive-Loc VI handles.

Item				
No.	Size + Size	lbs.	pkg.	
28142	2 4	.08	1	
28143	6 8	.10	1	



281 TORX® Drive-Loc VI Interchangeable Blade OAL 150mm/5.9"

Item				
No.	Size + Size	lbs.	pkg.	
28126	T6 T8	.10	1	
28127	T7 T9	.10	1	
28128	T10 T15	.10	1	
28129	T20 T25	.10	1	
28130	T30 T40	.10	1	



281 Security TORX® Drive-Loc VI Interchangeable Blade OAL 150mm/5.9"

Item				
No.	Size + Size	lbs.	pkg.	
28132	T6s T8s	.10	1	
28133	T7s T9s	.10	1	
28134	T10s T15s	.10	1	
28135	T20s T25s	.10	1	
28136	T30s T40s	.10	1	

## Wiha Drive-Loc VI Blades



**281 Hex Metric Drive-Loc VI Interchangeable Blade** OAL 150mm/5.9"

Item	mm	mm	lbs.	pkg.
No. 28149	2.0	2.5	.09	1
28150	3.0	4.0	.10	1
28151	5.0	6.0	.10	1



**281 Hex Inch Drive-Loc VI Interchangeable Blade** OAL 150mm/5.9"

Item	Inch	Inch	lbs.	pkg.
No. 28122	3/32	7/64	.10	1
28123	1/8	9/64	.10	1
28124	5/32	3/16	.10	1



**281 Ball End Hex & Hex Metric Drive-Loc VI Interchangeable Blade** Ball end enables the user to work at angles up to 25°. OAL 150mm/5.9". Fits all Drive-Loc VI handles.


Item	mm	mm	lbs.	pkg.
No. 28116	2.5	2.5	.10	1
28117	3	3	.10	1
28118	4	4	.10	1
28119	5	5	.10	1
28120	6	6	.10	1

## Drive-Loc VI Interchangeable Blade Sets



**28187 32 Pc. ESD Safe Drive-Loc VI Interchangeable Blade Set, In Canvas Pouch** Set includes Drive-Loc VI handle & 31 interchangeable blades.

<b>Item No. 28187</b>	lbs.	3.66
<b>Slotted:</b>	3.5+4.5, 5.5+6.5mm	<b>Square:</b> 1+2
<b>Slotted/Phillips:</b>	3.0+0, 4.0+1, 6.0+2	
<b>Security TORX®:</b>	T6s+T8s, T7s+T9s, T10s+T15s, T20s+T25s, T30s+T40s	
<b>Hex Inch:</b>	3/32+7/64, 1/8+9/64, 5/32+3/16	
<b>Hex Metric:</b>	2.0+2.5, 3.0+4.0, 5.0+6.0	
<b>Nut Drivers In:</b>	1/4, 9/32, 5/16, 11/32, 3/8, 7/16, 1/2"	
<b>Nut Drivers MM:</b>	5.5, 6.0, 7.0, 8.0, 9.0, 10.0, 11.0mm	
Wiha ESD Safe SoftFinish® Cushion Grip		

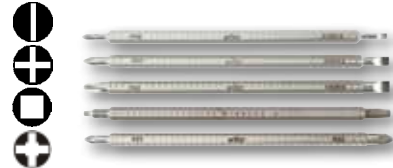

**28483 5 Pack Drive-Loc VI Interchangeable Blade Set** OAL 150mm/5.9"

<b>Item</b>	lbs.
No. 28483	.35
<b>Slotted/Phillips:</b>	3.0+#0, 4.0+#1, 6.0+#2
<b>Square:</b>	#1+#2 & Pozidriv®: #1+#2



**28479 5 Pack Drive-Loc VI Interchangeable Blade Set** OAL 150mm/5.9"

<b>Item</b>	lbs.
No. 28479	.35
<b>Tri-Wing:</b>	#0+#1, #2+#3, #4+#5
<b>Torq Set:</b>	#2+#4, #6+#8



**28477 5 Pack Drive-Loc VI Interchangeable Blade Set** OAL 150mm/5.9"

<b>Item</b>	lbs.
No. 28477	.35
<b>Security TORX®:</b>	T6s+T8s, T7s+T9s, T10s+T15s, T20s+T25s, T30s+T40s

## Wiha Drive-Loc VI Blade 5 Pack Sets



**28474 5 Pack Drive-Loc VI Interchangeable Blade Set** OAL 150mm/5.9"

<b>Item</b>	lbs.
No. 28474	.36
<b>Hex Metric:</b>	3.0+4.0, 5.0+6.0mm
<b>Hex Inch:</b>	3/32+7/64, 1/8+9/64, 5/32+3/16"



**28476 5 Pack Drive-Loc VI Interchangeable Blade Set** OAL 150mm/5.9"

<b>Item</b>	lbs.
No. 28476	.36
<b>Hex Metric:</b>	2.5, 3.0, 4.0, 5.0, 6.0mm




**28485 5 Pack Drive-Loc VI Interchangeable Blade Set** OAL 150mm/5.9"

<b>Item No. 28485</b>	lbs.
<b>TORX®:</b>	.35
<b>T6+T8, T7+T9, T10+T15, T20+T25, T30+T40</b>	

## Drive-Loc VI Interchangeable Blade Set In Tool Box Tray



Tool box set in blow molded tray

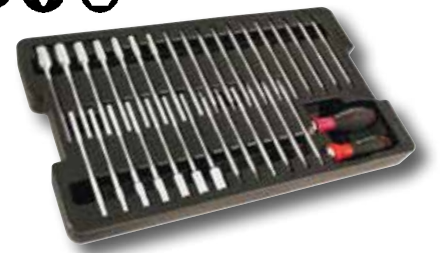


**28191 33 Pc. Drive-Loc VI Interchangeable Blade Set, In Tool Box Tray** Set includes Drive-Loc VI handles & 31 Drive-Loc VI blades.

<b>Item No. 28191</b>	lbs.	3.48
<b>Slotted:</b>	3.5+4.5, 5.5+6.5mm	<b>Square:</b> 1+2
<b>Slotted/Phillips:</b>	3.0+0, 4.0+1, 6.0+2	
<b>Security TORX®:</b>	T6s+T8s, T7s+T9s, T10s+T15s, T20s+T25s, T30s+T40s	
<b>Hex Inch:</b>	3/32+7/64, 1/8+9/64, 5/32+3/16	
<b>Hex Metric:</b>	2.0+2.5, 3.0+4.0, 5.0+6.0	
<b>Nut Drivers In:</b>	1/4, 9/32, 5/16, 11/32, 3/8, 7/16, 1/2"	
<b>Nut Drivers MM:</b>	5.5, 6.0, 7.0, 8.0, 9.0, 10.0, 11.0mm	
Wiha SoftFinish® Cushion Grip & MicroFinish Non-Slip Grip Handles		





**28194 5 Pc. Drive-Loc VI Interchangeable Blade Set, In Durable Pouch** Set includes Drive-Loc VI handle & 4 interchangeable blades.

**Item No. 28194**     lbs.


**Slotted:** 3.5+4.5, 5.5+6.5    **.80**

**Phillips:** 1+2    **Square:** 1+2

SoftFinish® Cushion Grip Blade Lock Handle



**28197 6 Pc. Drive-Loc VI Interchangeable Blade Set, In Durable Pouch** Set includes Drive-Loc VI handle & 5 interchangeable blades.

**Item**     lbs.


**No. 28197**    **.83**

**Security TORX®:** T6s+T8s, T7s+T9s, T10s+T15s, T20s+T25s, T30s+T40s

SoftFinish® Cushion Grip Blade Lock Handle



**28199 10 Pc. Drive-Loc VI Interchangeable Blade Set, In Durable Pouch** Set includes Drive-Loc VI handle & 9 interchangeable blades.

**Item No. 28199**     lbs.

**Slot/Ph:** 4.0+1, 6.0+2    **1.11**


**TORX®:** T6+T8, T7+T9, T10+T15, T20+T25

**Hex Inch:** 3/32+7/64, 1/8+9/64, 5/32+3/16"

SoftFinish® Cushion Grip Blade Lock Handle



**28189 15 Pc. Drive-Loc VI Interchangeable Blade Set, In Durable Pouch** Set includes Drive-Loc VI handle & 14 interchangeable blades.

**Item No. 28189**     lbs. 1.75

**Slotted:** 3.5+4.5, 5.5+6.5    **Phillips:** 1+2

**Security TORX®:** T6s+T8s, T7s+T9s, T10s+T15s, T20s+T25s, T30s+T40s

**Hex Inch:** 3/32+7/64, 1/8+9/64, 5/32+3/16

**Hex Metric:** 2.0+2.5, 3.0+4.0, 5.0+6.0mm

SoftFinish® Cushion Grip Blade Lock Handle

**Wiha MicroFinish Handle - Non-Slip Grip**

**Wiha MicroFinish handle** has a patented non-slip surface - It won't peel, crack or deteriorate when exposed to petroleum solvents. Oil and moisture flow away from the handle surface for a powerful, non-slip grip. Get maximum force & comfort with dry, oily or wet hands.

 
Safe, high density material, eliminates risk of sharp objects becoming embedded in the handle

Through hardened blades & hard chrome finish

Exact fit precision ground tips

 
 
 
 
 
 
 
 

 
 


CVM, hardened & tempered tool steel blade, gives exceptional tool life, wear resistance & high torque performance

Hex bolster & steel strike cap on 533 & 534 series



**520 Slotted Screwdriver, With Wiha-MicroFinish Handle**

 
 

 
 
 





 
Blade high alloy chrome-vanadium-molybdenum steel, hardened, hard chromed. Wiha-MicroFinish handle, cellulose-acetate, impact resistant, non-slip, oil and grease resistant. Round blades.

Item													
No.	mm	Inch	mm	Inch	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.	
52005*	4.0	.157	100	3.9	0.8	.031	211	8.3	30	1.18	.16	10	
52010*	4.0	.157	150	5.9	0.8	.031	261	10.3	30	1.18	.17	10	
52020*	5.5	.216	125	5.0	1.0	.039	236	9.3	30	1.18	.20	10	
52025*	5.5	.216	150	5.9	1.0	.039	261	10.3	30	1.18	.21	10	
52035	6.5	.255	150	5.9	1.2	.047	268	10.6	36	1.42	.28	10	
52040	8.0	.315	150	5.9	1.2	.047	274	10.8	41	1.61	.37	10	
52050	10.0	.393	200	8.0	1.6	.063	324	12.8	41	1.61	.50	10	

\*Cabinet Tips




**521 Phillips Screwdriver, With Wiha-MicroFinish Handle**

Item												
No.	Size	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.			
52105	1	80	3.1	191	7.5	30	1.18	.15	10			
52110	1	200	8.0	311	12.2	30	1.18	.21	10			
52115	2	100	3.9	218	8.6	36	1.42	.26	10			
52120	2	200	8.0	318	12.5	36	1.42	.34	10			
52125	3	150	5.9	274	10.8	41	1.61	.41	10			




**52090 5 Piece Slotted & Phillips**

**Screwdriver Set** Blade CVM steel, hardened, hard chromed.

Item	Slotted: 4.0x100,	
No.	5.5x125, 8.0x150mm	lbs.
52090	Phillips: 1x80, 2x100mm	1.23




**52099 12 Piece MicroFinish® Slotted & Phillips Screwdriver Set**

Item	Slotted: 4.0x100,	
No.	4.0x150, 5.5x125,	lbs.
52099	5.5x150, 6.5x150,	4.20
	8.0x150, 10.0x200mm	
	Phillips: 1x80, 1x200,	
	2x100, 2x200, 3x150mm	

 


**52097 7 Pc. Slotted/Phillips Screwdriver Set**

Item	Slotted: 4.0x100,	
No.	5.5x125, 8.0x150mm	lbs.
52097	Phillips: #1x80, #1x200,	1.35
	#2x100, #2x200mm	



**52098 8 Pc. Slotted/Phillips Screwdriver Set**

Item No.	Slotted: 4.0x100, 5.5x125	
52098	6.5, 8.0x150, 10.0x200mm	lbs. 2.58
	Phillips: 1x80, 2x100, 3x150mm	



## Wiha MicroFinish Extra Heavy Duty Non-Slip Grip Handle



### 533 Heavy Duty Slotted Screwdriver, Wiha-MicroFinish Handle & Steel Striking Cap

Blade high alloy chrome-vanadium-molybdenum steel, hardened, hard chromed. Hex blade extending through handle with striking plate. Hex bolster for additional torque. Wiha-MicroFinish handle, cellulose-acetate, impact resistant, non-slip, oil and grease resistant.

Item	↓	↓	←	←	⊖	⊖	←	←	⊕	⊕	↔	↔
No.	mm	Inch	mm	Inch	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.
53310*	4.5	.177	90	3.6	1.0	.039	201	7.9	30	1.18	.20	10
53315	5.5	.216	100	3.9	1.0	.039	213	8.4	36	1.42	.33	10
53320	6.5	.255	125	5.0	1.2	.047	238	9.4	36	1.42	.38	10
53325	8.0	.315	150	5.9	1.2	.047	271	10.7	41	1.61	.61	10
53330	10.0	.393	175	7.0	1.6	.063	296	11.7	41	1.61	.65	10

\*No hex bolster



### 534 Heavy Duty Phillips Screwdriver, Wiha-MicroFinish Handle & Steel Striking Cap

Blade high alloy chrome-vanadium-molybdenum steel, hardened, hard chromed. Hex blade extending through handle with striking plate. Hex bolster for additional torque. Wiha-MicroFinish handle, cellulose-acetate, impact resistant, non-slip, oil and grease resistant.

Item	⊕	←	←	←	←	⊕	⊕	↔	↔
No.	Size	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.
53405	1	80	3.1	186	7.3	30	1.18	.22	10
53410	2	100	3.9	213	8.4	36	1.42	.37	10
53425	3	150	5.9	268	10.6	41	1.61	.71	10



### 53390 5 Pc. Slotted/Phillips, Heavy Duty Set

Blade CVM steel, hardened, hard chromed. Hex blade extending through handle with steel striking cap. Hex bolster for additional torque.

Item	Slotted:	↔
No.	5.5, 6.5, 8.0mm	lbs.
53390	Phillips: #1, 2	2.1



### 53398 8 Pc. Slotted/Phillips, Heavy Duty Set

Blade CVM steel, hardened, hard chromed. Hex blade extending through handle with steel striking cap. Hex bolster for additional torque.

Item	Slotted: 4.5*, 5.5,	↔
No.	6.5, 8.0, 10.0mm	lbs.
53398	Phillips: #1, 2, 3	3.7

\*No hex bolster



### 52790 Set 5 Pcs. TORX® Blade CVM steel,

hardened, round blades hard chromed. Wiha-MicroFinish handle, cellulose-acetate, impact resistant, non-slip, oil & grease resistant.

Item	TORX®	↔
No.	T10, T15, T20,	lbs.
52790	T25, T30	1.0

## Wiha TORX® MicroFinish Handle Non-Slip Grip



527 TORX® Screwdriver, With Wiha-MicroFinish Handle Blade high alloy chrome-vanadium-molybdenum steel, hardened, hard chromed. Wiha-MicroFinish handle, cellulose-acetate, impact resistant, non-slip, oil and grease resistant. Round blades.

Item	⊕	←	←	⊖	⊖	←	←	⊕	⊕	↔	↔
No.	Size	mm	Inch	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.
52711	T9	60	2.4	4.0	.157	171	6.7	30	1.18	.15	10
52713	T10	80	3.1	4.0	.157	191	7.5	30	1.18	.15	10
52716	T15	80	3.1	4.0	.157	191	7.5	30	1.18	.15	10
52719	T20	100	3.9	4.0	.157	211	8.3	30	1.18	.15	10
52722	T25	100	3.9	4.5	.177	211	8.3	30	1.18	.16	10
52726	T27	115	4.5	5.5	.216	233	9.2	36	1.42	.25	10
52729	T30	115	4.5	6.0	.236	233	9.2	36	1.42	.27	10
52732	T40	130	5.1	7.0	.275	254	10.0	41	1.61	.40	10



52791 Set 8 Pcs. TORX® Blade CVM steel, hardened, round blades hard chromed. Wiha-MicroFinish handle, cellulose-acetate, impact resistant, non-slip, oil & grease resistant.

Item	TORX® : T9, T10,	↔
No.	T15, T20, T25,	lbs.
52791	T27, T30, T40	1.89



52650 1/4" Bit holding Screwdriver, With Wiha-MicroFinish Handle Magnetic, holds bit and screw. Retainer out of stainless steel. Shaft chrome-vanadium steel, nickel-plated.

Item	⊖	←	←	←	↔	↔	
No.	Size	mm	Inch	mm	Inch	lbs.	pkg.
52650	1/4	125	5.0	244	9.6	.24	10



## Wiha MicroFinish Non-Slip Grip Bit Holder

Wiha Powerhandle TORX® Made in Germany



**362 TORX® Screwdriver, With Wiha-Powerhandle** CVM steel blade, hardened, hard chromed. Wiha-powerhandle cellulose-acetate.

Item No.	Size	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.
36205	T5	50	2.0	2.5	.098	110	4.3	.03	10
36210	T6	50	2.0	3.5	.139	125	4.9	.06	10
36212	T7	50	2.0	3.5	.139	125	4.9	.06	10
36215	T8	60	2.4	3.5	.139	135	5.3	.06	10
36220	T9	60	2.4	4.0	.157	140	5.5	.09	10
36225	T10	80	3.1	4.0	.157	170	6.7	.13	10
36230	T15	80	3.1	4.0	.157	170	6.7	.13	10
36235	T20	100	3.9	4.0	.157	200	7.9	.17	10
36240	T25	100	3.9	4.5	.177	200	7.9	.18	10
36245	T27	115	4.5	5.5	.216	215	8.5	.20	10
36250	T30	115	4.5	6.0	.236	225	8.9	.28	10



**36292 8 Pc. Set TORX®** Blade high alloy CVM steel, hardened, hard chromed. Wiha-powerhandle cellulose-acetate, impact resistant.

Item No.	T6, T8, T10, T15,	lbs.
36292	T20, T25, T27, T30	1.45



**36293 6 Pc. Set TORX®**

Item No.	T6, T7, T8, T9,	lbs.
36293	T10, T15	.78

Wiha TORX® Protturn Screwdrivers

**protturn**  
TORX®

Through hardened for optimum wear resistance

Molded on ergonomic handle proportioned to blade sizes

High performance tool steel blades




**45589 Set 11 Pcs. TORX®**

Item No. TORX® :	T6, T7x50mm, T8, T9x60mm, T10, T15x80mm, T20, T25x100mm, T27, T30x115mm, T40x130mm
------------------	--




**45591 Set 6 Pcs. TORX®**

Item No.	TORX® :	lbs.
45591	T7, T8, T9, T10, T15, T20	.72

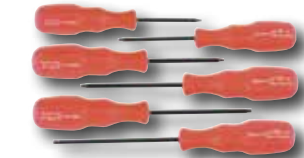

**45592 Set 8 Pcs. TORX®**

Item No.	T8, T9, T10, T15,	lbs.
45592	T20, T25, T27, T30	1.10

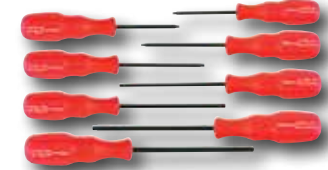

**455 TORX® Screwdriver, With Wiha-Protturn Handle** Blade high alloy CVM steel, hardened, black finish. Molded on ergonomic Wiha-Protturn handle, impact resistant.

Item No.	Size	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.
45505	T6	50	2.0	3.5	.139	129	5.1	.05	10
45506	T7	50	2.0	3.5	.139	129	5.1	.05	10
45511	T8	60	2.4	3.5	.139	139	5.5	.06	10
45516	T9	60	2.4	4.0	.157	149	5.8	.08	10
45521	T10	80	3.1	4.0	.157	170	6.7	.10	10
45522	T10	275	10.8	4.0	.157	363	14.2	.13	10
45526	T15	80	3.1	4.0	.157	170	6.7	.10	10
45531	T20	100	3.9	4.0	.157	190	7.5	.11	10
45536	T25	100	3.9	4.5	.177	190	7.5	.11	10
45541	T27	115	4.5	5.5	.216	215	8.4	.11	10
45546	T30	115	4.5	6.0	.236	215	8.4	.20	10
45551	T40	130	5.1	7.0	.275	240	9.4	.28	10
45561	T50	130	5.1	9.0	.354	240	9.4	.31	10



Retainer out of stainless steel

**48400 1/4" Bit Holding Screwdriver, With Wiha Protturn Handle** Magnetic, holds bit and screw. Shaft CVM steel, nickel-plated. Handle, molded on, impact resistant.

Item No.	Size mm	Inch	mm	Inch	lbs.	pkg.
48400	1/4	125	5.0	243	9.6	.24 10







## Wiha Cabinet Tip Slotted & Phillips Screwdrivers



**186 Slotted Cabinet Tip Screwdriver, With Wiha-Square Handle** Blade CVM steel, hardened, nickel-plated. Tip parallel to shaft. Series includes extra long dimensions for screws in difficult to reach locations. Wiha-square handle cellulose-acetate, impact resistant.

Item No.	Slotted	Phillips	Slotted	Phillips	Slotted	Phillips	Slotted	Phillips	Slotted	Phillips	Slotted	Phillips	lbs.	pkg.
	mm	Inch	mm	Inch	mm	Inch	mm	Inch	mm	Inch	mm	Inch		
18601	2.0	.08	40	1.6	0.40	.02	100	4.0	14	.55	.02	10		
18603	2.5	.10	50	2.0	0.40	.02	110	4.3	14	.55	.02	10		
18606	3.0	.12	75	3.0	0.50	.02	150	5.9	19	.75	.05	10		
18609	3.0	.12	100	3.9	0.50	.02	175	6.9	19	.75	.06	10		
18612	3.0	.12	150	5.9	0.50	.02	225	8.9	19	.75	.06	10		
18615	3.0	.12	200	8.0	0.50	.02	285	11.2	22	.87	.08	10		
18624	4.0	.16	100	3.9	0.60	.02	185	7.3	22	.87	.08	10		
18627	4.0	.16	150	5.9	0.60	.02	235	9.3	22	.87	.10	10		
18630	4.0	.16	200	8.0	0.60	.02	285	11.2	22	.87	.11	10		
18642	5.0	.20	100	3.9	0.70	.03	195	7.7	24	.94	.13	10		
18645	5.0	.20	150	5.9	0.70	.03	245	9.6	24	.94	.15	10		
18648	5.0	.20	200	8.0	0.70	.03	295	11.6	24	.94	.17	10		
18651	5.0	.20	300	12.0	0.70	.03	395	15.6	24	.94	.20	10		
18654	6.0	.24	100	3.9	0.90	.04	205	8.1	28	1.10	.19	10		
18657	6.0	.24	150	5.9	0.90	.04	255	10.0	28	1.10	.21	10		
18663	6.0	.24	300	12.0	0.90	.04	405	15.9	28	1.10	.29	10		
18678	8.0	.32	300	12.0	1.20	.05	415	16.3	32	1.26	.39	10		
18681	10.0	.39	200	8.0	1.60	.06	315	12.4	32	1.26	.37	10		



**153 Phillips Screwdriver, With Wiha-Square Handle** Blade chrome-vanadium-molybdenum steel, hardened, nickel-plated. Wiha-square handle cellulose-acetate, impact resistant.

Item No.	Size	Slotted	Phillips	Slotted	Phillips	Slotted	Phillips	Slotted	Phillips	lbs.	pkg.
		mm	Inch	mm	Inch	mm	Inch	mm	Inch		
15305	0	60	2.4	3.0	.12	135	5.3	19	.75	.05	10
15310	1	80	3.1	4.5	.18	175	6.9	24	.94	.11	10
15315	1	200	8.0	4.5	.18	295	11.6	24	.94	.15	10
15325	2	100	3.9	6.0	.24	205	8.1	28	1.10	.18	10
15330	2	250	10.0	6.0	.24	355	14.0	28	1.10	.27	10
15335	2	350	13.7	6.0	.24	455	17.8	28	1.10	.33	10
15340	3	150	5.9	8.0	.32	265	10.4	32	1.26	.33	10



**222 Pozidriv® Screwdriver, With Wiha-Square Handle** Blade chrome-vanadium-molybdenum steel, hardened, nickel-plated. Wiha-square handle cellulose-acetate, impact resistant.

Item No.	Size	Slotted	Phillips	Pozidriv	Pozidriv	Slotted	Phillips	Slotted	Phillips	lbs.	pkg.
		mm	Inch	mm	Inch	mm	Inch	mm	Inch		
22220	1	200	8.0	4.5	.17	295	11.6			.15	10
22230	2	250	9.8	6.0	.23	355	13.9			.27	10
22240	3	150	5.9	8.0	.31	265	10.4			.30	10

## Wiha Offset Screwdrivers



**161 Phillips Offset Screwdriver, With Handle** For working in confined spaces. Blade CVM special steel, hardened, hard chromed. Handle high quality plastic, impact resistant.

Item No.	Size	mm	Inch	mm	Inch	lbs.	Pkg.
16112	1 + 2	125	4.9	5.5	.217	.08	10
16134	3 + 4	200	8.0	10.0	.315	.33	10



**207 Slotted Offset Screwdriver, With Handle**

Item No.	Slotted	Phillips	Slotted	Phillips	Slotted	Phillips	lbs.	Pkg.
	mm	Inch	mm	Inch	mm	Inch		
20700	3.5	9/64	90	3.5	0.6	.02	.02	10
20705	4.0	5/32	100	3.9	0.8	.03	.03	10
20710	5.5	7/32	125	5.0	1.0	.04	.06	10
20715	6.5	1/4	125	5.0	1.2	.05	.07	10
20720	8.0	5/16	150	5.9	1.2	.05	.15	10
20725	10.0	3/8	175	6.9	1.6	.06	.23	10



**20790 5 Piece Slotted & Phillips Offset Screwdriver Set**

Item No.	Set includes:
20790	Slotted: 6.5, 8.0, 10.0 Phillips: 1 + 2, 3 + 4



**207 TORX® Offset Screwdriver With Molded Handle** Working in confined spaces. CVM special steel, hardened, black finish.

Item No.	Size	lbs.	pkg.
20756	T6 + T8	.02	1
20757	T7 + T9	.02	1
20758	T10 + T15	.02	1
20759	T20 + T25	.07	1
20760	T27 + T30	.10	1



**20799 TORX® Offset Screwdriver Set, 5 Pcs. Molded Handle.**

Item No.	Set includes:	lbs.	pkg.
20799	T6+T8, T7+T9, T10+T15, T20+T25, T27+T30	.24	1

**Wiha Power Blades**




**76000 CentroFix Cushion Grip Blade Holder**  
 Wiha-SoftFinish® impact resistant, with roll off protection. Ergonomic cushion grip handle. Quick release bit holder with magnet.

Item						
No.	mm	mm	Inch	mm	Inch	lbs.
76000	6.0	149	5.9	34.6	1.36	.26


**90mm Power Blades**

CentroFix quick release bit holder with magnet

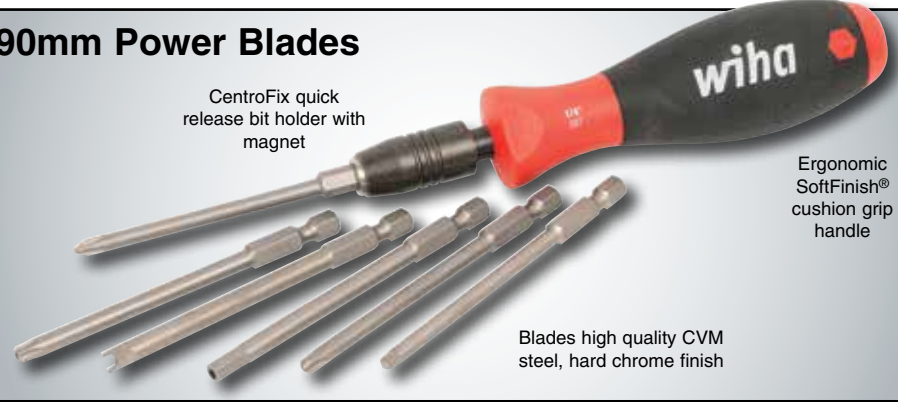
 
 




Ergonomic SoftFinish® cushion grip handle

Blades high quality CVM steel, hard chrome finish

 


 



**760 Slotted Power Blades**  
 S2 modified tool steel. Hardened & tempered to HRC 60. Blades fit CentroFix power blade handle. OAL 90mm/3.5".

Item				
No.	mm	lbs.	pkg.	
76035	2.5	.02	1	
76036	3.0	.02	1	
76037	4.5	.03	1	
76038	5.5	.03	1	
76039	6.0	.04	1	

 





**760 Square Power Blades**  
 S2 modified tool steel. Hardened & tempered to HRC 60. Blades fit CentroFix power blade handle. OAL 90mm/3.5".

Item				
No.	Size	lbs.	pkg.	
76056	1	.02	1	
76057	2	.03	1	
76058	3	.04	1	




**760 Spanner Power Blades**  
 S2 modified tool steel. Hardened & tempered to HRC 60. Blades fit CentroFix power blade handle. OAL 90mm/3.5".

Item				
No.	Size	lbs.	pkg.	
76022	6	.03	1	
76023	8	.04	1	
76024	10	.04	1	





**76093 5 Piece Slotted Blade Set**

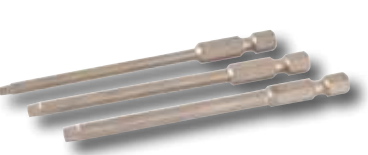Item		Set includes:
No.	lbs.	Slotted: 2.5, 3.0, 4.5,
76093	.16	5.5, 6.0mm x 90mm





**76095 3 Piece Square Blade Set**

Item		Set includes:
No.	lbs.	Square: #1, 2,
76095	.11	3 x 90mm








**76089 3 Piece Spanner Blade Set**

Item		Set includes:
No.	lbs.	Spanner: #6, 8,
76089	.12	10 x 90mm

 






**760 Phillips Power Blades**  
 S2 modified tool steel. Hardened & tempered to HRC 60. Blades fit CentroFix power blade handle. OAL 90mm/3.5".

Item				
No.	Size	lbs.	pkg.	
76041	0	.01	1	
76042	1	.02	1	
76043	2	.03	1	
76044	3	.04	1	


 





**760 Pozidriv® Power Blades**  
 S2 modified tool steel. Hardened & tempered to HRC 60. Blades fit CentroFix power blade handle. OAL 90mm/3.5".

Item				
No.	Size	lbs.	pkg.	
76011	1	.03	1	
76012	2	.04	1	
76013	3	.04	1	

 


**760 Tri-Wing Power Blades**  
 S2 modified tool steel. Hardened & tempered to HRC 60. Blades fit CentroFix power blade handle. OAL 90mm/3.5".

Item				
No.	Size	lbs.	pkg.	
76031	1	.02	1	
76032	2	.02	1	
76033	3	.03	1	
76034	4	.04	1	

 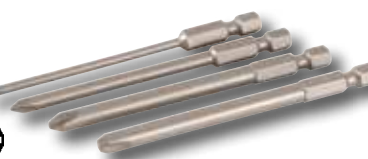


**76094 4 Piece Phillips Blade Set**

Item		Set includes:
No.	lbs.	Phillips: #0, 1, 2,
76094	.17	3 x 90mm



**76091 3 Piece Pozidriv® Blade Set**

Item		Set includes:
No.	lbs.	Pozidriv®: #1, 2,
76091	.12	3 x 90mm



**76088 4 Piece Tri-Wing Blade Set**

Item		Set includes:
No.	lbs.	Tri-Wing: #1, 2,
76088	.16	3, 4 x 90mm




## Wiha 90mm Power Blades & Sets



### 760 Security Hex Metric Power Blades

S2 modified tool steel. Hardened & tempered to HRC 60. Blades fit CentroFix power blade handle. OAL 90mm/3.5".

Item No.	mm	lbs.	pkg.
76001	2.5	.02	1
76002	3.0	.02	1
76003	4.0	.03	1
76004	5.0	.04	1

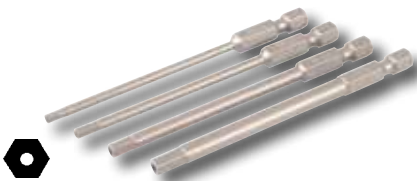

### 76090 4 Piece Security Hex Blade Set

Item No.	lbs.	Set includes:
76090	.12	Metric: 2.5, 3.0, 4.0, 5.0 x 90mm



### 760 Security Hex Inch Power Blades

OAL 90mm/3.5".

Item No.	Inch	lbs.	pkg.
76045	1/16*	.01	1
76046	5/64	.01	1
76047	3/32	.02	1
76048	7/64	.02	1
76049	1/8	.03	1
76050	9/64	.03	1
76051	5/32	.04	1
76052	3/16	.04	1
76053	7/32	.05	1
76054	1/4	.06	1

\* 1/16" Standard Inch Hex Only



### 76096 10 Piece Security Hex Blade Set

Item No.	lbs.	Inch:
76096	.32	1/16*, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4" x 90mm

\* 1/16" Standard Inch Hex Only



### 760 Security TORX® Power Blades

S2 modified tool steel. Hardened & tempered to HRC 60. Blades fit CentroFix power blade handle. OAL 90mm/3.5".

Item No.	Size	lbs.	pkg.
76008	T8s	.02	1
76009	T9s	.02	1
76010	T10s	.02	1
76015	T15s	.02	1
76020	T20s	.02	1
76025	T25s	.03	1
76027	T27s	.03	1
76030	T30s	.04	1
76040	T40s	.04	1



### 76092 9 Piece Security TORX® Blade Set

Item No.	lbs.	Set includes:
76092	.30	T8s, T9s, T10s, T15s, T20s, T25s, T27s, T30s, T40s



### 76087 61 Pc. Power Blade Service Kit, In Durable Zipper Case

Set includes Bit Holding Handle, MicroBit Storage Handle, 4mm to 1/4" Magnetic Adapter, 9 power blades, 46 bits & 3 nut setters.

Item No. 76087	lbs. 1.34
90mm Power Blades:	Slotted: 4.5, 5.5, 6.0mm
	Phillips: #1, 2, 3 & Square: #1, 2, 3
75mm Security TORX® Bits:	T10s, T15s, T20s, T25s, T27s, T30s
MicroBits:	Phillips: #000, 00, 0, 1, 2, Slotted: .8, 1.2, 1.5, 1.8, 2.0, 2.5, 3.0, 3.5, 4.0mm
	Hex Inch: .028, .035, .050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32"
	Hex Metric: 1.3, 1.5, 2.0, 2.5, 3.0, 4.0mm
TORX®:	T1, T2, T3, T4, T5, T6, T7, T8, T9, T10
Magnetic Nut Setters:	1/4, 5/16, 3/8"



### 76098 36 Pc. Power Blade Set, In Durable Belt Pack

Set includes cushion grip CentroFix Blade Holder & 35 interchangeable blades.

Item No. 76098	lbs. 1.86
Slotted:	2.5, 3.0, 4.5, 5.5, 6.0mm
Phillips:	#0, 1, 2, 3
Security TORX®:	T8s, T9s, T10s, T15s, T20s, T25s, T27s, T30s, T40s
Security Hex Metric:	2.5, 3.0, 4.0, 5.0mm
Pozidriv®:	#1, 2, 3 & Square: #1, 2, 3
Spanner:	#6, 8, 10 & Tri-Wing: #1, 2, 3, 4
	Cushion Grip CentroFix Blade Holder



### 76099 37 Pc. Power Blade Set, In Durable Belt Pack

Set includes cushion grip CentroFix Blade Holder & 36 interchangeable blades.

Item No. 76099	lbs. 2.06
Slotted:	2.5, 3.0, 4.5, 5.5, 6.0mm
Phillips:	#0, 1, 2, 3
Security TORX®:	T8s, T9s, T10s, T15s, T20s, T25s, T27s, T30s
Security Hex Inch:	1/16*, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4"
Pozidriv®:	#1, 2, 3 & Square: #1, 2, 3
4" Nut Setters:	1/4, 5/16, 3/8"
	Cushion Grip CentroFix Blade Holder
	* 1/16" Standard Inch Hex Only




### 76079 Canvas Belt Wallet Storage Pouch

Holds 38 90mm power blades. Folding pouch.

Item No.	Size	lbs.	pkg.
76079	7-1/8" x 6" x 2"	.42	1





**Rotating cap**  
for precise turning and control with fingertip

**Precision handle**  
high quality plastic, cadmium free

**Molded on tapered handle**  
allows rapid rotation

**High performance blades**  
CVM steel,  
Hard chrome finished

**Tip**  
precision ground for exact fit,  
hard chromed non-slip surface

**Wiha Precision Chip Lifter & Accessories**



**26810 Precision Chip Lifter**  
Blade CVM steel, hardened, chrome-plated. Precision handle high quality plastic, impact resistant. Standard handle

Item							
No.	mm	mm	mm	mm	Inch	lbs.	Pkg.
26810	1	3.5	50	145	5.7	.07	1

\*Metric dimensions actual - Inch dimensions approximate



**26001 Pocket Clip for Precision Screwdrivers** Tool clips turn Precision Screwdrivers into Pocket Screwdrivers.

Item No.	Fits all		lbs.		pkg.
26001	Precision handles	.01		1	



**26000 Plastic Precision Tool Rack**  
Rack holds 6 precision screwdrivers, can be set on workbench. Also has holes for hanging. Made from high quality plastic.

Item No.	Rack for 6		lbs.		Pkg.
26000	Precision screwdrivers	.08		1	

**Wiha Precision Slotted/Phillips Drivers**



**260 Slotted Screwdriver, With Precision Handle** Blade high alloy chrome-vanadium-molybdenum steel. Pkg. 10

Item								
No.	mm	Inch	mm	Inch	mm	mm	Inch	lbs.
26008	.80	1/32	40	1.6	0.16	120	4.7	.02
26010	1.0	.039	40	1.6	0.18	120	4.7	.02
26012	1.2	3/64	40	1.6	0.20	120	4.7	.02
26015	1.5	1/16	40	1.6	0.25	120	4.7	.02
26018	1.8	.070	40	1.6	0.30	120	4.7	.02
26020	2.0	5/64	40	1.6	0.40	120	4.7	.02
26022	2.0	5/64	50	2.0	0.40	145	5.7	.02
26023	2.0	5/64	100	3.9	0.40	180	7.1	.03
26025	2.5	3/32	50	2.0	0.40	145	5.7	.03
26027	2.5	3/32	100	3.9	0.40	195	7.7	.03
26028	2.5	3/32	150	6.0	0.40	245	9.6	.04
26030	3.0	1/8	50	2.0	0.50	145	5.7	.03
26032	3.0	1/8	60	2.4	0.50	170	6.7	.04
26033	3.0	1/8	100	3.9	0.50	210	8.3	.04
26034	3.0	1/8	150	5.9	0.50	260	10.2	.05
26035	3.5	9/64	60	2.4	0.60	170	6.7	.05
26040	4.0	5/32	60	2.4	0.80	170	6.7	.05
26041	4.0	5/32	100	3.9	0.80	210	8.3	.06
26042	4.0	5/32	150	5.9	0.80	260	10.2	.07

\*Metric dimensions actual - Inch dimensions approximate



**26090 6 Piece Precision Slotted Set**  
Blade high alloy chrome-vanadium-molybdenum steel. Hard chrome finished.

Item No.			lbs.
26090	<b>Slotted:</b>		
	1.5, 2.0 x 40mm		.27
	2.5, 3.0 x 50mm		
	3.5, 4.0 x 60mm		



**26099 8 Piece Precision Slotted Set**  
Blade high alloy CVM steel. Hard chrome finished. In canvas storage pouch.

Item	<b>Slotted:</b>		lbs.
No.	1.0, 1.2, 1.5, 2.0 x 40mm		
26099	2.5, 3.0 x 50mm, 3.5, 4.0 x 60mm		.54



**261 Phillips Screwdriver, With Precision Handle** Blade high alloy chrome-vanadium-molybdenum steel. Pkg. 10

Item								
No.	Size	mm	Inch	mm	Inch	mm	Inch	lbs.
26102	000	40	1.6	2.0	.08	120	4.7	.02
26100	00	40	1.6	2.0	.08	120	4.7	.02
26101	00	75	3.0	2.0	.08	155	6.1	.02
26105	0	50	2.0	3.0	.12	145	5.7	.02
26108	0	75	3.0	3.0	.12	170	6.7	.03
26107	0	100	3.9	3.0	.12	195	7.6	.05
26109	0	150	5.9	3.0	.12	245	9.6	.06
26110	1	60	2.4	4.0	.16	170	6.7	.05
26113	1	80	3.1	4.0	.16	190	7.5	.05
26114	1	100	3.9	4.0	.16	210	8.2	.06
26115	1	150	5.9	4.0	.16	260	10.2	.07

\*Metric dimensions actual - Inch dimensions approximate



**26190 8 Piece Precision Slotted & Phillips Screwdrivers & Industrial Long Nose Pliers Set**

Item No.	<b>Slotted:</b>	1.5 x 40mm
26190	2.0, 2.5 x 50mm, 3.0 x 60mm	
	<b>Phillips:</b>	00 x 40mm
lbs. .72	0 x 50mm, 1 x 60mm	
	<b>Industrial Long Nose Pliers</b>	
	6.3"/160mm OAL	



**26190.MC/26197 7 Pc. Precision Slotted & Phillips Set**

Item No.	<b>Slotted:</b>	1.5 x 40mm
26197	2.0, 2.5 x 50mm, 3.0 x 60mm	
	<b>Phillips:</b>	00 x 40mm
lbs. .31	0 x 50mm, 1 x 60mm	



In canvas storage pouch

**26199 8 Pc. Precision Slotted/Phillips Set**

Item No.	<b>Slotted:</b>	1.0, 2.0 x 40mm, 3.0 x 50mm, 4.0 x 60mm		lbs.
26199	<b>Phillips:</b>	000, 00 x 40mm, 0 x 50mm, 1 x 60mm		.55

## Wiha Precision Slotted/Phillips Drivers



**26092 7 Piece Precision Slotted & Phillips Set** Blade high alloy chrome-vanadium-molybdenum steel.

Item No.		
<b>26092</b>	<b>Slotted:</b>	lbs.
	2.5 x 50mm,	.30
	2.5, 3.0, 4.0 x 100mm	
	3.0, 4.0 x 150mm	
	<b>Phillips:</b>	
	0 x 75mm	



**26194 4 Piece Precision Phillips Set** Blade high alloy chrome-vanadium-molybdenum steel. Hard chrome finished.

Item No.	Phillips:	
	000, 00 x 40mm	lbs.
<b>26194</b>	0 x 50mm, 1 x 60mm	.18



**26192 5 Piece Precision Slotted & Phillips Set** Blade high alloy chrome-vanadium-molybdenum steel.

Item No.	Slotted:	
	2.5, 3.0, 4.0 x 150mm	lbs. .44
<b>26192</b>	<b>Phillips:</b>	
	0, 1 x 150mm	

## Wiha Pozidriv® Precision Series



**262 Pozidriv® Screwdriver, With Precision Handle** Blade high alloy chrome-vanadium-molybdenum steel. Pkg. 10

Item No.	Size	mm	Inch	mm	Inch	mm	Inch	lbs.
<b>26205</b>	0	50	2.0	3.0	.12	145	5.7	.03
<b>26210</b>	1	60	2.4	4.0	.16	170	6.7	.05

\*Metric dimensions actual - Inch dimensions approximate

## Wiha Hex Inch & Metric Precision Series



**263 Inch Hex Driver, With Precision Handle** Inch sizes. Blade high alloy chrome-vanadium-molybdenum steel. Pkg. 10

Item No.	Hex	Inch	mm	mm	Inch	mm	Inch	lbs.
<b>26307</b>	.028	0.7	40	1.6	120	4.7	.02	
<b>26309</b>	0.035	0.9	40	1.6	120	4.7	.02	
<b>26313</b>	0.05	1.3	40	1.6	120	4.7	.02	
<b>26316</b>	1/16	-	50	2.0	145	5.7	.03	
<b>26320</b>	5/64	2.0	50	2.0	145	5.7	.03	
<b>26323</b>	3/32	-	60	2.4	170	6.7	.04	
<b>26327</b>	7/64	-	60	2.4	170	6.7	.04	
<b>26331</b>	1/8	-	60	2.4	170	6.7	.04	
<b>26333</b>	9/64	-	60	2.4	170	6.7	.05	
<b>26336</b>	5/32	-	60	2.4	170	6.7	.05	

\*Metric dimensions actual - Inch dimensions approximate



**263 Metric Hex Driver, With Precision Handle** Metric sizes. Blade high alloy chrome-vanadium-molybdenum steel.

Item No.	Hex	Inch	mm	Inch	mm	Inch	lbs.	pkg.
<b>26307</b>	.7	.028	40	1.6	120	4.7	.02	10
<b>26309</b>	.9	.035	40	1.6	120	4.7	.02	10
<b>26313</b>	1.3	.050	40	1.6	120	4.7	.02	10
<b>26315</b>	1.5	-	50	2.0	145	5.7	.03	10
<b>26320</b>	2.0	5/64	50	2.0	145	5.7	.03	10
<b>26325</b>	2.5	-	60	2.4	170	6.7	.04	10
<b>26330</b>	3.0	-	60	2.4	170	6.7	.04	10
<b>26340</b>	4.0	-	60	2.4	170	6.7	.05	10

\*Metric dimensions actual - Inch dimensions approximate



**26391 8 Pc. Precision Hex Driver Set - Inch** Blade high alloy chrome-vanadium-molybdenum steel.

Item No.	Hex Inch:	
<b>26391</b>	.028, .035, .050 x 1.6"	lbs. .32
	1/16, 5/64 x 2.0"	
	3/32, 7/64, 1/8 x 2.4"	



**26390 7 Pc. Precision Hex Driver Set - Metric** Blade high alloy chrome-vanadium-molybdenum steel.

Item No.	Hex Metric:	
<b>26390</b>	.7, .9, 1.3 x 40mm	lbs. .28
	1.5, 2.0 x 50mm	
	2.5, 3.0 x 60mm	




**26399 8 Pc. Precision Hex Driver Set - Inch** Blade high alloy CVM steel. Hard chrome finished. In canvas storage pouch

Item No.	Hex Inch:	
<b>26399</b>	.028, .035, .050 x 1.6"	lbs. .55
	1/16, 5/64 x 2.0", 3/32, 7/64, 1/8 x 2.4"	

\*Metric dimensions actual - Inch dimensions approximate

**Wiha Ball End Precision Series**

**Wiha TORX® Precision Series**

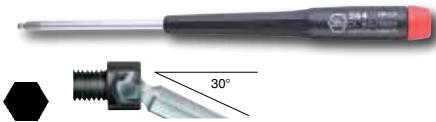

**264 Inch Ball End Hex Inch Screwdriver**

**With Precision Handle** Angle entry up to 30°. Blade high alloy chrome-vanadium-molybdenum steel. Hard chrome finish.

Item	No.	Inch	mm	Inch	mm	Inch	lbs.	Pkg.
	26413	.050	40	1.6	120	4.7	.02	10
	26416	1/16	50	2.0	145	5.7	.03	10
	26419	5/64	50	2.0	145	5.7	.03	10
	26423	3/32	50	2.0	145	5.7	.03	10
	26427	7/64	60	2.4	170	6.7	.03	10
	26431	1/8	60	2.4	170	6.7	.05	10
	26436	9/64	60	2.4	170	6.7	.05	10
	26439	5/32	60	2.4	170	6.7	.05	10


\*Metric dimensions actual - Inch dimensions approximate



**26490 8 Piece Ball End Hex Driver Set - Inch**

Angle entry up to 30°. Blade high alloy chrome-vanadium-molybdenum steel.

Item	No.	Hex Inch:	lbs.
	26490	1/16, 5/64, 3/32 x 2.0, 7/64, 1/8, 9/64, 5/32 x 2.4"	.40

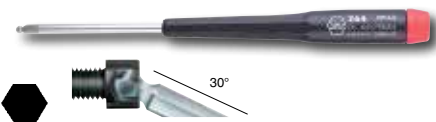

**264 Metric Ball End Hex Metric Screwdriver**

**With Precision Handle** Angle entry up to 30°. Blade high alloy CVM steel.

Item	No.	mm	Inch	mm	Inch	mm	Inch	lbs.	Pkg.
	26413	1.3	.050	40	1.6	120	4.7	.02	10
	26415	1.5	-	50	2.0	145	5.7	.03	10
	26420	2.0	-	50	2.0	145	5.7	.03	10
	26425	2.5	-	60	2.4	170	6.7	.04	10
	26430	3.0	-	60	2.4	170	6.7	.05	10
	26440	4.0	-	60	2.4	170	6.7	.05	10

\*Metric dimensions actual - Inch dimensions approximate



In canvas storage pouch

**26499 8 Pc. Ball End Hex Driver Set - Inch**

Blade high alloy chrome-vanadium-molybdenum steel. Hard chrome finished.

Item	Ball End Hex Inch:	lbs.	
	26499	.050 x 1.6"	.62
		1/16, 5/64, 3/32 x 2.0"	
		7/64, 1/8, 9/64, 5/32 x 2.4"	



**267 TORX® Screwdriver, With Precision Handle**

Blade high alloy chrome-vanadium-molybdenum steel.

Item	No.	Size	mm	Inch	mm	Inch	lbs.	pkg.
	26701	T1	40	1.6	120	4.7	.01	10
	26702	T2	40	1.6	120	4.7	.02	10
	26703	T3	40	1.6	120	4.7	.02	10
	26704	T4	40	1.6	120	4.7	.02	10
	26705	T5	40	1.6	120	4.7	.02	10
	26706	T6	40	1.6	120	4.7	.02	10
	26707	T7	40	1.6	120	4.7	.02	10
	26708	T8	40	1.6	120	4.7	.03	10
	26709	T9	50	2.0	145	5.7	.03	10
	26710	T10	50	2.0	145	5.7	.03	10
	26715	T15	60	2.4	170	6.7	.05	10
	26720	T20	60	2.4	170	6.7	.05	10

\*Metric dimensions actual - Inch dimensions approximate



**26790 6 Pc. TORX® Screwdriver Set**

Blade high alloy chrome-vanadium-molybdenum steel.

Item	No.	TORX®:	lbs.
	26790	T6, T7, T8 x 40mm T9, T10 x 50mm T15 x 60mm	.30

**26791 Set 8 Pcs. TORX® Screwdriver Set**

Item No.	TORX®:	lbs.
26791	T1, T2, T3, T4, T5, T6, T7, T8	

**Wiha TORX® Precision Series**



**26491 5 Piece Ball End Hex Driver Set - Metric**

Angle entry up to 30°.

Blade high alloy chrome-vanadium-molybdenum-steel.

Item	No.	Ball End Hex Metric:	lbs.
	26491	1.3 x 40mm 1.5, 2.0 x 50mm 2.5, 3.0 x 60mm	.31



**26792 7 Pc. TORX® Screwdriver Set**

Blade high alloy chrome-vanadium-molybdenum steel.

Item	No.	TORX®:	lbs.
	26792	T5, T6, T7, T8 x 40mm T9, T10 x 50mm T15 x 60mm	.33



**26799 8 Pc. TORX® Screwdriver Set**

Blade high alloy chrome-vanadium-molybdenum steel. Hard chrome finished.

Item	No.	TORX®:	lbs.
	26799	T3, T4, T5, T6, T7, T8 x 40mm T9 x T10 x 50mm	.50



## Wiha Pentalobe Precision Series

Wiha Pentalobe drivers will fit fasteners used in "Apple" brand products including iPhone, Mac Book & Mac Air



- Exact fit precision machined tips
- High performance CRM72 tool steel
- Hard chromed finish blades & tips
- Tapered ergonomic handle
- Easy spin finger tip control cap



**267 Pentalobe Screwdrivers, With Precision Handle** Blade high alloy chrome-vanadium-molybdenum steel.

Item No.	Size	mm	Inch	mm	Inch	lbs.	pkg.
26761	PL1	40	1.6	120	4.7	.01	1
26762	PL2	40	1.6	120	4.7	.02	1
26763	PL3	40	1.6	120	4.7	.02	1
26764	PL4	40	1.6	120	4.7	.02	1
26765	PL5	40	1.6	120	4.7	.02	1
26766	PL6	40	1.6	120	4.7	.02	1

\*Metric dimensions actual - Inch dimensions approximate



**26794 6 Pc. Precision Pentalobe Screwdriver Set** Blade high alloy CVM steel. Hard chrome finished. Super hardened best wear resistance long life.

Item No.	Pentalobe Drivers:	lbs.
26794	PL1, PL2, PL3, PL4, PL5, PL6	.35

## Wiha Precision Screwdriver Sets



**92189 Master Technicians Bench Top Set** Metal frame. Equipped with 50 precision drivers.

Item No.	Slotted:
92189	1.5, 2.0, 2.5, 3.0, 3.5, 4.0
	<b>Phillips:</b> #000, #00, #0, #1
	<b>Pentalobe:</b> PL1, PL2, PL3, PL4
	<b>TORX®:</b> T1, T2, T3, T4, T5, T6, T7, T8, T9, T10
	<b>Metric Hex:</b> 1.27, 1.5, 2.0, 2.5, 3.0
	<b>Inch Hex:</b> .028, .035, .050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32"
	<b>Metric Nut Drivers:</b> 1.5, 1.8, 2.0, 2.5, 3.0, 3.5, 4.0, 4.5, 5.0, 5.5
	26810 Chip Lifter



**92191 51 Pc. Precision Tool Tray Set** Tool box tray. Equipped with 51 precision drivers.

Item No.	Slotted:
92191	.8, 1.0, 1.2, 1.5, 1.8, 2.0, 2.5, 3.0, 3.5, 4.0
	<b>Phillips:</b> #000, #00, #0, #1
	<b>Torx®:</b> T1, T2, T3, T4, T5, T6, T7, T8, T9, T10
	<b>Metric Hex:</b> 1.27, 1.5, 2.0, 2.5, 3.0, 4.0
	<b>Inch Hex:</b> .028, .035, .050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32"
	<b>Metric Nut Drivers:</b> 1.5, 1.8, 2.0, 2.5, 3.0, 3.5, 4.0, 4.5, 5.0, 5.5
	26810 Chip Lifter



**92190 Master Technicians Bench Top Set** Metal frame. Equipped with 50 precision drivers.

Item No.	Slotted:
92190	.8, 1.0, 1.2, 1.5, 1.8, 2.0, 2.5, 3.0, 3.5, 4.0
	<b>Phillips:</b> #000, #00, #0, #1
	<b>TORX®:</b> T1, T2, T3, T4, T5, T6, T7, T8, T9, T10
	<b>Metric Hex:</b> 1.27, 1.5, 2.0, 2.5, 3.0
	<b>Inch Hex:</b> .028, .035, .050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32"
	<b>Metric Nut Drivers:</b> 1.5, 1.8, 2.0, 2.5, 3.0, 3.5, 4.0, 4.5, 5.0, 5.5
	26810 Chip Lifter



**91118 Rugged Polyester Canvas Storage Pouch** Holds 8 Precision Tools up to 170mm in length. Folding pouch. Has security flaps and velcro closer.

Item No.	Size	lbs.	pkg.
91118	14 1/2" W x 7 3/4" L	.13	1

Wiha Soft Grip PicoFinish Precision Screwdrivers

The Comfortable Precision Screwdriver



Color coded symbols on rotating cap gives easy recognition of individual styles & sizes

CVM tool steel blade, hardened, hard chrome finish

Soft Grip Handle



Ergonomic multi-component handle with rotating cap for maximum user comfort and precise control



**260 Slotted Precision Screwdriver, With PicoFinish Handle** Blade CVM steel, hardened, hard chromed.

Item No.	Size	mm	Inch	mm	Inch	mm	Inch	Pkg.
26050	0.8	.03	40	1.6	134	5.3		
26051	1.0	.04	40	1.6	134	5.3	10	
26052	1.2	.05	40	1.6	134	5.3	10	
26053	1.5	.06	40	1.6	134	5.3	10	
26054	1.5	.06	60	2.4	154	6.1	10	
26055	1.8	.07	40	1.6	134	5.3	10	
26056	1.8	.07	60	2.4	154	6.1	10	
26060	2.0	.08	40	1.6	140	5.5	10	
26061	2.0	.08	60	2.4	160	6.3	10	
26063	2.0	.08	100	3.9	200	7.9	10	
26065	2.5	.09	50	2.0	150	5.9	10	
26066	2.5	.09	75	3.0	175	6.9	10	
26068	2.5	.09	100	3.9	200	7.9	10	
26070	3.0	.13	50	2.0	150	5.9	10	
26072	3.0	.13	100	3.9	200	7.9	10	
26073	3.0	.13	150	5.9	250	9.8	10	
26074	3.5	.14	60	2.4	160	6.3	10	
26076	4.0	.16	60	2.4	160	6.3	10	
26079	4.0	.16	100	3.9	200	7.9	10	
26080	4.0	.16	150	5.9	250	9.8	10	

\*Metric dimensions actual - Inch dimensions approximate



**26093 8 Pc. Slotted Precision Screwdriver Set, With Soft PicoFinish Handle** In storage pouch

Item No.	Slotted:	lbs.
26093	.8, 1.2, 1.5, 2.0 x 40mm 2.5, 3.0 x 50mm, 3.5, 4.0 x 60mm	.54



**261 Phillips Precision Screwdriver, With Soft PicoFinish Precision Handle** Blade high alloy CVM steel. Hard chrome finished.

Item No.	Size	mm	Inch	mm	Inch	mm	Inch	Pkg.
26130	000	40	1.6	2.0	.08	134	5.3	Pkg.
26132	00	40	1.6	2.0	.08	134	5.3	10
26133	00	60	2.4	2.0	.08	154	6.1	10
26135	0	50	2.0	3.0	.12	150	5.9	10
26136	0	75	3.0	3.0	.12	175	6.9	10
26140	1	60	2.4	4.0	.16	160	6.3	10
26142	1	80	3.1	4.0	.16	180	7.1	10
26145	1	150	5.9	4.0	.16	250	9.8	10

\*Metric dimensions actual - Inch dimensions approximate



**26193 8 Pc. Phillips Precision Driver Set, With Soft PicoFinish Handle**

Blade high alloy CVM steel, hardened, hard chromed. ChromTop finish on tip for a perfect fit. In storage pouch

Item No.	Slotted:	lbs.
26193	1.0, 1.5, 2.0 x 40mm 2.5 x 50mm, 3.5 x 60mm Phillips: 00 x 40mm 0 x 50mm, 1 x 60mm	.55



**267 MagicSpring Screw Holding TORX® Screwdriver, With Wiha-Precision Soft PicoFinish Handle** Blade high alloy CVM steel, hardened, hard chromed. Molded on ergonomic Wiha-PicoFinish precision handle, molded on, soft grips.

Item No.	Size	mm	Inch	mm	Inch	lbs.	Pkg.
26721	T6	40	1.6	140	5.5	.03	10
26723	T7	40	1.6	140	5.5	.03	10
26725	T8	40	1.6	140	5.5	.03	10
26727	T9	50	2.0	150	5.9	.04	10
26729	T10	50	2.0	150	5.9	.04	10
26731	T15	60	2.4	160	6.3	.04	10

\*Metric dimensions actual - Inch dimensions approximate



**26798 6 Pc. MagicSpring Screw Holding TORX® Screwdriver Set, With Wiha-Precision Soft PicoFinish Handle**

Blade high alloy CVM steel, hardened, hard chromed. Molded on ergonomic Wiha-PicoFinish precision handle, molded on, soft grips. In storage pouch

Item No.	MagicSpring TORX®:	lbs.
26798	T6, T7, T8 x 40mm T9, T10, T15 x 50mm	.50



## Wiha Pico Soft Grip TORX®



**267 TORX® Screwdriver, With Precision Soft PicoFinish Handle** Blade high alloy CVM tool steel, hardened, hard chrome finish.

Item						
No.	Size	mm	Inch	mm	Inch	Pkg.
26732	T1	40	1.6	134	5.3	10
26733	T2	40	1.6	134	5.3	10
26735	T3	40	1.6	134	5.3	10
26736	T4	40	1.6	134	5.3	10
26737	T5	40	1.6	134	5.3	10
26739	T6	40	1.6	140	5.5	10
26741	T7	40	1.6	140	5.5	10
26743	T8	40	1.6	140	5.5	10
26745	T9	50	2.0	150	5.9	10
26747	T10	50	2.0	150	5.9	10
26749	T15	60	2.4	160	6.3	10
26751	T20	60	2.4	160	6.3	10

\*Metric dimensions actual - Inch dimensions approximate

In storage pouch



**26793 8 Pc. TORX® Precision Driver Set, With Soft PicoFinish Handle** Blade high alloy CVM steel, hardened, hard chromed. ChromTop finish on tip for a perfect fit.

Item	TORX®:	lbs.
No.	T1, T2, T3, T4,	
26793	T5, T6, T7, T8	.50

In storage pouch



**26796 8 Pc. TORX® Precision Driver Set, Soft PicoFinish Handle** Blade high alloy CVM steel, hardened, hard chromed. ChromTop finish on tip for a perfect fit.

Item	TORX®:	lbs.
No.	T5, T6, T7, T8 x 40mm	.57
26796	T9, T10 x 50mm, T15, T20 x 60mm	

## Pico Soft Grip Hex Inch & Metric



**263 Hex Inch Screwdriver, With Precision Soft PicoFinish Handle** Blade high alloy CVM tool steel, hardened, hard chrome finish.

Item						
No.	Inch	mm	Inch	mm	Inch	Pkg.
26341	.028(0.7)	40	1.6	134	5.3	10
26343	.035(0.9)	40	1.6	134	5.3	10
26345	.050(1.3)	40	1.6	134	5.3	10
26349	5/64(2.0)	50	2.0	150	5.9	10
26363	1/16	50	2.0	144	5.7	10
26367	3/32	60	2.4	160	6.3	10
26369	7/64	60	2.4	160	6.3	10
26371	1/8	60	2.4	160	6.3	10

\*Metric dimensions actual - Inch dimensions approximate



In storage pouch

**26392 8 Piece Hex Inch Precision Driver Set, Soft PicoFinish Handle** Blade high alloy CVM steel, hardened, hard chromed.

Item	Hex Inch:	lbs.
No.	.028, .035, .050 x 1.6"	.24
26392	5/64, 1/16 x 2.0", 3/32, 7/64, 1/8 x 2.4"	



**263 Hex Metric Driver, With Precision Soft PicoFinish Handle**

Item						
No.	mm	mm	Inch	mm	Inch	Pkg.
26341	.7(.028)	40	1.6	134	5.3	10
26343	.9(.035)	40	1.6	134	5.3	10
26345	1.3(.050)	40	1.6	134	5.3	10
26347	1.5	50	2.0	144	5.7	10
26349	2.0(5/64)	50	2.0	150	5.9	10
26351	2.5	60	2.4	160	6.3	10
26353	3.0	60	2.4	160	6.3	10

\*Metric dimensions actual - Inch dimensions approximate



In storage pouch

**26393 7 Piece Hex Metric Precision Driver Set, Soft PicoFinish Handle** Blade high alloy CVM steel, hardened, hard chromed.

Item No.	Hex Metric:	lbs.
26393	.71, .89, 1.27 x 40mm	.22
	1.5, 2.0 x 50mm, 2.5, 3.0 x 60mm	

## Pico Soft Grip Ball End Inch & Metric



**264 Ball End Hex Inch Screwdriver, With Precision Soft PicoFinish Handle** Blade high alloy CVM tool steel, hardened, hard chrome finish.

Item						
No.	Inch	Inch	mm	Inch	mm	pkg.
26455	1/16	2.0	50	5.9	150	10
26457	5/64	2.0	50	5.9	150	10
26459	3/32	2.0	50	5.9	150	10
26461	7/64	2.4	60	6.3	160	10
26463	1/8	2.4	60	6.3	160	10
26465	9/64	2.4	60	6.3	160	10
26467	5/32	2.4	60	6.3	160	10

\*Metric dimensions actual - Inch dimensions approximate



**26493 7 Pc. Inch Ball End Hex Precision Driver Set, With Soft PicoFinish Handle**

Blade high alloy CVM steel, hardened, hard chromed. ChromTop finish on tip for a perfect fit. In storage pouch

Item	Ball End Hex Inch:	lbs.
No.	1/16, 5/64, 3/32 x 2.0"	.27
26493	7/64, 1/8, 9/64, 5/32 x 2.4"	



**264 Ball End Hex Metric Screwdriver, With Precision Soft PicoFinish Handle.** Blade high alloy CVM tool steel, hardened, hard chrome finish.

Item						
No.	mm	mm	Inch	mm	Inch	pkg.
26441	1.3	40	1.6	134	5.3	10
26443	1.5	50	2.0	150	5.9	10
26445	2.0	50	2.0	150	5.9	10
26447	2.5	60	2.4	160	6.3	10
26449	3.0	60	2.4	160	6.3	10

\*Metric dimensions actual - Inch dimensions approximate

## Pico Soft Grip Precision Chip Lifter




**26815 Soft PicoFinish Precision Chip Lifter** Blade CVM steel, hardened, hard chromed.

Item	mm	mm	mm	mm	Inch
No.	1	3.5	50	150	5.9
26815	Standard Soft PicoFinish handle				



**Wiha Protturn Precision Screwdrivers**

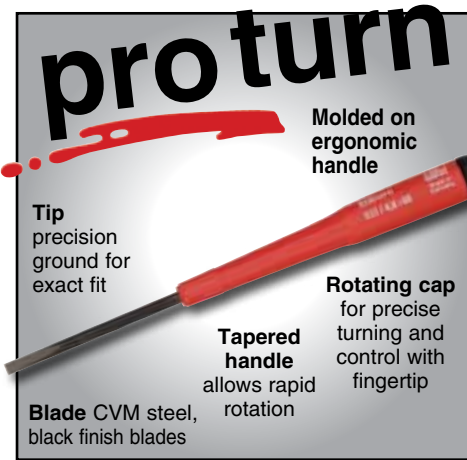

**pro turn**

Molded on ergonomic handle

Tip precision ground for exact fit

Rotating cap for precise turning and control with fingertip

Tapered handle allows rapid rotation

Blade CVM steel, black finish blades



**62990 5 Piece Slotted & Phillips Pocket Pack Set** Wiha Protturn precision ball retainer handle & 4 Wiha interchangeable blades.

**62990 Set includes the following blades:**  
 ↓ ⚪ **Slotted:** 1.5, 2.0, 3.0, 4.0mm  
 ⊕ **Phillips:** #000, #00, #0, #1  
 ⚖ **lbs.** .15



**95190 6 Pc. Slotted/Phillips Protturn Precision Screwdriver Set** Molded on precision handle. Blade high alloy CVM tool steel, black finish.

<b>Item</b>	<b>Slotted:</b> 1.5x40mm	⚖
<b>No.</b>	2.5x50mm, 3.5x60mm	lbs.
<b>95190</b>	<b>Phillips:</b> 00x40mm, 0x50mm, 1x60mm	.27



**62993 9 Pc. Slotted/Phillips/TORX® Work Station Set** Wiha Protturn precision ball retainer handle & 8 Wiha interchangeable blades.

**62993 Set includes the following blades:**  
 ↓ ⚪ **Slotted:** 1.5, 2.0, 3.0, 4.0mm  
 ⊕ **Phillips:** #000, #00, #0, #1  
 ⚙ **TORX®:** T6, T7, T8, T9, T10, T15, T20  
 ⚖ **lbs.** .64



**65090 9 Pc. Slotted/Phillips Protturn Precision Screwdriver Set** Molded on precision handle. CVM tool steel, black finish blades.

<b>Item</b>	<b>Slotted:</b>
<b>No.</b>	1.5x40mm, 2.0x50mm,
<b>65090</b>	2.5, 3.0, 3.5, 4.0x60mm
	<b>Phillips:</b> 00x40mm, 0x50mm, 1x60mm




**62995 22 Pc. Slotted/Phillips/TORX®/Ball End Hex Inch & Metric Tech Pack** Wiha Protturn precision ball retainer handle & 21 interchangeable blades. In canvas storage pouch

**62995 Set includes the following blades:**  
 ↓ ⚪ **Slotted:** 1.5, 2.0, 3.0, 4.0mm  
 ⊕ **Phillips:** #000, #00, #0, #1  
 ⚙ **TORX®:** T6, T7, T8, T9, T10, T15, T20  
 ⚡ **Hex Inch:** .050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32"  
 ⚡ **Hex Metric:** 1.5, 2.0, 2.5, 3.0, 4.0mm  
 ⚖ **lbs.** .87



**96800 Protturn Precision Chip Lifter** Molded on precision handle. Blade CVM tool steel, hardened, black finish.


<b>Item</b>		⚖
<b>No.</b>	Size mm mm Inch lbs. pkg.	
<b>96800</b>	1.0 50 145 5.7 .07 1	

**62994 14 Pc. Inch/Metric Ball End Hex Work Tech Pack** Protturn precision ball retainer handle & 13 Wiha interchangeable blades.

**62994 Set includes the following blades:**  
 ⚡ **Hex Inch:** .050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32"  
 ⚡ **Hex Metric:** 1.5, 2.0, 2.5, 3.0, 4.0mm  
 ⚖ **lbs.** .66  
 Set in canvas storage pouch

**Wiha Magnetizer/Demagnetizer**

Magnetize or Demagnetize tools and small parts instantly



Shatterproof Box is made from high quality plastic

Uses 2 C8 industrial permanent magnets

(+) to Magnetize  
 (-) to Demagnetize

**40010 Magnetizer and Demagnetizer**  
 To magnetize and demagnetize steel screwdriver blades, tweezers and similar tools. Box high quality plastic, shock-resistant, green, cadmium free.

**Application:**  
 To magnetize, lead tool slowly through the (+) opening, to demagnetize guide tool slowly through the (-) opening.

Item		⚖
No.	Dimensions	lbs.
<b>40010</b>	2.1" x 2.0" x 1.1"	.30

(Parts under 1" Length or 1/8" Diameter may not demagnetize)



## Wiha SYSTEM 4 Precision Handles and Blades



### 26900 SYS 4 Standard Precision Handle,

with rotating control cap. Accepts all SYSTEM 4 interchangeable blades. Wiha Precision handle, tapered, impact resistant. Ball retainer hold. 110mm/4.3" OAL

Item					
No.	mm	Inch	mm	Inch	lbs.
26900	4.0	.1574	14.0	.55	.04



### 26901 SYSTEM 4 Standard Precision

Adjustable handle with rotating control cap.

#### Advantages:

- Allows adjustable blade from 15 to 95mm.
- Collet lock allows for quick & easy adjustment.
- Holds blade securely in place. Accepts all SYSTEM 4 blades. 110mm/4.3" OAL

Item					
No.	mm	Inch	mm	Inch	lbs.
26901	4.0	.1574	14.0	.55	.06



### 28000 ESD Safe Dissipative Precision

Handle with rotating control cap. Surface resistant 10<sup>6</sup>-10<sup>9</sup> Ohms. 4 mm hex retainer for all SYSTEM 4 interchangeable blades.

Tapered handle, high quality plastic, impact resistant. Ball retainer hold. 110mm/4.3" OAL

Item					
No.	mm	Inch	mm	Inch	lbs.
28000	4.0	.1574	14.0	.55	.04



### 28001 ESD Safe Dissipative Precision

Adjustable Handle with rotating control cap.

#### Advantages:

- Use in ESD sensitive applications. Surface resistant 10<sup>6</sup>-10<sup>9</sup> Ohms.
- Collet lock allows for quick & easy adjustment.
- Holds blade securely in place. Accepts all SYSTEM 4 blades. 110mm/4.3" OAL

Item					
No.	mm	Inch	mm	Inch	lbs.
28001	4.0	.1574	14.0	.55	.04

**Rotating Cap**  
for precise turning and control

**Tapered Handle**  
allows rapid rotation, requires less clearance

**Precision Handle**  
high quality plastic. ESD Safe or Standard styles

**Tips**  
Exact fit, precision machined

**Blades**  
CVM steel, hardened, hard chromed. On 4mm Hex shafts

Collet Lock Handle adjustable blade length from 15 to 95mm/.6" to 3.75"



### 269 SYSTEM 4 Slotted Reversible Blade

High alloy CVM steel, hardened, hard chromed. Wiha vapor Chrome-Top finish on tips.

Item					
No.	mm	mm	mm	Inch	lbs.
26903	1.5 + 3.0	120	4.7	.05	
26904	2.0 + 3.5	120	4.7	.05	
26905	2.5 + 4.0	120	4.7	.06	



### 269 SYSTEM 4 Phillips Reversible Blade

High alloy CVM steel, hardened, hard chromed. Wiha vapor Chrome-Top finish on tips.

Item					
No.	Size	Size	mm	Inch	lbs.
26911	000 + 00	120	4.7	.03	
26912	0 + 1	120	4.7	.03	



### 269 SYSTEM 4 Combined Slotted/Phillips Reversible Blade

Item					
No.	mm	Size	mm	Inch	lbs.
26971	1.5 + 000	120	4.7	.05	
26972	2.0 + 00	120	4.7	.05	
26973	3.0 + 0	120	4.7	.05	
26974	4.0 + 1	120	4.7	.06	



### 269 SYSTEM 4 Pozidriv® Reversible Blade

High alloy CVM steel, hardened, hard chromed. Wiha vapor Chrome-Top finish on tips.

Item					
No.	Size	Size	mm	Inch	lbs.
26922	0 + 1	120	4.7	.03	



### 269 SYSTEM 4 Metric Ball End & Standard Hex, Reversible Blade

CVM steel, hardened, hard chromed. Wiha vapor Chrome-Top finish on tips.

One side hex, other side ballpoint hex.

Item					
No.	mm	mm	mm	Inch	lbs.
26932	1.3 + 1.3	120	4.7	.05	
26934	2.0 + 2.0	120	4.7	.06	
26935	2.5 + 2.5	120	4.7	.06	
26936	3.0 + 3.0	120	4.7	.06	
26937	4.0 + 4.0	120	4.7	.06	



### 280 SYSTEM 4 Metric Ball End Hex

Interchangeable Blade High alloy tool steel, hardened, corrosion protected. Ball end works at 30° angle entry for easy access to fasteners.

Item					
No.	mm	mm	Inch	lbs.	pkg.
28033	1.5	120	4.7	.06	1
28034	2.0	120	4.7	.06	1
28035	2.5	120	4.7	.06	1
28036	3.0	120	4.7	.06	1
28037	4.0	120	4.7	.06	1



### 280 SYSTEM 4 Inch Ball End Hex

Interchangeable Blade High alloy tool steel, hardened, corrosion protected. Ball end works at 30° angle entry for easy access to fasteners.

Item					
No.	Inch	mm	Inch	lbs.	
28021	.050	120	4.7	.06	
28023	1/16	120	4.7	.06	
28024	5/64	120	4.7	.06	
28025	3/32	120	4.7	.06	
28026	7/64	120	4.7	.06	
28027	1/8	120	4.7	.06	
28028	9/64	120	4.7	.06	
28029	5/32	120	4.7	.06	

### Wiha SYSTEM 4 Precision Blades



**269 SYSTEM 4 Metric Hex Sizes, Interchangeable Blade** High alloy CVM steel, hardened, corrosion protected.

Item						
No.	mm	mm	Inch	lbs.		
26913	0.7	120	4.7	.06		
26914	0.9	120	4.7	.06		
26916	1.5	120	4.7	.06		
26917	2.0	120	4.7	.06		
26918	2.5	120	4.7	.06		
26919	3.0	120	4.7	.06		
26920	4.0	120	4.7	.06		



**269 SYSTEM 4 Inch Hex Sizes, Interchangeable Blade** High alloy CVM steel, hardened, corrosion protected.

Item						
No.	Inch	mm	Inch	lbs.		
26921	.050	120	4.7	.06		
26923	1/16	120	4.7	.06		
26924	5/64	120	4.7	.06		
26925	3/32	120	4.7	.06		
26926	7/64	120	4.7	.06		
26927	1/8	120	4.7	.06		
26928	9/64	120	4.7	.06		
26929	5/32	120	4.7	.06		



**269 SYSTEM 4 TORX® Reversible Blade** High alloy CVM steel, hardened, vapor chrome protected, Wiha vapor Chrome-Top finish on tips. 120mm/4.7" OAL.

Item			
No.	Size	Size	lbs.
26951	T6	+ T8	.03
26952	T7	+ T9	.03
26953	T10	+ T15	.03
26954	T15	+ T20	.03



**269 SYSTEM 4 TORX® Interchangeable Blade** High alloy CVM steel, hardened, Wiha vapor Chrome-Top finish on tips. 120mm/4.7" OAL.

Item		
No.	Size	lbs.
26955	T3	.03
26956	T4	.03
26957	T5	.03

### Wiha SYSTEM 4 Drive-Loc Precision Locking Tools

Blade lengths can be adjusted from 18mm (.7") to 90mm (3.5") Max. In 3mm increments



**26961 ESD Safe Dissipative Precision Drive-Loc Handle** Surface resistant 10<sup>6</sup>-10<sup>9</sup> Ohms. 4 mm hex retainer for all SYSTEM 4 interchangeable blades. Ball retainer hold. 105mm/4.13" OAL

Item					
No.	mm	Inch	mm	Inch	lbs.
26961	4.0	.1574	23	.91	.08



**269 SYSTEM 4 Slotted Drive-Loc Reversible Locking Blades** On 4mm Hex

Item			
No.	mm	mm	lbs.
26958	1.5	+ 3.0	.02
26959	2.0	+ 3.5	.02
26960	2.5	+ 4.0	.02



**269 SYSTEM 4 Phillips Drive-Loc Reversible Locking Blades** On 4mm Hex

Item			
No.	Size	Size	lbs.
26975	000	+ 00	.02
26976	0	+ 1	.02



**269 SYSTEM 4 TORX® Drive-Loc Reversible Locking Blades** On 4mm Hex

Item			
No.	Size	Size	lbs.
26977	T1	+ T2	.02
26978	T3	+ T4	.02
26979	T5	+ T6	.02
26980	T6	+ T8	.02
26981	T7	+ T9	.02
26982	T10	+ T15	.02

Blade lengths can be adjusted from 18mm (.7") to 90mm (3.5") Max. In 3mm increments



**280 SYSTEM 4 Pozidriv® Drive-Loc Reversible Locking Blades** On 4mm Hex

Item			
No.	Size	Size	lbs.
28002	0	+ 1	.02



**280 SYSTEM 4 Metric Ball End Hex & Hex Metric Drive-Loc Reversible Locking Blades** On 4mm Hex blades

Item			
No.	mm	mm	lbs.
28003	1.3	+ 1.3	.02
28004	1.5	+ 1.5	.02
28005	2.0	+ 2.0	.02
28006	2.5	+ 2.5	.02
28007	3.0	+ 3.0	.02
28008	4.0	+ 4.0	.02



**280 SYSTEM 4 Metric Nut Drivers Drive-Loc Locking Blades** On 4mm Hex blades

Item			
No.	mm	mm	lbs.
28009	1.5	+ 1.8	.02 Reversible
28010	2.0	+ 2.5	.02 Reversible
28011	3.0	+ -	.02
28012	3.2	+ -	.02
28013	3.5	+ -	.02
28014	4.0	+ -	.02
28015	4.5	+ -	.02
28016	5.0	+ -	.02
28017	5.5	+ -	.02



**26985 12 Piece SYSTEM 4 Precision ESD Drive-Loc Set** In storage pouch

Item No.	
26985	<b>ESD Safe Drive-Loc Handle</b>
	<b>Slotted:</b> 1.5x3.0, 2.0x3.5, 2.5x4.0 lbs. .44
	<b>Phillips:</b> 000x00, 0x1
	<b>TORX®:</b> T1xT2, T3xT4, T5xT6, T6xT8, T7xT9, T10xT15

 


## ESD Technicians Kit

Precision Screwdrivers & Tweezers




**44590 12 Pc. Slotted, Phillips & TORX®**

**Precision Interchangeable Blade Set** ESD Safe  precision collet lock handle, 7 Wiha interchangeable blades & 4 ESD Safe Tweezers.

**44590 Set includes the following blades:**


 **Slotted:** 2.0, 3.0, 4.0mm

 **Phillips:** 00, 0, 1

 **TORX®:** T5, T6, T7, T8, T9, T10, T15

**ESD Safe Precision Tweezers:**

44501 Fine Point - AA SA

44509 Extra Fine Point - 5 SA 

44505 Flat and Blunt - 2a SA lbs.

 
44510 Curved Fine Point - 7a SA .60

## Slotted, Phillips, TORX® Set



In steel box

 
**28094 11 Pc. Slotted, Phillips & TORX®**

**Precision Interchangeable Blade Set** Wiha ESD Safe  precision collet lock handle and 10 Wiha interchangeable blades.

**28094 Set includes the following blades:**

 **Slotted:** 1.5, 2.0, 3.0, 4.0mm

lbs.  **Phillips:** 000, 00, 0, 1


 
1.51  **TORX®:** T3, T4, T5, T6, T7, T8, T9, T10, T15

## Slotted & Phillips Set





In steel box

**26993 6 Pc. Slotted & Phillips Precision**

**Interchangeable Blade Set** Wiha ESD Safe  precision collet lock handle and 5 Wiha interchangeable blades. 

**26993 Set includes the following blades:**

 **Slotted:** 1.5, 2.0, 2.5, 3.0, 3.5, 4.0mm

 
 **Phillips:** 000, 00, 0, 1

## Precision Interchangeable Blade Sets In Metal Box




**26996 5 Pc. Slotted & Phillips**

**Precision Interchangeable Blade Set**

Wiha ESD Safe  precision collet lock handle and 4 Wiha interchangeable blades.

 
**26996  Phillips:** 000, 00, 0, 1

 **Slotted:** 1.5, 2.0, 3.0, 3.5mm

 lbs. .54




**26995 5 Pc. TORX® Precision Blade Set**

Wiha ESD Safe  precision collet lock handle and 4 interchangeable blades.

 
**26995  TORX®:** T6, T7, T8, T9, T10, T15, T20

 lbs. .52

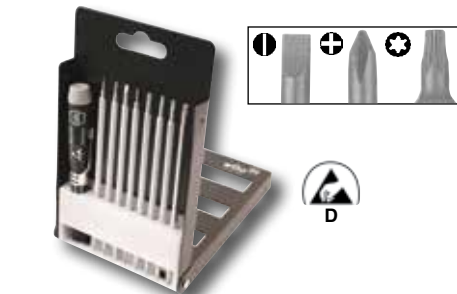



**26997 9 Pc. Slotted, Phillips and TORX®**

**Precision Interchangeable Blade Set**

Wiha ESD Safe  precision collet lock handle and 8 Wiha Interchangeable blades.

**26997  Phillips:** 000, 00, 0, 1


 **Slotted:** 1.5, 2.0, 2.5, 3.0, 3.5, 4.0mm

 **TORX®:** T6, T7, T8, T9, T10, T15

 lbs. .64




**26987 8 Pc. TORX® Precision Blade Set**

Wiha ESD Safe  precision collet lock handle and 7 interchangeable blades.

**26987 Set includes the following blades:**

 **TORX® standard blades:** T3, T4, T5


 **TORX® reversible blades:**

T6, T7, T8, T9, T10, T15, T20

 lbs. .62



**26989 9 Pc. Hex Inch Precision Blade Set**


Wiha ESD Safe  precision collet lock handle and 8 Wiha interchangeable blades.

**26989  Hex Inch:** .050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32"

 
 lbs. .64

**Wiha Canvas Pouch Sets**

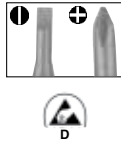

Canvas Pouch



**26990 4 Pc. Slotted & Phillips Precision Interchangeable Blade Set**


Wiha ESD Safe  precision collet lock handle and 3 Wiha interchangeable blades.

**26990 Set includes the following blades:**

 
-  **Slotted:** 2.0, 3.0, 4.0mm
-  **Phillips:** 00, 0, 1

 lbs. .17

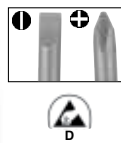

Canvas Pouch




**26991 6 Pc. Slotted & Phillips Precision Interchangeable Blade Set**


Wiha ESD Safe  precision collet lock handle & 5 Wiha interchangeable blades. In canvas pouch.

**26991 Set includes the following blades:**

 
-  **Slotted:** 1.5, 2.0, 2.5, 3.0, 3.5, 4.0mm
-  **Phillips:** 000, 00, 0, 1

 lbs. .29

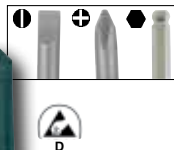


 
Canvas Pouch



**26992 17 Pc. Slotted, Phillips & Ball End Hex Metric/Inch Precision Interchangeable Blade Set**

Wiha ESD Safe  precision collet lock handle & 15 Wiha interchangeable blades.

 
**26992 Set include the following blades:**

-  **Slotted:** 1.5, 2.0, 3.0, 4.0mm
-  **Phillips:** 000, 00, 0, 1
-  **Ball End Hex Inch:** .050, 1/16, 5/64, 7/64, 3/32, 1/8"
-  **Ball End Hex Metric:** 1.5, 2.0, 2.5, 3.0, 4.0mm

**ESD Safe Precision Chip Lifter**

 lbs. .63





 
Canvas Pouch



**28080 22 Pc. Slotted, Phillips, TORX® & Hex Precision Interchangeable Blade Set**

Wiha ESD Safe  precision collet lock handle and 20 Wiha interchangeable blades.

**28080 Set includes the following blades:**

 
-  **Slotted:** 1.5, 2.0, 3.0, 4.0mm
-  **Phillips:** 000, 00, 0, 1
-  **TORX®:** T3, T4, T5, T6, T7, T8, T9, T10, T15
-  **Hex:** .028, .035
-  **Ball Hex:** .050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32"

**ESD Safe Precision Chip Lifter**

 
 lbs. .33

**ESD Anti-Static Vinyl Pouch Set**



ESD Safe



**28091 6 Pc. Slotted & Phillips Precision Interchangeable Blade Set**

Wiha-ESD Safe  precision collet lock handle and 5 Wiha interchangeable blades.

 
**28091 Set includes the following blades:**

-  **Slotted:** 1.5, 2.0, 2.5, 3.0, 3.5, 4.0mm
-  **Phillips:** 000, 00, 0, 1


 lbs. .25

**ESD Anti-Static Vinyl Pouch Set**




ESD Safe



**28097 9 Pc. Slotted, Phillips & TORX® Precision Interchangeable Blade Set**

 
Wiha ESD Safe  precision collet lock handle and 8 Wiha Interchangeable blades.

**28097 Set includes the following blades:**

 
-  **Slotted:** 1.5, 2.0, 3.0, 4.0mm
-  **Phillips:** 000, 00, 0, 1
-  **TORX®:** T5, T6, T7, T8, T9, T10, T15

 lbs. .33



ESD Safe



**28084 13 Pc. Slotted, Phillips & Ball End Hex Inch Precision Interchangeable Blade Set**

Wiha ESD Safe  precision collet lock handle and 12 Wiha interchangeable blades.

**28084 Set includes the following blades:**

 
-  **Slotted:** 1.5, 2.0, 3.0, 4.0mm
-  **Phillips:** 000, 00, 0, 1
-  **Ball End Hex Inch:** .050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32"

 lbs. .44



ESD Safe



**28087 8 Pc. TORX® Precision Interchangeable Blade Set**

Wiha-ESD Safe  precision collet lock handle and 7 Wiha interchangeable blades.


**28087 Includes the following blades:**

-  **TORX® Standard blades:** T3, T4, T5
-  **TORX® Reversible blades:** T6, T7, T8, T9, T10, T15, T20

 lbs. .29

## Wiha SoftFinish® Handle - Ergonomic Cushion Grip

Handle is molded directly onto the blade for a permanent bond

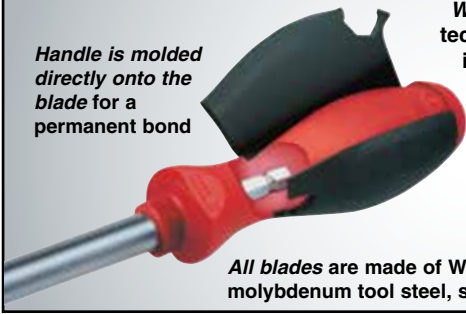

**Wiha SoftFinish® Handle:** Featuring advanced technology dual material molding. A remarkable improvement in handle design, comfort and performance. The SoftFinish® ergonomic shape allows maximum torque and user comfort.

**Wiha Nut Drivers** are precision formed to exact tolerances for a perfect fit every time

All blades are made of Wiha's exclusive formula chrome-vanadium-molybdenum tool steel, super hardened plated for unmatched durability



**341 Nut Driver, With Wiha-SoftFinish® Handle** Inch sizes. Blade CVM steel, hardened. Deep drawn 1" socket. Solid shafts. Wiha-SoftFinish® handle, multi-component, cushion grips.


Item No.	Circle	Square	Hex	Tri	Star	Star	Star	Star	Star	Star
No.	Inch	Inch	mm	mm	Inch	Inch	mm	lbs.	pkg.	
34134	9/64	5.0	125	238	9.4	1.18	30	.18	10	
34135	5/32	5.0	125	238	9.4	1.18	30	.24	10	
34136	3/16	5.0	125	238	9.4	1.18	30	.25	10	
34137	7/32	5.0	125	238	9.4	1.18	30	.26	10	
34138	1/4	5.0	125	246	9.7	1.42	36	.38	10	
34139	5/16	5.0	125	246	9.7	1.42	36	.40	10	
34140	11/32	5.0	125	246	9.7	1.42	36	.40	10	
34141	3/8	5.0	125	246	9.7	1.42	36	.40	10	
34142	7/16	5.0	125	246	9.7	1.61	41	.40	10	
34143	1/2	5.0	125	246	9.7	1.61	41	.40	10	
34144	9/16	5.0	125	246	9.7	1.61	41	.40	10	
34145	5/8	5.0	125	246	9.7	1.61	41	.40	10	

**341 Nut Driver, With Wiha-SoftFinish® Handle** Metric sizes

Item No.	Circle	Square	Hex	Tri	Star	Star	Star	Star	Star
No.	mm	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.
34120	5.0	125	5.0	238	9.4	30	1.18	.14	10
34121	5.5	125	5.0	238	9.4	30	1.18	.14	10
34122	6.0	125	5.0	238	9.4	30	1.18	.15	10
34123	7.0	125	5.0	238	9.4	36	1.42	.25	10
34124	8.0	125	5.0	238	9.4	36	1.42	.25	10
34126	10.0	125	5.0	238	9.4	36	1.42	.27	10
34127	11.0	125	5.0	247	9.7	41	1.61	.37	10
34128	12.0	125	5.0	247	9.7	41	1.61	.40	10
34129	13.0	125	5.0	247	9.7	41	1.61	.40	10
34130	14.0	125	5.0	247	9.7	41	1.61	.40	10
34131	15.0	125	5.0	247	9.7	41	1.61	.40	10
34132	16.0	125	5.0	249	9.8	41	1.61	.42	10
34133	17.0	125	5.0	249	9.8	41	1.61	.42	10

**341 Magnetic Nut Driver, With Wiha-SoftFinish® Handle**

Item No.	Circle	Square	Hex	Tri	Star	Star	Star
No.	mm	mm	Inch	mm	Inch	lbs.	pkg.
34152	5.5	125	5.0	238	9.4	.14	10
34154	5.5	250	9.8	361	14.2	.21	10
34158	7.0	125	5.0	238	9.4	.15	10

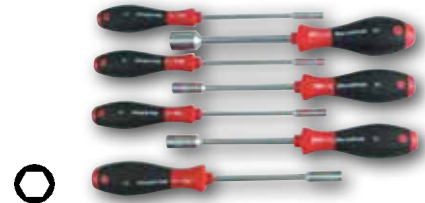

**34193 7 Pcs. Nut Driver Set** Inch sizes. Blade CVM steel, hardened. Deep drawn 1" socket.

Item No.	Circle	Square	Circle	Square	lbs.
No.	Inch	Inch	Inch	Inch	
34193	3/16	5.0	3/8	5.0	1.89
	1/4	5.0	7/16	5.0	
	5/16	5.0	1/2	5.0	
	11/32	5.0			



**34195 10 Piece Nut Driver Set** Inch sizes

Item No.	Circle	Square	Circle	Square	lbs.
No.	Inch	Inch	Inch	Inch	
34195	3/16	5.0	3/8	5.0	3.12
	7/32	5.0	7/16	5.0	
	1/4	5.0	1/2	5.0	
	5/16	5.0	9/16	5.0	
	11/32	5.0	5/8	5.0	



**34194 7 Piece Nut Driver Set** Metric sizes

Item No.	Circle	Square	Circle	Square	lbs.
No.	mm	mm	mm	mm	
34194	5.0	125	8.0	125	1.93
	5.5	125	10.0	125	
	6.0	125	13.0	125	
	7.0	125			



**Wiha SoftFinish® Heavy Duty Nut Drivers**



**347 Nut Driver, With Hex Bolster & Wiha-SoftFinish® Handle**

Blade CVM steel, hardened. Deep drawn 1" socket. Hex bolster for additional torque, Solid shafts. Wiha-SoftFinish® cushion grip handle.

Item No.	mm	mm	Inch	mm	mm	Inch	mm	Inch	lbs.	pkg.
34712	7.0	125	5.0	10.0	238	9.4	36	1.42	.25	10
34715	8.0	125	5.0	10.0	238	9.4	36	1.42	.25	10
34718	9.0	125	5.0	10.0	238	9.4	36	1.42	.26	10
34721	10.0	125	5.0	10.0	238	9.4	36	1.42	.27	10
34724	11.0	125	5.0	13.0	247	9.7	41	1.61	.37	10
34727	12.0	125	5.0	13.0	247	9.7	41	1.61	.40	10
34730	13.0	125	5.0	13.0	247	9.7	41	1.61	.40	10



**34791 5 Piece Nut Driver Set Metric sizes**

Item No.	mm	mm	mm	mm	lbs.
34791	5.0*	125	10.0	125	1.42
	6.0*	125	11.0	125	
	8.0	125			

\*Standard blade - no hex bolster



**34792 6 Piece Nut Driver Set Inch sizes**

Item No.	Inch	Inch	Inch	Inch	lbs.
34792	3/16	5.0	3/8	5.0	1.94
	1/4	5.0	7/16	5.0	
	5/16	5.0	1/2	5.0	



**347 Nut Driver, Hex Bolster & Wiha-SoftFinish® Handle Inch sizes**

Item No.	Inch	Inch	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.
34753	3/16	5.0	125	5/16	231	9.1	36	1.42	.18	10
34759	1/4	5.0	125	3/8	238	9.4	36	1.42	.24	10
34765	5/16	5.0	125	3/8	238	9.4	36	1.42	.25	10
34771	3/8	5.0	125	3/8	238	9.4	36	1.42	.26	10
34774	7/16	5.0	125	1/2	246	9.7	41	1.61	.38	10
34777	1/2	5.0	125	1/2	246	9.7	41	1.61	.40	10

**Wiha SoftFinish® Metric Nut Drivers - Hollow Shaft**

- Hollow shafts allow for fit over extended bolts
- Finally a handle that makes Nut Drivers useful
- Get 40% more power with SoftFinish cushion grip
- Soft ergonomic molded shape for maximum comfort
- Hardened for maximum torque and wear resistance
- Heavy duty hollow shaft - 3.7" depth
- Chrome plated anti corrosion finish



**343 Hollow Shaft Nut Driver With Wiha-SoftFinish® Handle Metric**

Item No.	mm	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.
34302	5.0	70	2.75	175	7.0	36	1.42	.14	10
34304	5.5	70	2.75	175	7.0	36	1.42	.14	10
34306	6.0	70	2.75	175	7.0	36	1.42	.15	10
34308	7.0	70	2.75	182	7.5	41	1.61	.25	10
34310	8.0	70	2.75	182	7.5	41	1.61	.25	10
34312	10.0	70	2.75	187	7.6	41	1.61	.27	10
34314	13.0	70	2.75	187	7.6	41	1.61	.40	10



**34391 7 Piece Hollow Shaft Nut Driver Set Metric Sizes**

Item No.	mm	mm	mm	mm	lbs.
34391	5.0	70	8.0	70	1.41
	5.5	70	10.0	70	
	6.0	70	13.0	70	
	7.0	70			

## Long Flexible Shaft Nut Drivers, SoftFinish® Handle - Ergonomic Cushion Grip



**372 Long Flexible Shaft Nut Driver, With Wiha-SoftFinish® Handle** Inch sizes. Heavy Duty flexible shaft of braided steel with protective sleeve. Hardened mounted socket for optimal torque. Wiha-SoftFinish® handle, multi-component, cushion grips.

Item	⊙	⊖	⊖	⊖	⊖	⊖	⊖	⊖	⊖
No.	Inch	Inch	mm	mm	Inch	mm	Inch	lbs.	pkg.
37220	3/16	5.9	150	261	10.2	30	1.18	.30	1
37222	1/4	5.9	150	261	10.2	36	1.42	.42	1
37224	5/16	5.9	150	261	10.2	36	1.42	.44	1
37226	3/8	6.9	175	261	10.2	36	1.42	.44	1
37228	7/16	6.9	175	261	10.2	41	1.61	.44	1
37230	1/2	6.9	175	261	10.2	41	1.61	.44	1



**372 Long Flexible Shaft Nut Driver, With Wiha-SoftFinish® Handle** Metric sizes. Heavy Duty flexible shaft of braided steel with protective sleeve. Hardened mounted socket for optimal torque. Wiha-SoftFinish® handle, multi-component, cushion grips.

Item	⊙	⊖	⊖	⊖	⊖	⊖	⊖	⊖	⊖
No.	mm	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.
37235	5.0	150	5.9	261	10.2	30	1.18	.16	1
37236	5.5	150	5.9	261	10.2	30	1.18	.16	1
37237	6.0	150	5.9	261	10.2	30	1.18	.17	1
37238	7.0	150	5.9	261	10.2	36	1.42	.28	1
37239	8.0	150	5.9	261	10.2	36	1.42	.28	1
37241	10.0	175	6.9	261	10.2	41	1.61	.44	1
37244	13.0	175	6.9	261	10.2	41	1.61	.44	1



**37290 6 Piece Flexible Shaft Nut Driver Set, Inch Sizes**

Item	⊙	⊖	⊙	⊖	⊖
No.	Inch	Inch	Inch	Inch	lbs.
37290	3/16	5.9	3/8	6.9	2.50
	1/4	5.9	7/16	6.9	
	5/16	5.9	1/2	6.9	



**37291 7 Piece Flexible Shaft Nut Driver Set, Metric Sizes**

Item	⊙	⊖	⊙	⊖	⊖
No.	mm	mm	mm	mm	lbs.
37291	5.0	150	8.0	150	1.93
	5.5	150	10.0	175	
	6.0	150	13.0	175	
	7.0	150			

## Wiha SoftFinish® Inch Nut Drivers - Hollow Shaft



**343 Hollow Shaft Nut Driver-Wiha-SoftFinish® Handle** Inch sizes

Item	⊙	⊖	⊖	⊖	⊖	⊖	⊖	⊖	⊖
No.	Inch	Inch	mm	mm	Inch	mm	Inch	lbs.	pkg.
34336	3/16	2.75	70	175	7.0	30	1.18	.18	10
34338	1/4	2.75	70	175	7.0	30	1.18	.24	10
34339	5/16	2.75	70	175	7.0	36	1.42	.25	10
34340	11/32	2.75	70	182	7.5	36	1.42	.25	10
34341	3/8	2.75	70	182	7.5	36	1.42	.26	10
34342	7/16	2.75	70	187	7.6	41	1.61	.38	10
34343	1/2	2.75	70	187	7.6	41	1.61	.40	10



**34390 7 Piece Hollow Shaft Nut Driver Set, Inch Sizes**

Item	⊙	⊖	⊙	⊖	⊖
No.	Inch	Inch	Inch	Inch	lbs.
34390	3/16	2.75	3/8	2.75	1.55
	1/4	2.75	7/16	2.75	
	5/16	2.75	1/2	2.75	
	11/32	2.75			



Inch Color Coded To Size


**Wiha SoftFinish® Triangle Nut Drivers**



**344 Triangle Nut Driver, With Wiha-SoftFinish® Handle**

Blade Chrome-vanadium-molybdenum steel, hardened. Wiha-SoftFinish® cushion grip handle.

Item No.	Size	mm	Inch	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.
34474	M4	6.8	.267	125	5"	236	9.3	30	1.18	.17	10
34475	M5	8.3	.326	125	5"	236	9.3	30	1.18	.19	10
34476	M6	10.1	.413	125	5"	236	9.3	30	1.18	.21	10
34478	M8	12.1	.474	125	5"	243	9.6	36	1.42	.23	10
34480	M10	15.1	.592	125	5"	243	9.6	36	1.42	.25	10
34482	M12	16.1	.651	125	5"	243	9.6	41	1.61	.27	10

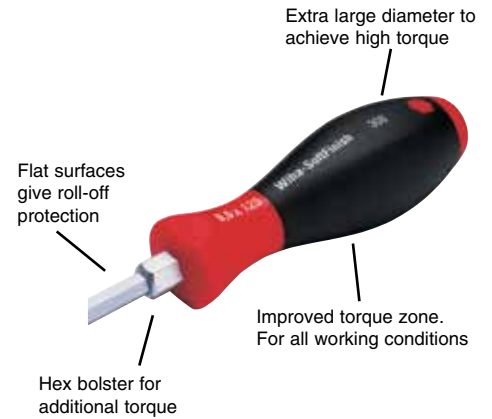

**Wiha T-Handle Nut Drivers**



**336 Nut Driver, With Wiha T-handle** Blade CVM steel, hardened, nickel-plated.

Wiha T-handle high quality plastic, impact resistant. Deep drawn 1" socket, solid shaft.

Item No.	Inch	Inch	mm	Inch	mm	Inch	mm	lbs.	pkg.
33653	3/16	6.0	150	7.2	182	4.0	100	.16	10
33659	1/4	6.0	150	7.2	182	4.0	100	.18	10
33665	5/16	6.0	150	7.2	182	4.0	100	.19	10
33671	3/8	6.0	150	7.2	182	4.0	100	.20	10
33674	7/16	6.0	150	7.2	182	4.0	100	.26	10
33677	1/2	6.0	150	7.2	182	4.0	100	.30	10



**33690 6 Pc. Nut Driver T-handle Set**

Inch Sizes. Blade CVM steel, hardened, nickel-plated. Wiha T-handle high quality plastic, impact resistant. Deep drawn 1" socket, solid shaft.

Item No.	Inch	Inch	Inch	Inch	lbs.
33690	3/16	6.0	3/8	6.0	1.61
	1/4	6.0	7/16	6.0	
	5/16	6.0	1/2	6.0	



**336 Nut Driver, With Wiha T-handle** Blade CVM steel, hardened, nickel-plated. Wiha T-handle high quality plastic, impact resistant. Deep drawn 1" socket, solid shaft.

Item No.	mm	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.
33603	6.0	125	4.9	157	6.2	100	4.0	.16	10
33606	8.0	125	4.9	157	6.2	100	4.0	.18	10
33607	8.0	200	7.9	232	9.1	100	4.0	.22	10
33609	9.0	125	4.9	157	6.2	100	4.0	.23	10
33612	10.0	125	4.9	157	6.2	100	4.0	.24	10
33614	10.0	230	9.0	262	10.3	100	4.0	.26	10
33620	12.0	125	4.9	157	6.2	100	4.0	.26	10
33622	13.0	125	4.9	157	6.2	100	4.0	.27	10
33623	13.0	230	9.0	262	10.3	100	4.0	.30	10



**33691 5 Piece Nut Driver T-handle Set**

Metric Sizes. Blade CVM steel, hardened, nickel-plated. Wiha T-handle high quality plastic, impact resistant. Deep drawn 1" socket, solid shaft.

Item No.	mm	mm	mm	mm	lbs.
33691	6.0	125	10.0	125	1.57
	8.0	125	13.0	125	
	9.0	125			





## Wiha Drive-Loc VI Nut Drivers



Locking mechanism in Wiha SoftFinish® cushion grip ergonomic handle. Blade length can be adjusted from 40mm-120mm. (1.7 to 4.7" In 1/8" increments)

**See Drive-Loc VI Handles & Screwdrivers on pages 19-20**

### Drive-Loc VI

For Adjustable Length Locking Blades



The blade length can be adjusted from 40mm-120mm. (1.7 to 4.7")



#### 281 Drive-Loc VI Inch Nut Driver Blades

High alloy CVM steel, through hardened, hard chrome finish. OAL blade length 150mm/5.9". Blades fit all Drive-Loc VI handles.

Item No.	Inch	OAL	lbs.	pkg.
28156	3/16	5.9"	.11	1
28157	7/32	5.9"	.11	1
28158	1/4	5.9"	.11	1
28159	9/32	5.9"	.12	1
28160	5/16	5.9"	.13	1
28161	11/32	5.9"	.14	1
28162	3/8	5.9"	.15	1
28163	7/16	5.9"	.17	1
28164	1/2	5.9"	.18	1



#### 281 Drive-Loc VI Metric Nut Driver Blades

High alloy CVM steel, through hardened, hard chrome finish. OAL blade length 150mm/5.9". Blades fit all Drive-Loc VI handles.

Item No.	mm	OAL	lbs.	pkg.
28168	4.0	150mm	.10	1
28169	4.5	150mm	.10	1
28170	5.0	150mm	.11	1
28171	5.5	150mm	.11	1
28172	6.0	150mm	.12	1
28173	7.0	150mm	.13	1
28174	8.0	150mm	.13	1
28177	9.0	150mm	.14	1
28175	10.0	150mm	.15	1
28176	11.0	150mm	.20	1



#### 28196 8 Pc. Drive-Loc VI Interchangeable Blade Set, In Durable Pouch

Set includes Drive-Loc VI handle & 7 Inch Nut Driver blades.

Item No.	lbs.
28196	1.22

Inch: 3/16, 1/4, 5/16, 11/32, 3/8, 7/16, 1/2"  
SoftFinish® Cushion Grip Blade Lock Handle



#### 28198 8 Pc. Drive-Loc VI Interchangeable Blade Set, In Durable Pouch

Set includes Drive-Loc VI handle & 7 Metric Nut Driver blades.

Item No.	lbs.
28198	1.00

Metric: 5.0, 5.5, 6.0, 7.0, 8.0, 9.0, 10.0mm  
SoftFinish® Cushion Grip Blade Lock Handle



#### 28144 Extension Blade For Drive-Loc VI Blades

High alloy CVM steel, through hardened, hard chrome finish. OAL blade length 6.5". Blades fit all Drive-Loc VI handles.

Item No.	mm	OAL	lbs.	pkg.
28144	6.0	150mm	.14	1

## Pico Soft Grip Nut Drivers



#### 265 Inch Nut Drivers, With Precision Soft PicoFinish Handle

Blade high alloy CVM tool steel, hardened, hard chrome finish.

Item No.	Inch	Inch	Inch	Inch	pkg.
26571	3/32	2.4	6.3	.71	10
26572	7/64	2.4	6.3	.71	10
26573	1/8	2.4	6.3	.71	10
26574	9/64	2.4	6.3	.71	10
26575	5/32	2.4	6.3	.71	10
26576	3/16	2.4	6.3	.71	10
26577	7/32	2.4	6.3	.71	10
26578	1/4	2.4	6.3	.71	10

\*Metric dimensions actual - Inch dimensions approximate



#### 265 Metric Nut Drivers, With Precision PicoFinish Handle

Blade high alloy CVM tool steel, hardened, hard chrome finish.

Item No.	mm	mm	mm	mm	mm	mm	pkg.
26579	1.5	60	160	2.5	3.0	18	10
26581	2.0	60	160	3.2	4.0	18	10
26582	2.5	60	160	4.0	4.0	18	10
26583	3.0	60	160	5.0	5.0	18	10
26584	3.5	60	160	5.3	6.0	18	10
26585	4.0	60	160	5.5	6.0	18	10
26586	4.5	60	160	6.2	7.0	18	10
26587	5.0	60	160	6.8	7.0	18	10
26588	5.5	60	160	7.6	8.0	18	10
26589	6.0	60	160	8.2	9.0	18	10

\*Metric dimensions actual - Inch dimensions approximate



#### 26593 8 Piece Inch Nut Driver Set, With Precision Soft PicoFinish Handle

In storage pouch

Item No.	Inch Nut Drivers:	lbs.
26593	3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4" x 2.4"	.72

#### 26596 8 Piece Metric Nut Driver Set, With Precision Soft PicoFinish Handle

In storage pouch

Item No.	Metric Nut Drivers:	lbs.
26596	2.0, 2.5, 3.0, 3.5, 4.0, 4.5, 5.0, 5.5 x 60mm	.66

**Wiha Nut Driver Precision Series**



**265 Metric Metric Nut Driver With Precision Handle** Metric sizes.

Blade Chrome-Vanadium-Molybdenum steel. Hard chrome finished.

Item No.	mm	mm	Inch	mm	Inch	mm	mm	lbs.	pkg.
26510	1.5	60	2.4	140	5.5	2.5	3.0	.03	10
26515	1.8	60	2.4	140	5.5	2.9	3.5	.03	10
26520	2.0	60	2.4	140	5.5	3.2	4.0	.04	10
26525	2.5	60	2.4	155	6.1	4.0	4.0	.04	10
26530	3.0	60	2.4	155	6.1	5.0	5.0	.05	10
26532	3.2	60	2.4	155	6.1	5.0	5.0	.05	10
26535	3.5	60	2.4	155	6.1	5.3	6.0	.05	10
26540	4.0	60	2.4	155	6.1	5.5	6.0	.05	10
26545	4.5	60	2.4	155	6.1	6.2	7.0	.05	10
26550	5.0	60	2.4	155	6.1	6.8	7.0	.05	10
26555	5.5	60	2.4	170	6.7	7.6	8.0	.06	10
26560	6.0	60	2.4	170	6.7	8.2	9.0	.06	10
26570	7.0	60	2.4	170	6.7	9.6	10.0	.06	10

\*Metric dimensions actual - Inch dimensions approximate



**265 Inch Inch Nut Driver With Precision Handle** Inch sizes.

Blade Chrome-Vanadium-Molybdenum steel. Hard chrome finished.

Item No.	Inch	mm	Inch	mm	Inch	Inch	Inch	lbs.	pkg.
26523	3/32	60	2.4	155	6.1	.16	.16	.04	10
26527	7/64	60	2.4	155	6.1	.20	.20	.05	10
26531	1/8	60	2.4	155	6.1	.20	.20	.05	10
26536	9/64	60	2.4	155	6.1	.21	.24	.05	10
26539	5/32	60	2.4	155	6.1	.22	.24	.05	10
26547	3/16	60	2.4	155	6.1	.25	.28	.05	10
26556	7/32	60	2.4	170	6.7	.30	.32	.06	10
26563	1/4	60	2.4	170	6.7	.34	.36	.06	10

\*Metric dimensions actual - Inch dimensions approximate



**26599 8 Pc. Precision Nut Driver Set - Inch**  
Blade high alloy CVM steel. Hard chrome finished. In canvas storage pouch

Item No.	Inch Nut Drivers:	lbs.
26599	3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4" x 2.4"	.72



**26590 8 Pc. Precision Nut Driver Set - Metric**  
Blade CVM steel.

Item No.	Metric Nut Drivers:	lbs.
26590	2.5, 3.0, 3.5, 4.0, 4.5, 5.0, 5.5, 6.0mm x 60mm	.48

Item No.	Set 7 Pcs. Nut Driver Metric
26592	1.5, 1.8, 2.0, 2.5, 3.0, 3.5, 4.0mm



**26598 8 Pc. Precision Nut Driver Set - Metric**  
Blade high alloy CVM steel. Hard chrome finished. In canvas storage pouch

Item No.	Metric Nut Drivers:	lbs.
26598	2.5, 3.0, 3.5, 4.0, 4.5, 5.0, 5.5, 6.0mm x 60mm	.70



**26591 8 Pc. Precision Nut Driver Set - Inch**  
Blade CVM steel.

Item No.	Inch Nut Drivers:	lbs.
26591	3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4" x 2.4"	.47

**Rotating Cap**  
for precise turning and control

**Tapered Handle**  
allows rapid rotation, requires less clearance

**Precision Handle**  
high quality plastic, cadmium free. ESD Safe or Standard styles

**Blades**  
CVM steel, hardened, hard chromed

**Tips**  
Exact fit, precision machined

15mm  
Collet Lock Handle adjustable blade length from 15 to 95mm/.6" to 3.75"  
95mm



**269 SYSTEM 4 Nut Driver Inch, Interchangeable Blade** High alloy CVM steel, hardened, corrosion protected. On 4mm Hex shaft. 120mm/4.7" OAL

Item No.	Inch	Inch	Inch	lbs.
26962	3/32	.16	.16	.04
26963	7/64	.20	.20	.04
26964	1/8	.20	.20	.04
26965	9/64	.21	.24	.04
26966	5/32	.22	.24	.04
26967	3/16	.26	.28	.04
26968	7/32	.30	.32	.04
26969	1/4	1.34	.36	.04



**269 SYSTEM 4 Nut Driver Metric, Interchangeable Blade** High alloy CVM steel, hardened, corrosion protected. On 4mm Hex Shaft. 120mm/4.7" OAL

Item No.	mm	mm	Inch	Inch	lbs.
26940	1.5 + 1.8		.12	.12	.03
26941	2.0 + 2.5		.16	.16	.03
26938	1.5 -		.11	.11	.04
26939	1.8 -		.12	.12	.04
26949	2.0 -		.13	.13	.06
26950	2.5 -		.16	.16	.06
26942	3.0 -		.20	.20	.06
26943	3.2 -		.20	.20	.06
26944	3.5 -		.22	.24	.06
26945	4.0 -		.22	.24	.06
26946	4.5 -		.25	.28	.06
26947	5.0 -		.27	.28	.06
26948	5.5 -		.30	.32	.06

## SYSTEM 4 Compact Fold-out box Sets & Pouch Sets

See **SYSTEM 4 Handles & Blades** on pages 33-36



- ESD Safe Precision Handle
- High alloy CVM steel, hardened
- Exact fit tips
- In metal storage box

## SYSTEM 4 Nut Driver Sets



**26988 9 Pc. Nut Driver Inch Precision Blade Set** Wiha ESD Safe precision collet lock handle & 8 Wiha interchangeable blades.

**26988 Set includes the following blades:**

- Nut Driver Inch: 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4"
- ↵ lbs. .65



**28088 9 Piece Nut Driver Inch Precision Blade Set** Wiha ESD Safe precision collet lock handle and 8 Wiha interchangeable blades.

**28088 Set includes the following blades:**

- Nut Driver Inch: 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4"
- ↵ lbs. .37



**26998 9 Pc. Nut Driver Metric Precision Blade Set** Wiha ESD Safe precision collet lock handle and 8 Wiha interchangeable blades.

**26998 Set includes the following blades:**

- Nut Driver Metric: 2.0, 2.5, 3.0, 3.2, 3.5, 4.0, 4.5, 5.0, 5.5mm
- ↵ lbs. .68



**28098 8 Pc. Nut Driver Metric Precision Blade Set** Wiha ESD Safe precision collet lock handle and 7 Wiha interchangeable blades.

**28098 Set includes the following blades:**

- Nut Driver Metric: 3.0, 3.2, 3.5, 4.0, 4.5, 5.0, 5.5mm
- ↵ lbs. .40



Item No.	Page	Item No.	Page	Item No.	Page	Item No.	Page	Item No.	Page	Item No.	Page
10810	19	26041	27	26336	28	26560	43	26792	29	26966	44
15305	24	26042	27	26340	28	26563	43	26793	32	26967	44
15310	24	26050	31	26341	32	26570	43	26794	30	26968	44
15315	24	26051	31	26343	32	26571	42	26796	32	26969	44
15325	24	26052	31	26345	32	26572	42	26798	31	26971	34
15330	24	26053	31	26347	32	26573	42	26799	29	26972	34
15335	24	26054	31	26349	32	26574	42	26810	27	26973	34
15340	24	26055	31	26351	32	26575	42	26815	32	26974	34
16112	24	26056	31	26353	32	26576	42	26900	34	26975	35
16134	24	26060	31	26363	32	26577	42	26901	34	26976	35
18601	24	26061	31	26367	32	26578	42	26903	34	26977	35
18603	24	26063	31	26369	32	26579	42	26904	34	26978	35
18606	24	26065	31	26371	32	26581	42	26905	34	26979	35
18609	24	26066	31	26390	28	26582	42	26911	34	26980	35
18612	24	26068	31	26391	28	26583	42	26912	34	26981	35
18615	24	26070	31	26392	32	26584	42	26913	35	26982	35
18624	24	26072	31	26393	32	26585	42	26914	35	26985	35
18627	24	26073	31	26399	28	26586	42	26916	35	26987	36
18630	24	26074	31	26413	29	26587	42	26917	35	26988	44
18642	24	26076	31	26415	29	26588	42	26918	35	26989	36
18645	24	26079	31	26416	29	26589	42	26919	35	26990	37
18648	24	26080	31	26419	29	26590	43	26920	35	26991	37
18651	24	26090	27	26420	29	26591	43	26921	35	26992	37
18654	24	26092	28	26423	29	26592	43	26922	34	26993	36
18657	24	26093	31	26425	29	26593	42	26923	35	26995	36
18663	24	26099	27	26427	29	26596	42	26924	35	26996	36
18678	24	26100	27	26430	29	26598	43	26925	35	26997	36
18681	24	26101	27	26431	29	26599	43	26926	35	26998	4
20700	24	26102	27	26436	29	26701	29	26927	35	28000	34
20705	24	26105	27	26439	29	26702	29	26928	35	28001	34
20710	24	26107	27	26440	29	26703	29	26929	35	28002	35
20715	24	26108	27	26441	32	26704	29	26932	34	28003	35
20720	24	26109	27	26443	32	26705	29	26933	34	28004	35
20725	24	26110	27	26445	32	26706	29	26934	34	28005	35
20756	24	26113	27	26447	32	26707	29	26935	34	28006	35
20757	24	26114	27	26449	32	26708	29	26936	34	28007	35
20758	24	26115	27	26455	32	26709	29	26937	34	28008	35
20759	24	26130	31	26457	32	26710	29	26938	44	28009	35
20760	24	26132	31	26459	32	26715	29	26939	44	28010	35
20790	24	26133	31	26461	32	26720	29	26940	44	28011	35
20799	24	26135	31	26463	32	26721	31	26941	44	28012	35
21103	14	26136	31	26465	32	26723	31	26942	44	28013	35
21105	14	26140	31	26467	32	26725	31	26943	44	28014	35
22220	24	26142	31	26490	29	26727	31	26944	44	28015	35
22230	24	26145	31	26491	29	26729	31	26945	44	28016	35
22240	24	26190	27	26493	32	26731	31	26946	44	28017	35
26000	27	26192	28	26499	29	26732	32	26947	44	28021	34
26001	27	26193	31	26510	43	26735	32	26948	44	28023	34
26008	27	26194	28	26515	43	26736	32	26949	44	28024	34
26010	27	26197	27	26520	43	26737	32	26950	44	28025	34
26012	27	26199	27	26523	43	26739	32	26951	35	28026	34
26015	27	26205	28	26525	43	26741	32	26952	35	28027	34
26018	27	26210	28	26527	43	26743	32	26953	35	28028	34
26020	27	26307	28	26530	43	26745	32	26954	35	28029	34
26022	27	26309	28	26531	43	26747	32	26955	35	28033	34
26023	27	26313	28	26532	43	26749	32	26956	35	28034	34
26025	27	26315	28	26535	43	26751	32	26957	35	28035	34
26027	27	26316	28	26536	43	26761	30	26958	35	28036	34
26028	27	26320	28	26539	43	26762	30	26959	35	28037	34
26030	27	26323	28	26540	43	26763	30	26960	35	28080	37
26032	27	26325	28	26545	43	26764	30	26961	35	28084	37
26033	27	26327	28	26547	43	26765	30	26962	44	28087	37
26034	27	26330	28	26550	43	26766	30	26963	44	28088	44
26035	27	26331	28	26555	43	26790	29	26964	44	28091	37
26040	27	26333	28	26556	43	26791	29	26965	44	28094	36

Item No.	Page	Item No.	Page	Item No.	Page	Item No.	Page	Item No.	Page	Item No.	Page
28097	37	28197	21	30816	5	34132	38	36203	9	36299	11
28098	44	28198	42	30817	5	34133	38	36205	23	36710	12
28103	14	28199	21	30820	5	34134	38	36207	9	36713	12
28105	19	28474	20	30825	5	34135	38	36210	23	36715	13
28106	19	28476	20	30830	5	34136	38	36211	11	36716	12
28107	19	28477	20	30835	5	34137	38	36212	23	36719	12
28108	19	28479	20	30892	5	34138	38	36215	23	36720	13
28109	19	28483	20	30896	5	34139	38	36220	23	36723	12
28110	19	28485	20	30898	5	34140	38	36223	11	36725	13
28112	19	28486	19	30942	11	34141	38	36225	23	36726	12
28114	19	28487	19	31105	6	34142	38	36228	11	36728	12
28116	20	28488	19	31110	6	34143	38	36229	11	36730	13
28117	20	28489	14	31112	6	34144	38	36230	23	36732	12
28118	20	30202	6	31114	6	34145	38	36233	11	36734	12
28119	20	30203	6	31115	6	34152	38	36234	9	36736	12
28120	20	30204	6	31117	6	34154	38	36235	23	36738	12
28122	20	30205	6	31118	6	34158	38	36238	11	36740	13
28123	20	30206	6	31120	6	34193	38	36239	11	36742	12
28124	20	30208	6	31125	6	34194	38	36240	23	36744	12
28126	19	30210	6	31135	7	34195	38	36243	11	36750	13
28127	19	30211	6	31137	8	34302	39	36244	9	36760	13
28128	19	30212	6	31140	7	34304	39	36245	23	36780	13
28129	19	30215	6	31190	7	34306	39	36248	11	36786	13
28130	19	30216	6	31191	7	34308	39	36249	9	36790	13
28132	19	30217	6	31192	7	34310	39	36250	23	36791	12
28133	19	30218	6	31193	7	34312	39	36253	11	36792	13
28134	19	30219	6	31194	8	34314	39	36254	9	36793	12
28135	19	30220	6	31201	5	34336	40	36255	11	36794	12
28136	19	30221	6	31202	5	34338	40	36256	9	37220	40
28137	19	30222	6	31203	5	34339	40	36257	9	37222	40
28138	19	30223	6	31305	8	34340	40	36258	9	37224	40
28139	19	30225	6	31310	8	34341	40	36259	10	37226	40
28140	19	30226	6	31312	8	34342	40	36264	10	37228	40
28142	19	30227	6	31315	8	34343	40	36266	10	37230	40
28143	19	30230	6	31320	8	34390	40	36267	10	37235	40
28144	42	30232	6	32644	11	34391	39	36268	10	37236	40
28149	20	30235	6	33603	41	34474	41	36269	10	37237	40
28150	20	30236	6	33606	41	34475	41	36270	10	37238	40
28151	20	30237	8	33607	41	34476	41	36271	10	37239	40
28156	42	30238	6	33609	41	34478	41	36272	10	37241	40
28157	42	30239	7	33612	41	34480	41	36273	10	37244	40
28158	42	30255	7	33614	41	34482	41	36274	10	37290	40
28159	42	30265	7	33620	41	34712	39	36275	10	37291	40
28160	42	30276	5	33622	41	34715	39	36276	10	38450	14
28161	42	30290	7	33623	41	34718	39	36277	10	38460	14
28162	42	30291	7	33653	41	34721	39	36278	10	38600	14
28163	42	30294	6	33659	41	34724	39	36279	10	39700	9
28164	42	30295	8	33665	41	34727	39	36280	10	39701	9
28168	42	30297	6	33671	41	34730	39	36281	10	39702	9
28169	42	30298	6	33674	41	34753	39	36282	10	39825	9
28170	42	30299	8	33677	41	34759	39	36283	10	39830	9
28171	42	30517	8	33690	41	34765	39	36284	10	39840	9
28172	42	30520	8	33691	41	34771	39	36285	10	39850	9
28173	42	30523	8	34120	38	34774	39	36286	10	39860	9
28174	42	30526	8	34121	38	34777	39	36287	10	39892	9
28175	42	30530	8	34122	38	34791	39	36288	10	39896	9
28176	42	30535	8	34123	38	34792	39	36290	9	40010	11,33
28177	42	30540	8	34124	38	35800	7	36291	10	44590	36
28187	20	30550	8	34126	38	35801	7	36292	23	45040	16
28188	20	30560	8	34127	38	35802	7	36293	23	45050	16
28189	21	30580	8	34128	38	35803	7	36294	10	45052	16
28191	20	30813	5	34129	38	35894	7	36296	11	45054	16
28194	21	30814	5	34130	38	36201	10	36297	11	45055	16
28196	42	30815	5	34131	38	36202	9	36298	10	45056	16

Item No.	Page	Item No.	Page	Item No.	Page	Item No.	Page	Item No.	Page	Item No.	Page
45057	16	46097	16	53020	4	76048	26				
45058	16	46098	16	53025	4	76049	26				
45060	16	46099	15	53027	4	76050	26				
45061	16	46702	18	53035	4	76051	26				
45062	16	46704	18	53040	4	76052	26				
45064	16	46706	18	53075	4	76053	26				
45065	16	46708	18	53090	4	76054	26				
45067	16	46710	18	53096	4	76056	25				
45069	16	46712	18	53097	5	76057	25				
45135	16	46714	18	53099	5	76058	25				
45137	16	46715	18	53110	4	76079	26				
45140	16	46716	18	53115	4	76087	26				
45142	16	46718	18	53120	4	76088	25				
45144	16	46720	18	53310	22	76089	25				
45147	16	46722	18	53315	22	76090	26				
45150	16	46724	18	53320	22	76091	25				
45152	16	46725	18	53325	22	76092	26				
45190	16	46726	18	53330	22	76093	25				
45205	17	46728	18	53390	22	76094	25				
45207	17	46730	18	53398	22	76095	25				
45215	17	46740	18	53405	22	76096	26				
45220	17	46750	18	53410	22	76098	26				
45225	17	46760	18	53425	22	76099	26				
45230	17	46780	18	62990	33	91118	30				
45235	17	46786	18	62993	33	92189	30				
45504	17	46790	15	62994	33	92190	30				
45505	23	46793	18	62995	33	92191	30				
45506	23	46794	18	65090	33	95190	33				
45507	17	46796	18	76000	25	96800	33				
45508	17	46797	18	76001	26						
45509	17	46799	18	76002	26						
45510	17	48190	14	76003	26						
45511	23	48400	23	76004	26						
45515	17	48401	15	76008	26						
45516	23	51099	14	76009	26						
45520	17	52005	21	76010	26						
45521	23	52010	21	76011	25						
45522	23	52020	21	76012	25						
45525	17	52025	21	76013	25						
45526	23	52035	21	76015	26						
45527	17	52040	21	76020	26						
45530	17	52050	21	76022	25						
45531	23	52090	21	76023	25						
45536	23	52097	21	76024	25						
45540	17	52098	21	76025	26						
45541	23	52099	21	76027	26						
45545	17	52105	21	76030	26						
45546	23	52110	21	76031	25						
45550	17	52115	21	76032	25						
45551	23	52120	21	76033	25						
45561	23	52125	21	76034	25						
45589	23	52650	22	76035	25						
45591	23	52711	22	76036	25						
45592	23	52713	22	76037	25						
45593	17	52716	22	76038	25						
45595	17	52719	22	76039	25						
45597	17	52722	22	76040	26						
45598	17	52726	22	76041	25						
45831	15	52729	22	76042	25						
45832	15	52732	22	76043	25						
45833	15	52790	22	76044	25						
45891	15	52791	22	76045	26						
46094	16	53010	4	76046	26						
46095	16	53015	4	76047	26						

**CALIFORNIA PROPOSITION 65 WARNING**

These products contain chemicals known to the state of California to cause cancer and birth defects or other reproductive harm.  
(California law requires this warning to be given to customers in the state of California.)



MANUFACTURING  
EXCELLENCE  
AWARD  
BESTES KMU  
2014

WIHA – WINNER OF THE  
MX AWARD 2014.  
GERMANY'S BEST SME.



Like Us On  
facebook



Tools that work for you



(800) 494-6104  
fax: (800) 494-7456  
cservice@wihatools.com  
www.wihatools.com



**Wiha Quality Tools**

1348 Dundas Circle  
Monticello, MN 55362  
tel: 763.295.6591  
fax: 763.295.6598

**Wiha Tools Canada Ltd.**

www.wihatools.ca  
Brampton, ONT L6T 4X4  
tel: 866.494.0096 or 763.295.6591  
fax: 763.295.6598

To:


**SEE OUR  
GREAT  
WEB  
SPECIALS!**

Catalog Item No. 99002 .wo  
version - 4/1/17

Subject to change without notice

©2017 Willi Hahn Corporation

®Torx is a registered trademark of  
Acument Intellectual Properties LLC.

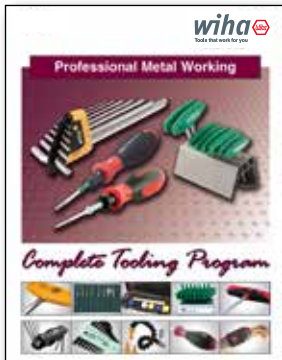

91330.wo - Tooling Catalog



99004.wo - Shop Tools Catalog



99914.wo - TORX Catalog



99951.wo - Bits Catalog



99919.wo - Insulated Catalog



99001.wo - TorqueControl Catalog



99934.wo - Hex Tools Catalog



99006.wo - Tech Tools Catalog



99945.wo - ESD Catalog



99977.wo - Pliers/Crimpers Catalog