

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300070177](#)
Status: **Active**
Overview: Brad Mini-Change Connectors
Description: Mini-Change Single-Ended Straight Cordset, 8 Poles, B-Size Mini, Female (Straight) to Pigtail, 22 AWG, PVC Cable, 10.0m (32.81') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837

General

Product Family Industrial Cordsets
 Series [130007](#)
 Connector End A Mini-Change
 Connector End B Pigtail
 IP Rating IP67
 Material - Contact Brass
 Overview [Brad Mini-Change Connectors](#)
 Product Name Mini-Change
 Protocol DeviceNet
 Region America
 Type Single Ended
 UPC 78678840190

Physical

Cable Diameter 6.10mm (.240")
 Cable Length 10.0m (32.81')
 Color - Cable Jacket Yellow
 Coupling Style Push to Lock
 Gender Female-Pigtail
 Keyway Single
 LED Indicator No
 Material - Cable Jacket PVC
 Material - Connector Body PVC
 Material - Coupling Nut Black Epoxy Coated Zinc
 Material - Plating Mating Gold
 Orientation Straight to Pigtail
 Poles 8
 Temperature Range - Operating -20°C to +75°C
 Wire Size AWG 22
 Wire/Cable Type ST00W

Electrical


Current - Maximum per Contact 2.5A
 Voltage - Maximum 600V

Material Info

Engineering Number 208000A04M100

Reference - Drawing Numbers

Sales Drawing SD-130007-007

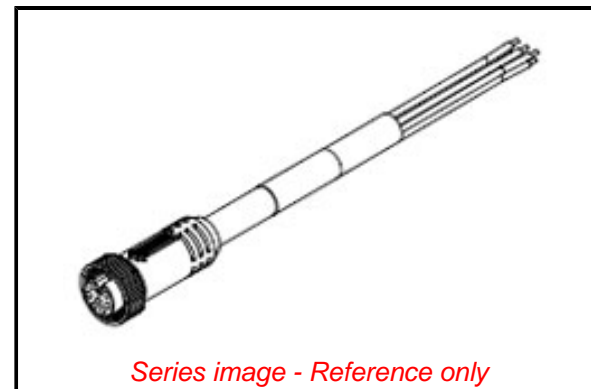

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130007 Series](#)