

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [130010-0884](#)
Status: **Active**
Overview: Brad® Mini-Change® Connectors
Description: Mini-Change® A-Size Double-Ended Cordset, 4 Poles, Male (Straight) to Female (Straight), 16 AWG, TPE Cable, 23.0m (9.84') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E152210

General

Product Family	Industrial Cordsets
Series	130010
Connector End A	Mini-Change®
Connector End B	Mini-Change®
IP Rating	IP67
Overview	Brad® Mini-Change® Connectors
Product Name	Mini-Change®
Protocol	N/A
Region	America
Type	Double Ended
UPC	78678883797

Physical

Cable Diameter	10.67mm (.420")
Cable Length	23.0m (75.46")
Color - Cable Jacket	Yellow
Coupling Style	Threaded
Gender	Male-Female
Keyway	Single
LED Indicator	No
Material - Cable Jacket	TPE
Material - Connector Body	PVC
Material - Contact	Copper Alloy
Material - Coupling Nut	Black Epoxy Coated Zinc
Material - Plating Mating	Gold over Nickel
Net Weight	3834.000/g
Orientation	Straight
Poles	4
Temperature Range - Operating	-20°C to +105°C
Wire Size AWG	16
Wire/Cable Type	TC-ER

Electrical

Current - Maximum per Contact	10A
Voltage - Maximum	600V

Material Info

Old Part Number 114030K12M230

Reference - Drawing Numbers

Sales Drawing SD-130010-016

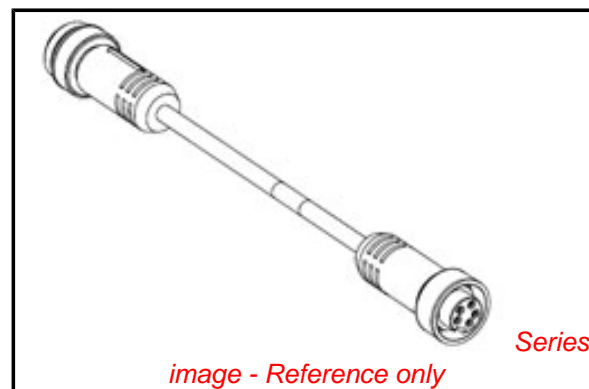


image - Reference only

EU RoHS

RoHS Compliant by Exemption
REACH SVHC
 Not Reviewed
Low-Halogen Status
 Not Reviewed

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

130010Series

This document was generated on 10/02/2014

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION