

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300120385](#)
Status: **Active**
Overview: [Brad Mini-Change Connectors](#)
Description: Mini-Change C-Size Double-Ended Cordset, 9 Poles, Male (Straight) to Female (Straight), 16 AWG, PVC Cable, 1.83m (6.0') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837
 UL E152210

General

Product Family Industrial Cordsets
 Series [130012](#)
 Connector End A Mini-Change
 Connector End B Mini-Change
 IP Rating IP67
 Material - Contact Brass
 Overview [Brad Mini-Change Connectors](#)
 Product Name Mini-Change
 Protocol FF
 Region America
 Type Double Ended
 UPC 78678844190

Physical

Cable Diameter 16.26mm (.640")
 Cable Length 1.83m (6.0')
 Color - Cable Jacket Yellow
 Coupling Style Threaded
 Gender Female-Male
 Keyway Single
 LED Indicator No
 Material - Cable Jacket PVC
 Material - Connector Body PVC
 Material - Coupling Nut Black Epoxy Coated Zinc
 Material - Plating Mating Gold
 Orientation Straight to Straight
 Poles 9
 Temperature Range - Operating -20°C to +105°C
 Wire Size AWG 16
 Wire/Cable Type ST00W

Electrical


Current - Maximum per Contact 7.0A
 Voltage - Maximum 600V

Material Info

Engineering Number 339020A01F060

Reference - Drawing Numbers

Sales Drawing SD-130012-001

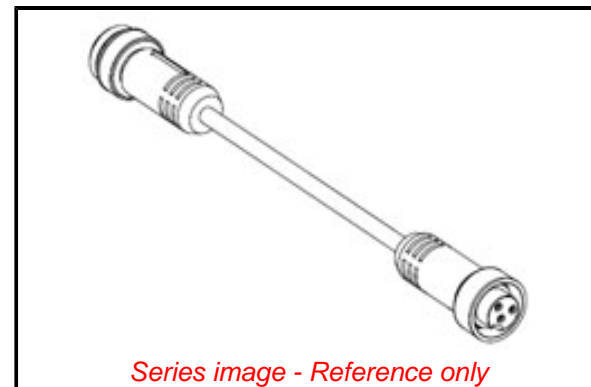

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Compliant

REACH SVHC

Contained Per -
 ED/30/2017 (7 July
 2017)
 Di-(2-
 ethylhexyl)phthalate
 (DEHP)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

50 Image

Not Relevant

Contained:
 DEHP,DEHP

Search Parts in this Series

[130012 Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION