

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [130017-0014](#)
Status: **Active**
Overview: Brad® Mini-Change® Products
Description: Mini-Change® Field Attachable, Male Connector, 3 Pole, Cable Range: 5.08-12.19mm Outside Diameter with External Threads

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E258922

General

Product Family Field Attachable / Accessories
 Series [130017](#)
 IP Rating IP67
 Overview [Brad® Mini-Change® Products](#)
 Product Name Mini-Change®
 Type Field Attachable Connector
 UPC 78678802997

Physical

Cable Diameter 5.00 - 12.00mm (.197-.472")
 Coupling Type External Thread
 Diagnostics / LEDs No
 Diagnostics Port No
 Gender Male
 Keyway Single
 Material - Connector Body Nylon
 Material - Contact Brass
 Material - Coupling Nut Nickel-plated Brass
 Material - Plating Mating Gold over Nickel
 Net Weight 54.430/g
 Orientation Straight
 Poles 3
 Temperature Range - Operating -20°C to +80°C
 Wire Size AWG 15 to 24

Electrical


Current - Maximum per Contact 15A
 Voltage - Maximum 600V AC/DC

Material Info

Old Part Number 1A3006-34PWR

Reference - Drawing Numbers

Sales Drawing SD-130017-011

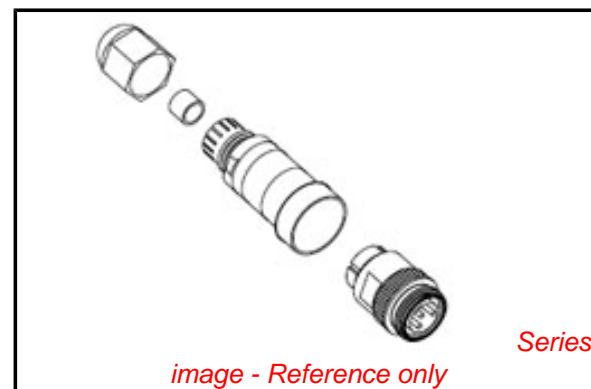

EU RoHS

ELV and RoHS Compliant
REACH SVHC
 Not Reviewed
Low-Halogen Status
 Not Reviewed

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
[130017Series](#)