

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1300250482

Status:


Active

Overview:

Brad Mini-Change Connectors

Description:

Mini-Change Double-Ended Cordset, 5 Poles, Female (90°) to Male (90°), 15/18 AWG, DeviceNet Thick Flex-Rated Cable, 1.0m (3.28') Length

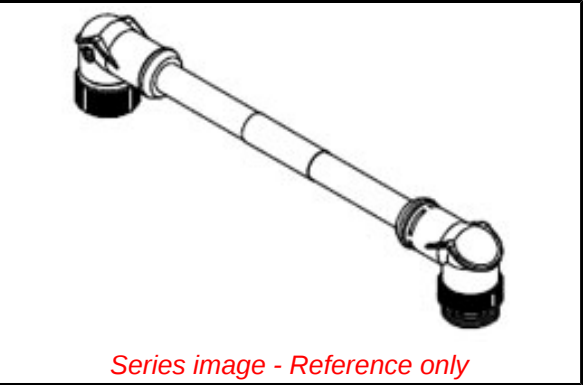

Series image - Reference only

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR6837
General	
Product Family	Industrial Cordsets
Series	130025
Connector End A	Mini-Change
Connector End B	Mini-Change
IP Rating	IP67
Material - Contact	Brass
Overview	Brad Mini-Change Connectors
Product Name	DeviceNet Trunk, Mini-Change
Region	Europe
Type	Double Ended
UPC	78678849037
Physical	
Cable Diameter	12.10mm (.480")
Cable Length	1.0m (3.28')
Color - Cable Jacket	Gray
Coupling Style	Threaded
Gender	Female-Male
Keyway	Single
LED Indicator	No
Material - Cable Jacket	PVC
Material - Connector Body	PVC
Material - Coupling Nut	Die-Cast Zinc
Material - Plating Mating	Gold
Orientation	90° to 90°
Poles	5
Temperature Range - Operating	-20°C to +80°C
Wire Size AWG	18
Wire/Cable Type	Thick (Trunk)
Electrical	
Current - Maximum per Contact	4.0A
Voltage - Maximum	300V AC/DC
Material Info	
Engineering Number	DNF99A-M010
Reference - Drawing Numbers	
Sales Drawing	SD-130025-018

EU ELV	
Not Reviewed	
EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

130025 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION