

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [130034-0005](#)
Status: **Active**
Overview: Brad® Mini-Change® Connectors
Description: Mini-Change® Trunk Connector, Threaded, Single Keyway, Straight Female, 5 Poles

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837

General

Product Family Field Attachable / Accessories
 Series [130034](#)
 IP Rating IP67
 Overview [Brad® Mini-Change® Connectors](#)
 Product Name Mini-Change®
 Type Field Attachable Connector
 UPC 78678848866

Physical

Cable Diameter N/A
 Coupling Type Internal Thread
 Diagnostics / LEDs No
 Diagnostics Port No
 Gender Female
 Keyway Single
 Material - Connector Body Polyamide
 Material - Contact Copper
 Material - Coupling Nut Nickel-plated Brass
 Material - Plating Mating n/a
 Orientation Straight
 Poles 5
 Temperature Range - Operating -25°C to +90°C
 Wire Size AWG N/A

Electrical


Current - Maximum per Contact 4.0A
 Voltage - Maximum 36V

Material Info

Old Part Number 1A5000-34DN

Reference - Drawing Numbers

Sales Drawing SD-130034-003

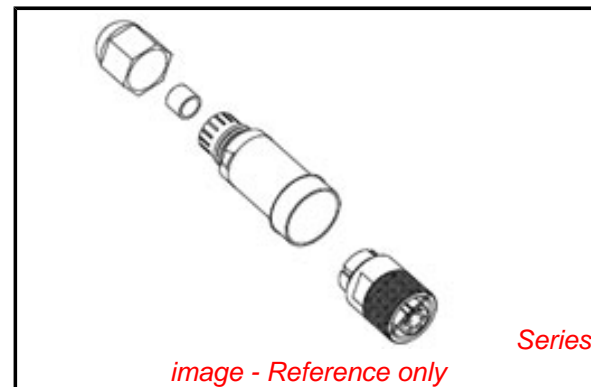

EU RoHS

RoHS Compliant by Exemption
REACH SVHC
 Not Reviewed
Low-Halogen Status
Not Reviewed

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

[130034Series](#)