

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300370004](#)
Status: **Active**
Overview: [DeviceNet Solutions](#)
Description: DeviceNet Micro-Change (M12) -Change 4 Port Mini, Mini-Change 5 Poles, Male

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Passive Distribution Boxes
Series	130037
IP Rating	IP67
NEMA Rating	NEMA 6
Overview	DeviceNet Solutions
Product Name	DeviceNet, Micro-Change (M12)
UPC	78678829102

Physical

Bus I/O	Micro-Change (M12)
Cable Connector Orientation	N/A
Cable Length	N/A
Home Run Cable Length	N/A
Home Run Connector	N/A
Home Run Interface	N/A
Keyway	Single
LED Indicator	No
Material - Cable Jacket	N/A
Material - Housing	PBT
Material - Metal	Copper
Material - Plating Mating	Gold over Nickel
Net Weight	136.078/g
Orientation	Top Mount
Poles	5
Poles (wired)	4
Ports	4
Temperature Range - Operating	-25°C to +90°C
Wiring Configuration	Single I/O per Port

Electrical


Current - Maximum per Contact	4.0A per port
Functional Wiring	Parallel
Voltage - Maximum	10-30V DC

Material Info

Engineering Number	DND4200
--------------------	---------

Reference - Drawing Numbers

Sales Drawing	SD-130037-001-001
---------------	-------------------

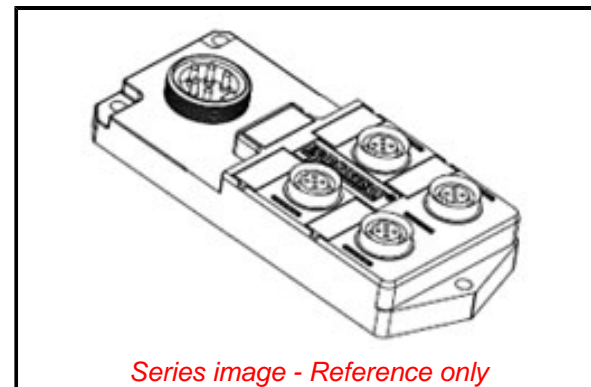

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

China RoHS

Search Parts in this Series

[130037 Series](#)