

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1300370008](#)  
**Status:** **Active**  
**Overview:** [DeviceNet Solutions](#)  
**Description:** DeviceNet Micro-Change (M12), 8 Port, 5 Poles, Male

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Passive Distribution Boxes
Series	<a href="#">130037</a>
IP Rating	IP67
Overview	<a href="#">DeviceNet Solutions</a>
Product Name	DeviceNet, Micro-Change (M12)
UPC	78678829103

**Physical**

Bus I/O	Micro-Change (M12)
Cable Connector Orientation	N/A
Cable Length	N/A
Home Run Cable Length	N/A
Home Run Connector	Mini-Change - 5 pole
Home Run Interface	Integrated Connector
Keyway	Single
LED Indicator	No
Material - Cable Jacket	N/A
Material - Housing	PBT
Material - Metal	Copper
Material - Plating Mating	Gold over Nickel
Net Weight	259.001/g
Orientation	Top Mount
Poles	5
Poles (wired)	5
Ports	8
Temperature Range - Operating	-20°C to +90°C
Wiring Configuration	Single I/O per Port

**Electrical**


Current - Maximum per Contact	4.0A per port
Functional Wiring	Parallel
Voltage - Maximum	10-30V DC

**Material Info**

Engineering Number	DND8200
--------------------	---------

**Reference - Drawing Numbers**

Sales Drawing	SD-130037-004
---------------	---------------

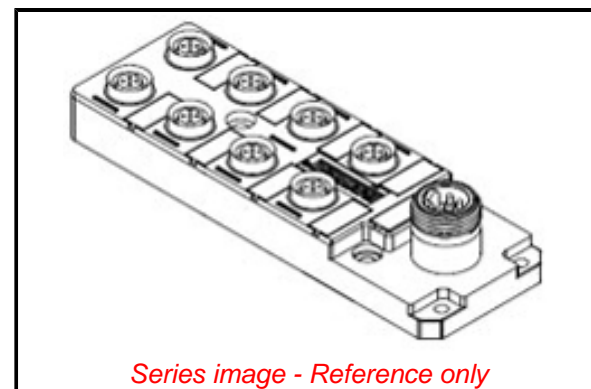

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[130037 Series](#)