

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300390097](#)

Status: **Active**

Overview: [Brad Mini-Change Connectors](#)

Description: Mini-Change Cord and Receptacle, DeviceNet Trunk Cable, 7/8" - 16 UN-2A Threads, Male-Female Straight, 5 Poles, 2.0m (6.56') Length

Documents:

[Drawing \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA	LR6837
UL	E152210

General

Product Family	Industrial Receptacles
Series	130039
IP Rating	IP67
Overview	Brad Mini-Change Connectors
Product Name	DeviceNet Trunk, Mini-Change
Type	Double Ended
UPC	78678882935

Physical

Coupling Type	Internal Thread
Gender	Male-Female
Keyway	Single
Length	2.0m
Material - Component	Stainless Steel Type 303
Mounting Thread Size	7/8" - 16 UN-2A
Orientation	Straight
Panel Mount	N/A
Poles	5
Temperature Range - Operating	-20°C to +80°C
Wire Size AWG	16, 18
Wire/Cable Type	N/A

Electrical


Current - Maximum per Contact	4.0A
Voltage - Maximum	300V AC/DC

Material Info

Engineering Number	DN5210A-M020
--------------------	--------------

Reference - Drawing Numbers

Sales Drawing	SD-130039-005
---------------	---------------

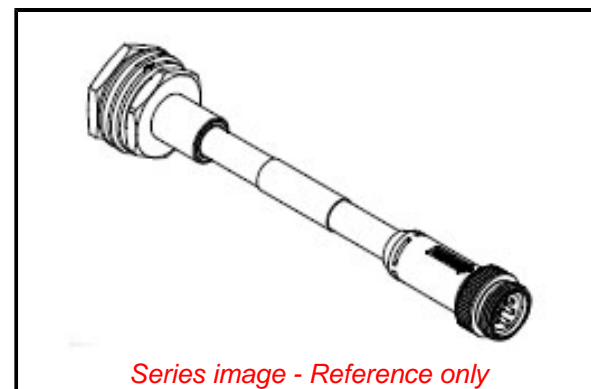

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130039 Series](#)