


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300610046](#)
Status: **Active**
Overview: [BradPower Cordsets and Receptacles](#)
Description: BradPower A-Size (7/8"–M22) Single-Ended Cordset, 3 Poles, Male (Straight) to Pigtail, 16 AWG, PVC Cable, 2.0m (6.56') Length

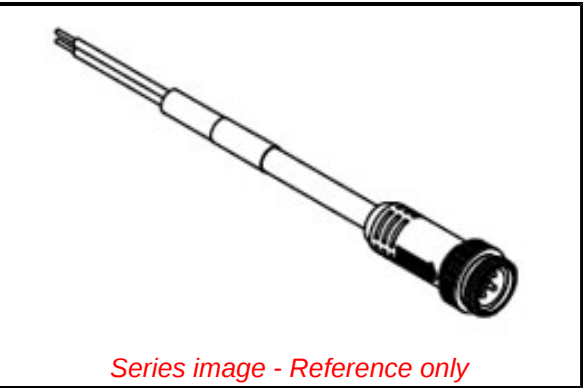

Series image - Reference only

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E258922

General

Product Family Industrial Cordsets
Series [130061](#)
Connector End A BradPower A-Size (7/8"–M22)
Connector End B Pigtail
IP Rating IP67
Material - Contact Copper Alloy
Overview [BradPower Cordsets and Receptacles](#)
Product Name BradPower A-Size
Protocol FF
Region Europe
Type Single Ended
UPC 78678888660

Physical

Cable Diameter 11.68mm (.460")
Cable Length 2.0m (6.56')
Color - Cable Jacket Gray
Coupling Style Threaded
Gender Male-Pigtail
Keyway Single
LED Indicator No
Material - Cable Jacket PVC
Material - Connector Body PVC
Material - Coupling Nut Black Epoxy Coated Zinc
Material - Plating Mating Gold
Orientation Straight to Pigtail
Poles 3
Temperature Range - Operating -20°C to +90°C
Wire Size AWG 16
Wire/Cable Type Unshielded-Stranded

Electrical

Current - Maximum per Contact 13.0A
Voltage - Maximum 600V

Material Info

Engineering Number 103006A45M020

Reference - Drawing Numbers

Sales Drawing SD-130061-008

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China RoHS

China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

[130061](#) Series