

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [130090015](#)
Status: **Active**
Overview: [Reels - Woodhead](#)
Description: Woodhead Standard Duty Reel, 16/3 SJTOW Cord, 10.67m (35.0') Cord Length with 100W Incandescent Hand Lamp and Rubber Handle

Documents:

[RoHS Certificate of Compliance \(PDF\)](#) [Product Literature \(PDF\)](#)

Agency Certification

UL E22769

General

Product Family	Electric Reels
Series	130090
Cable Length	0.457m (1.50')
Comments	Ratchet Lock (ON/OFF Switchable). NEMA 5-15 side Outlet, Ratchet Lock (ON/OFF Switchable). NEMA 5-15 side Outlet
Depth	0.24m (9.59")
Duty	Standard
Enclosure Rating	NEMA 1
Exclude SD Check	Yes
Height	0.32 (12.62")
NEMA Configuration	NEMA 5-15
Overview	Reels - Woodhead
Product Literature Order No	987650-8061
Product Name	Super-Safeway
Type	Cord Reel
UPC	78678875253
Width	13.06mm (5.160")

Physical


Cable Movement	Ratchet Lock
Cord Length	10.67m (35.0')
Drum Lock	Ratchet
Material - Coating	Powder Coating
Material - Housing	Steel
Mounting Style	Swinging
Number of Conductors	3
Packaging Type	Carton
Primary Cord/Cable Entry	N/A
Retraction Weight	0.9kg (2.0 lb)
Wire Size AWG	16

Electrical

Bulb Included	No
Cord Type	16/3 SJTOW
Current - Maximum per Contact	6.0A
GFCI	No
Lamp Type	Incandescent
Lamp Wattage - Maximum	100W
On/Off Switch	Yes
Voltage - Maximum	120V

Material Info

Engineering Number 963

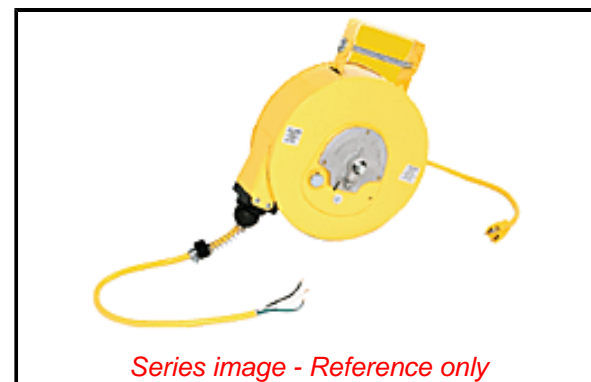

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

China RoHS

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130090](#) Series

This document was generated on 09/11/2019

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION