

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1300940209](#)  
**Status:** **Active**  
**Overview:** [Support Grips](#)  
**Description:** Standard Duty Support Grip, Double Eye, Closed Mesh, Double Weave, Cable Diameter 12.70-15.49mm (.500-.610"), Approximate Break Strength 349.27kg (770 lbs)

**Documents:**

[RoHS Certificate of Compliance \(PDF\)](#)      [Product Literature \(PDF\)](#)

**Agency Certification**

CSA      LR32159

**General**


Product Family	Cable Grips
Series	<a href="#">130094</a>
Exclude SD Check	Yes
Eye Type	Double
O-Ring	N/A
Overview	<a href="#">Support Grips</a>
Product Literature Order No	987650-8065
Product Name	Standard Duty
Type	Support Grip
UPC	78678835001

<b>Physical</b>	
Approximate Break Strength	349.27kg (770 lbs)
Bale Length	0.102m (4.00")
Body Style	Straight
Cable Diameter	12.70-15.49mm (.500-.610")
Color - Grommet	N/A
Gender	N/A
Material - Body	N/A
Material - Grip	Non-magnetic Tin Bronze Wire
Mesh Length	0.279m (11.00")
Net Weight	521.110/g
Number of Holes	N/A
Thread Size	N/A

**Material Info**

Engineering Number      35001

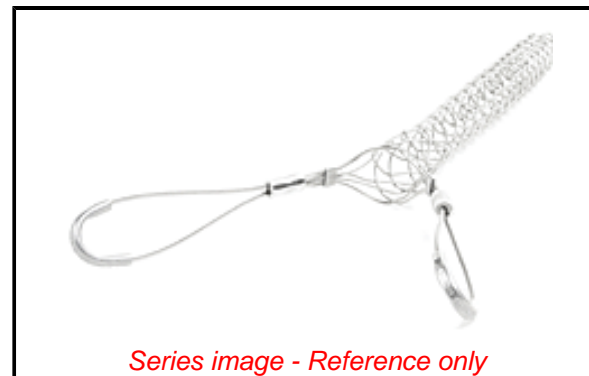

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[130094](#) Series

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**