

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1300940219](#)  
**Status:** **Active**  
**Overview:** [Support Grips](#)  
**Description:** Standard Duty Support Grip, Double Eye, Closed Mesh, Double Weave, Cable Diameter 38.10-44.20mm (1.500-1.740"), Approximate Break Strength 870.90kg (1920 lbs)

**Documents:**

[RoHS Certificate of Compliance \(PDF\)](#)

[Product Literature \(PDF\)](#)

**Agency Certification**

CSA LR32159

**General**


|                             |                               |
|-----------------------------|-------------------------------|
| Product Family              | Cable Grips                   |
| Series                      | <a href="#">130094</a>        |
| Exclude SD Check            | Yes                           |
| Eye Type                    | Double                        |
| O-Ring                      | N/A                           |
| Overview                    | <a href="#">Support Grips</a> |
| Product Literature Order No | 987650-8065                   |
| Product Name                | Standard Duty                 |
| Type                        | Support Grip                  |
| UPC                         | 78678835006                   |

**Physical**

|                            |                              |
|----------------------------|------------------------------|
| Approximate Break Strength | 870.90kg (1920 lbs)          |
| Bale Length                | 0.152m (6.00")               |
| Body Style                 | Straight                     |
| Cable Diameter             | 38.10-44.20mm (1.500-1.740") |
| Color - Grommet            | N/A                          |
| Gender                     | N/A                          |
| Material - Body            | N/A                          |
| Material - Grip            | Non-magnetic Tin Bronze Wire |
| Mesh Length                | 0.457m (18.00")              |
| Number of Holes            | N/A                          |
| Thread Size                | N/A                          |

**Material Info**

Engineering Number 35006

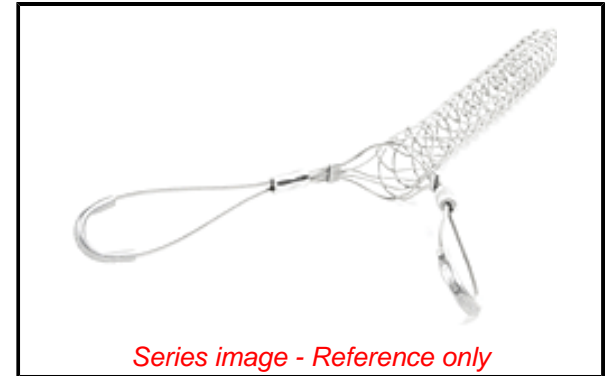

*Series image - Reference only*

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**China RoHS**

**Search Parts in this Series**

[130094](#) Series