

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300940249](#)
Status: **Active**
Overview: [Support Grips](#)
Description: Standard Duty Support Grip, Single Eye, Closed Mesh, Single Weave, Cable Diameter 88.90-101.35m (3.500-3.990"), Approximate Break Strength 2286.11kg (5040 lbs)

Documents:

[RoHS Certificate of Compliance \(PDF\)](#) [Product Literature \(PDF\)](#)

Agency Certification


CSA LR32159

General

Product Family	Cable Grips
Series	130094
Exclude SD Check	Yes
Eye Type	Single
O-Ring	N/A
Overview	Support Grips
Product Literature Order No	987650-8065
Product Name	Standard Duty
Type	Support Grip
UPC	78678835040
Physical	
Approximate Break Strength	2286.11kg (5040 lbs)
Bale Length	0.61m (24.00")
Body Style	Straight
Cable Diameter	88.90-101.35mm (3.500-3.990")
Color - Grommet	N/A
Gender	N/A
Material - Body	N/A
Material - Grip	Non-magnetic Tin Bronze Wire
Mesh Length	0.711m (28.00")
Number of Holes	N/A
Thread Size	N/A

Material Info

Engineering Number 35040

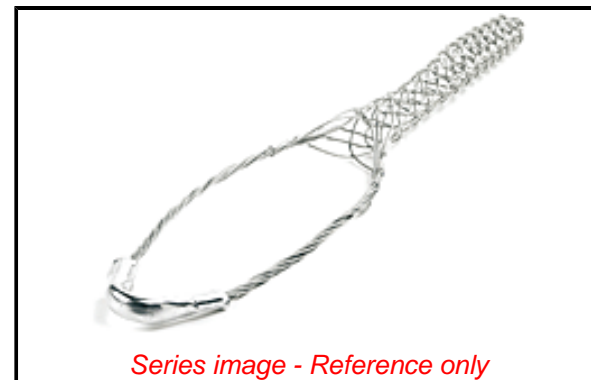

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

China RoHS

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130094](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION