

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1300940259](#)  
**Status:** **Active**  
**Overview:** [Support Grips](#)  
**Description:** Standard Duty Support Grip, Offset Eye, Closed Mesh, Single Weave, Cable Diameter 31.75-37.85mm (1.250-1.490"), Approximate Break Strength 762.04kg (1680 lbs)

**Documents:**

[RoHS Certificate of Compliance \(PDF\)](#)      [Product Literature \(PDF\)](#)

**Agency Certification**

CSA      LR32159

**General**


Product Family      Cable Grips  
 Series      [130094](#)  
 Exclude SD Check      Yes  
 Eye Type      Offset  
 O-Ring      N/A  
 Overview      [Support Grips](#)  
 Product Literature Order No      987650-8065  
 Product Name      Standard Duty  
 Type      Support Grip  
 UPC      78678835064

**Physical**

Approximate Break Strength      762.04kg (1680 lbs)  
 Bale Length      0.127m (5.00")  
 Body Style      Straight  
 Cable Diameter      31.75-37.85mm (1.250-1.490")  
 Color - Grommet      N/A  
 Gender      N/A  
 Material - Body      N/A  
 Material - Grip      Non-magnetic Tin Bronze Wire  
 Mesh Length      0.406m (16.00")  
 Number of Holes      N/A  
 Thread Size      N/A

**Material Info**

Engineering Number      35064

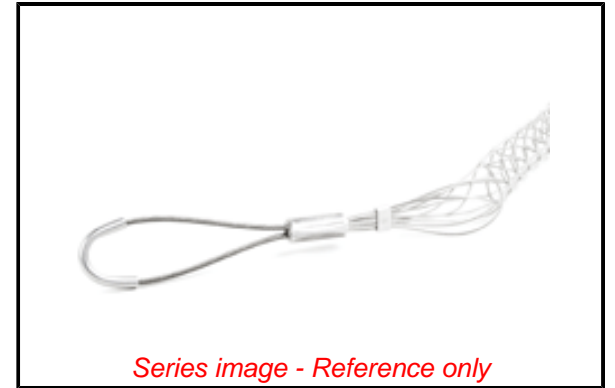

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[130094](#) Series