

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300940263](#)
Status: **Active**
Overview: [Support Grips](#)
Description: Standard Duty Support Grip, Offset Eye, Closed Mesh, Single Weave, Cable Diameter 44.45-50.55mm (1.750-1.990"), Approximate Break Strength 1197.48kg (2640 lbs)

Documents:

[RoHS Certificate of Compliance \(PDF\)](#) [Product Literature \(PDF\)](#)

Agency Certification

CSA LR32159

General


Product Family Cable Grips
 Series [130094](#)
 Exclude SD Check Yes
 Eye Type Offset
 O-Ring N/A
 Overview [Support Grips](#)
 Product Literature Order No 987650-8065
 Product Name Standard Duty
 Type Support Grip
 UPC 78678835066

Physical

Approximate Break Strength 1197.48kg (2640 lbs)
 Bale Length 0.152m (6.00")
 Body Style Straight
 Cable Diameter 44.45-50.55mm (1.750-1.990")
 Color - Grommet N/A
 Gender N/A
 Material - Body N/A
 Material - Grip Non-magnetic Tin Bronze Wire
 Mesh Length 0.508m (20.00")
 Number of Holes N/A
 Thread Size N/A

Material Info

Engineering Number 35066

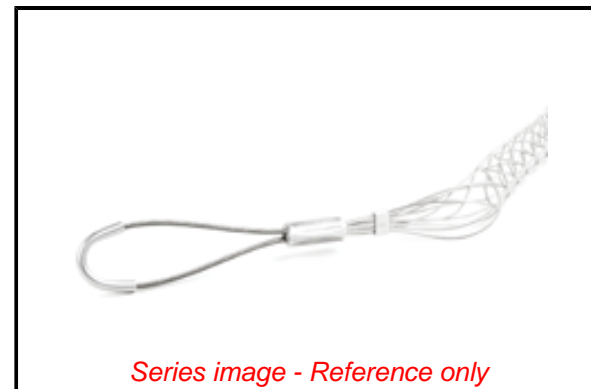

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130094 Series](#)