

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300940330](#)
Status: **Active**
Overview: [Support Grips](#)
Description: Standard Duty Support Grip, Offset Eye, Split Lace, Single Weave, Cable Diameter 12.70-15.49mm (.500-.610"), Approximate Break Strength 349.27kg (770 lbs)

Documents:

[RoHS Certificate of Compliance \(PDF\)](#) [Product Literature \(PDF\)](#)

Agency Certification


CSA LR32159

General

| | |
|-----------------------------|-------------------------------|
| Product Family | Cable Grips |
| Series | 130094 |
| Exclude SD Check | Yes |
| Eye Type | Offset |
| O-Ring | N/A |
| Overview | Support Grips |
| Product Literature Order No | 987650-8065 |
| Product Name | Standard Duty |
| Type | Support Grip |
| UPC | 78678835195 |
| Physical | |
| Approximate Break Strength | 349.27kg (770 lbs) |
| Bale Length | 0.102m (4.00") |
| Body Style | Straight |
| Cable Diameter | 12.70-15.49mm (.500-.610") |
| Color - Grommet | N/A |
| Gender | N/A |
| Material - Body | N/A |
| Material - Grip | Non-magnetic Tin Bronze Wire |
| Mesh Length | 0.279m (11.00") |
| Number of Holes | N/A |
| Thread Size | N/A |

Material Info

Engineering Number 35195

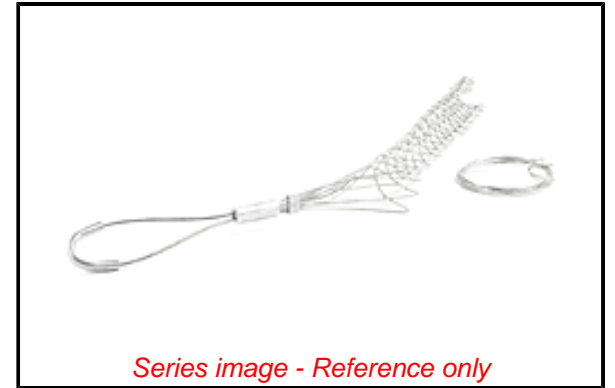

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130094](#) Series