

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300940352](#)
Status: **Active**
Overview: [Support Grips](#)
Description: Standard Duty Support Grip, Locking Bale, Split Lace, Single Weave, Cable Diameter 12.70-15.49mm (.500-.610"), Approximate Break Strength 349.27kg (770 lbs)

Documents:

[RoHS Certificate of Compliance \(PDF\)](#) [Product Literature \(PDF\)](#)

Agency Certification

CSA LR32159

General


Product Family	Cable Grips
Series	130094
Exclude SD Check	Yes
Eye Type	Locking Bale
O-Ring	N/A
Overview	Support Grips
Product Literature Order No	987650-8065
Product Name	Standard Duty
Type	Support Grip
UPC	78678835225

Physical

Approximate Break Strength	349.27kg (770 lbs)
Bale Length	0.457m (18.00")
Body Style	Straight
Cable Diameter	12.70-15.49mm (.500-.610")
Color - Grommet	N/A
Gender	N/A
Material - Body	N/A
Material - Grip	Non-magnetic Tin Bronze Wire
Mesh Length	0.279m (11.00")
Number of Holes	N/A
Thread Size	N/A

Material Info

Engineering Number 35225

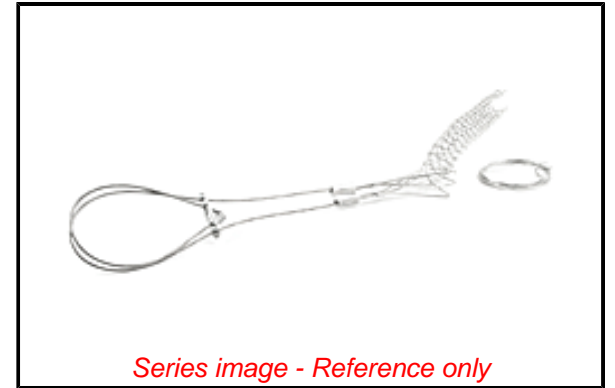

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130094 Series](#)