

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300940387](#)
Status: **Active**
Overview: [Support Grips](#)
Description: Standard Duty Support Grip, Single "U" Eye, Split Rod, Single Weave, Cable Diameter 15.88-19.05mm (.625-.750"), Approximate Break Strength 435.45kg (960 lbs)

Documents:

[RoHS Certificate of Compliance \(PDF\)](#) [Product Literature \(PDF\)](#)

Agency Certification

CSA LR32159


General

Product Family	Cable Grips
Series	130094
Exclude SD Check	Yes
Eye Type	Single
O-Ring	N/A
Overview	Support Grips
Product Literature Order No	987650-8065
Product Name	Standard Duty
Type	Support Grip
UPC	78678835286

Physical	
Approximate Break Strength	435.45kg (960 lbs)
Bale Length	0.203m (8.00")
Body Style	Straight
Cable Diameter	15.88-19.05mm (.625-.750")
Color - Grommet	N/A
Gender	N/A
Material - Body	N/A
Material - Grip	Non-magnetic Tin Bronze Wire
Mesh Length	0.279m (11.00")
Net Weight	204.116/g
Number of Holes	N/A
Thread Size	N/A

Material Info

Engineering Number 35286

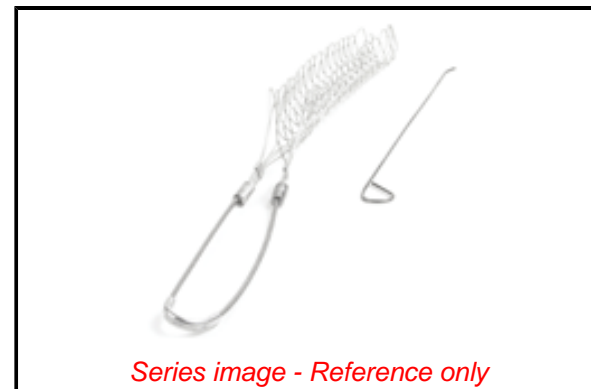

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130094 Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION