

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1300940450](#)  
**Status:** **Active**  
**Overview:** [Support Grips](#)  
**Description:** Heavy Duty Support Grip, Double Eye, Double Weave, Closed Mesh, Cable Diameter 63.50-75.95mm (2.500-2.990"), Approximate Break Strength 4572.21kg (10080 lbs)

**Documents:**

[RoHS Certificate of Compliance \(PDF\)](#)      [Product Literature \(PDF\)](#)

**Agency Certification**

CSA      LR32159

**General**


Product Family	Cable Grips
Series	<a href="#">130094</a>
Exclude SD Check	Yes
Eye Type	Double
O-Ring	N/A
Overview	<a href="#">Support Grips</a>
Product Literature Order No	987650-8065
Product Name	Heavy Duty
Type	Support Grip
UPC	78678835430

<b>Physical</b>	
Approximate Break Strength	4572.21kg (10080 lbs)
Bale Length	0.254m (10.00")
Body Style	Straight
Cable Diameter	63.50-75.95mm (2.500-2.990")
Color - Grommet	N/A
Gender	N/A
Material - Body	N/A
Material - Grip	Non-magnetic Tin Bronze Wire
Mesh Length	0.965m (38.00")
Number of Holes	N/A
Thread Size	N/A

**Material Info**

Engineering Number      35430

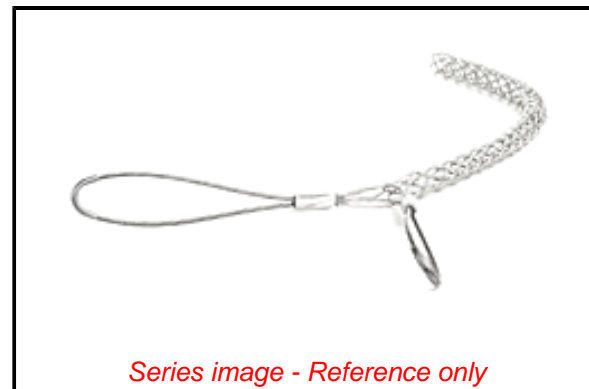

*Series image - Reference only*

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[130094](#) Series

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**