

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300940452](#)
Status: **Active**
Overview: [Support Grips](#)
Description: Heavy Duty Support Grip, Double Eye, Double Weave, Closed Mesh, Cable Diameter 76.20-88.65mm (3.000-3.490"), Approximate Break Strength 4572.21kg (10080 lbs)

Documents:

[RoHS Certificate of Compliance \(PDF\)](#) [Product Literature \(PDF\)](#)

Agency Certification

CSA LR32159


General

Product Family	Cable Grips
Series	130094
Exclude SD Check	Yes
Eye Type	Double
O-Ring	N/A
Overview	Support Grips
Product Literature Order No	987650-8065
Product Name	Heavy Duty
Type	Support Grip
UPC	78678835431

Physical	
Approximate Break Strength	4572.21kg (10080 lbs)
Bale Length	0.254m (10.00")
Body Style	Straight
Cable Diameter	76.20-88.65mm (3.000-3.490")
Color - Grommet	N/A
Gender	N/A
Material - Body	N/A
Material - Grip	Non-magnetic Tin Bronze Wire
Mesh Length	1.041m (41.00")
Number of Holes	N/A
Thread Size	N/A

Material Info

Engineering Number 35431

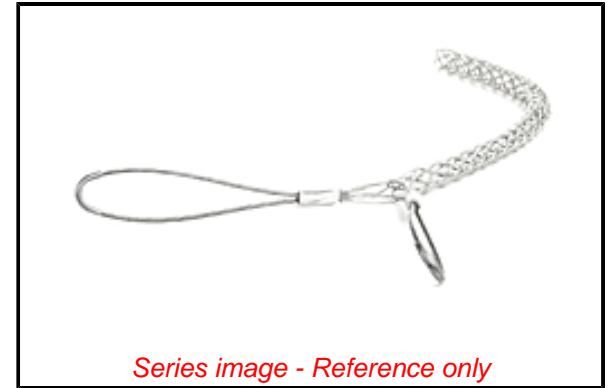

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130094](#) Series