

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300940455](#)
Status: **Active**
Overview: [Support Grips](#)
Description: Heavy Duty Support Grip, Double Eye, Double Weave, Closed Mesh, Cable Diameter 101.60-114.05mm (4.000-4.490"), Approximate Break Strength 5951.13kg (13120 lbs)

Documents:

[RoHS Certificate of Compliance \(PDF\)](#) [Product Literature \(PDF\)](#)

Agency Certification

CSA LR32159


General

Product Family	Cable Grips
Series	130094
Exclude SD Check	Yes
Eye Type	Double
O-Ring	N/A
Overview	Support Grips
Product Literature Order No	987650-8065
Product Name	Heavy Duty
Type	Support Grip
UPC	78678835433

Physical	
Approximate Break Strength	5951.13kg (13120 lbs)
Bale Length	0.254m (10.00")
Body Style	Straight
Cable Diameter	101.60-114.05mm (4.000-4.490")
Color - Grommet	N/A
Gender	N/A
Material - Body	N/A
Material - Grip	Non-magnetic Tin Bronze Wire
Mesh Length	1.194m (47.00")
Number of Holes	N/A
Thread Size	N/A

Material Info

Engineering Number 35433

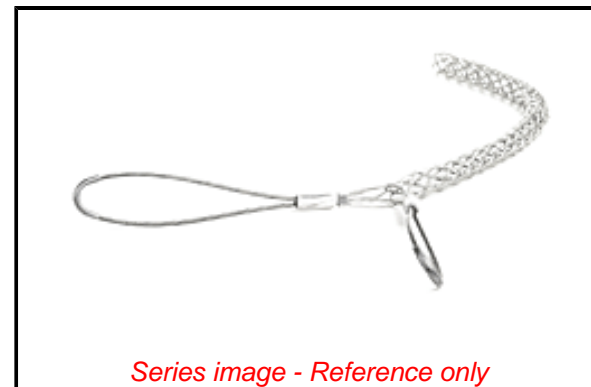

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130094](#) Series