

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300940459](#)
Status: **Active**
Overview: [Support Grips](#)
Description: Heavy Duty Support Grip, Single Eye, Double Weave, Closed Mesh, Cable Diameter 25.40-31.50mm (1.000-1.240"), Approximate Break Strength 2140.96kg (4720 lbs)

Documents:

[RoHS Certificate of Compliance \(PDF\)](#) [Product Literature \(PDF\)](#)

Agency Certification

CSA LR32159


General

| | |
|-----------------------------|-------------------------------|
| Product Family | Cable Grips |
| Series | 130094 |
| Exclude SD Check | Yes |
| Eye Type | Single |
| O-Ring | N/A |
| Overview | Support Grips |
| Product Literature Order No | 987650-8065 |
| Product Name | Heavy Duty |
| Type | Support Grip |
| UPC | 78678835436 |

| | |
|----------------------------|------------------------------|
| Physical | |
| Approximate Break Strength | 2140.96kg (4720 lbs) |
| Bale Length | 0.254m (10.00") |
| Body Style | Straight |
| Cable Diameter | 25.40-31.50mm (1.000-1.240") |
| Color - Grommet | N/A |
| Gender | N/A |
| Material - Body | N/A |
| Material - Grip | Non-magnetic Tin Bronze Wire |
| Mesh Length | 0.737m (29.00") |
| Number of Holes | N/A |
| Thread Size | N/A |

Material Info

Engineering Number 35436

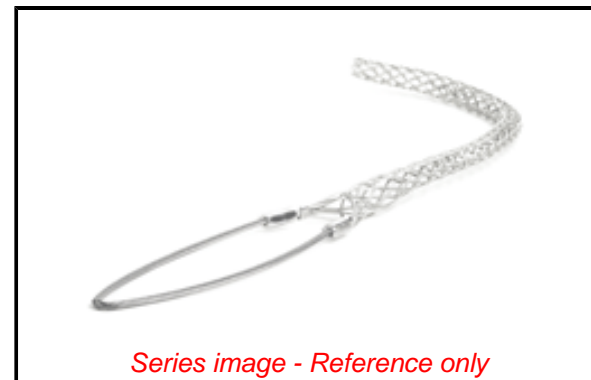

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

China RoHS

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130094 Series](#)