

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1300940534](#)  
**Status:** **Active**  
**Overview:** [Support Grips](#)  
**Description:** Support Grips for Fiber Optics, Closed Mesh, Single Eye, Bale Length 7", Cable Diameter 14.22-18.03mm (.560-.710"), Approximate Break Strength 272.16kg (600 lbs)

**Documents:**

[Drawing \(PDF\)](#) [Product Literature \(PDF\)](#)  
[RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

CSA LR32159

**General**

Product Family	Cable Grips
Series	<a href="#">130094</a>
Exclude SD Check	Yes
Eye Type	Single
O-Ring	N/A
Overview	<a href="#">Support Grips</a>
Product Literature Order No	987650-8066
Product Name	Fiber Optic
Type	Support Grip
UPC	78678836685

**Physical**


Approximate Break Strength	272.16kg (600 lbs)
Bale Length	0.178m (7.00")
Body Style	Straight
Cable Diameter	14.22-18.03mm (.560-.710")
Color - Grommet	N/A
Gender	N/A
Material - Body	N/A
Material - Grip	Non-magnetic Tin Bronze Wire
Mesh Length	0.14m (5.50")
Number of Holes	N/A
Thread Size	N/A

**Material Info**

Engineering Number 36685

**Reference - Drawing Numbers**

Sales Drawing SD-130094-008

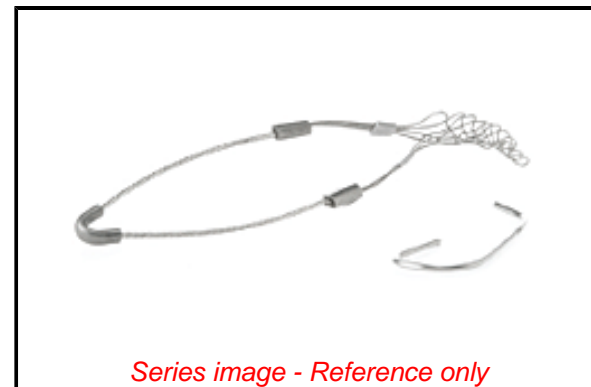

*Series image - Reference only*

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[130094](#) Series