

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300950240](#)
Status: **Active**
Overview: Support Grips
Description: Medium Duty Wire Mesh Slack Grip Cable, Split Lace, Double Weave, Offset Eye, Medium Mesh Length 0.33m (13.00"), Approximate Break Strength 1360.78kg (3000 lbs)

Documents:

[Drawing \(PDF\)](#) [Product Literature \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR32159

General

Product Family Cable Grips
 Series [130095](#)
 Exclude SD Check Yes
 Eye Type Offset
 O-Ring N/A
 Overview [Support Grips](#)
 Product Literature Order No 987650-8066
 Product Name Medium Duty
 Type Pulling Grip
 UPC 78678836120

Physical


Approximate Break Strength 1360.78kg (3000 lbs)
 Bale Length N/A
 Body Style Straight
 Cable Diameter 19.05-25.15mm (.750-.990")
 Color - Grommet N/A
 Gender N/A
 Material - Body N/A
 Material - Grip Galvanized Steel
 Mesh Length 0.33m (13.00")
 Net Weight 88.904/g
 Number of Holes N/A
 Thread Size N/A

Material Info

Engineering Number 36120

Reference - Drawing Numbers

Sales Drawing SD-130095-114

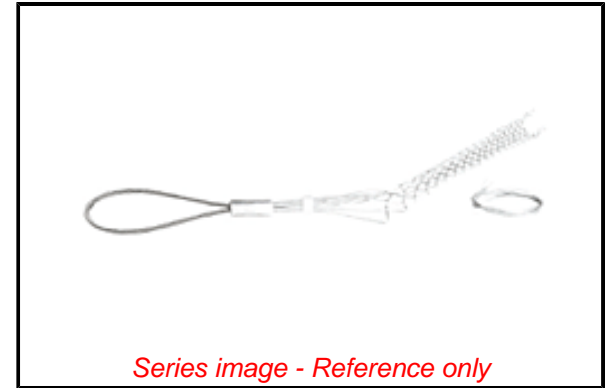

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130095 Series](#)