

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300970258](#)
Status: **Active**
Overview: Strain-Relief Cord Grips
Description: Dust-Tight Strain Relief Wide Range Grip, 1/2" NPT, Straight Male, Cable Diameter 7.62-10.92mm (.300-.430"), Approximate Break Strength 136.08kg (300 lbs)

Documents:

[Drawing \(PDF\)](#) [Product Literature \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR32159
 UL E76954

General

Product Family Cable Grips
 Series [130097](#)
 Exclude SD Check Yes
 Eye Type N/A
 Insulated Yes
 NEMA Rating Dust Tight
 O-Ring N/A
 Overview [Strain-Relief Cord Grips](#)
 Product Literature Order No 987651-6081
 Product Name Dust-Tight
 Type Strain Relief Grip
 UPC 78678836503
 Use With 1/2" NPT MAX-LOC Lock Nut [1300990143](#) , MAX-LOC O-Ring, 1/2" NPT [1301800314](#) , 1/2" NPT MAX-LOC Gasket [1300990149](#)

Physical


Approximate Break Strength 136.08kg (300 lbs)
 Bale Length N/A
 Body Style Straight
 Cable Diameter 7.62-10.92mm (.300-.430")
 Color - Grommet N/A
 Gender Male
 Material - Body Zinc Plated Steel
 Material - Grip Galvanized Steel
 Mesh Length 0.12m (4.75")
 Number of Holes N/A
 Thread Size 1/2" NPT

Material Info

Engineering Number 36503

Reference - Drawing Numbers

Sales Drawing SD-130097-002

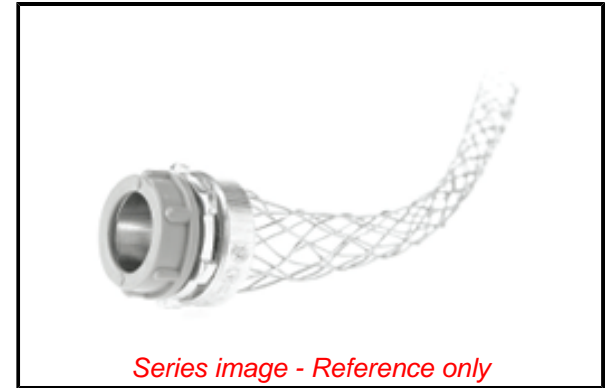

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130097 Series](#)