

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300970322](#)
Status: **Active**
Overview: [Strain-Relief Cord Grips](#)
Description: MAX-LOC Strain Relief Cord-Sealing Grip, 1/2" NPT, Straight Male, Cable Diameter 6.35-9.53mm (.250-.375"), Stainless Steel

Documents:

[Drawing \(PDF\)](#) [Product Literature \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR32159

General

Product Family Cable Grips
 Series [130097](#)
 Exclude SD Check Yes
 Eye Type N/A
 NEMA Rating NEMA 3R
 O-Ring No
 Overview [Strain-Relief Cord Grips](#)
 Product Literature Order No 987651-6081
 Product Name MAX-LOC
 Type Strain Relief Grip
 UPC 78678837126
 Use With 1/2" NPT MAX-LOC Lock Nut [1300990143](#) , MAX-LOC O-Ring, 1/2" NPT [1301800314](#) , 1/2" NPT MAX-LOC Gasket [1300990149](#)

Physical


Approximate Break Strength N/A
 Bale Length N/A
 Body Style Straight
 Cable Diameter 6.35-9.53mm (.250-.375")
 Color - Grommet Black
 Gender Male
 Material - Body Stainless Steel
 Material - Grip Stainless Steel
 Mesh Length N/A
 Number of Holes 1
 Thread Size 1/2" NPT

Material Info

Engineering Number 5524MSS

Reference - Drawing Numbers

Sales Drawing SD-130097-102

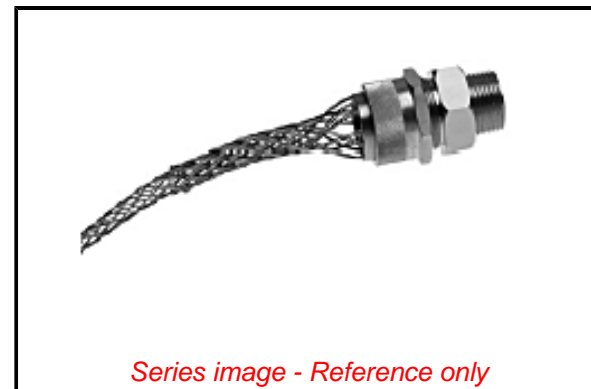

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS Not Reviewed

ELV Not Reviewed

RoHS Phthalates Not Reviewed

China RoHS

Search Parts in this Series

[130097 Series](#)