

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1300970338](#)  
**Status:** **Active**  
**Overview:** Strain-Relief Cord Grips  
**Description:** MAX-LOC Strain Relief Cord-Sealing Grip, 1" NPT, Straight Male, Cable Diameter 22.23-25.40mm (.875-1.000"), Stainless Steel Mesh

**Documents:**

[Drawing \(PDF\)](#) [Product Literature \(PDF\)](#)  
[RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

CSA LR32159

**General**

Product Family	Cable Grips
Series	<a href="#">130097</a>
Exclude SD Check	Yes
Eye Type	N/A
NEMA Rating	NEMA 3R
O-Ring	No
Overview	<a href="#">Strain-Relief Cord Grips</a>
Product Literature Order No	987651-6081
Product Name	MAX-LOC
Type	Strain Relief Grip
UPC	78678837151
Use With	MAX-LOC Lock Nut 1" NPT <a href="#">1300990145</a> , MAX-LOC Gasket Sealing Ring 1" NPT <a href="#">1300990151</a> , MAX-LOC O-Ring, 1" NPT <a href="#">1301800334</a>

**Physical**


Approximate Break Strength	N/A
Bale Length	N/A
Body Style	Straight
Cable Diameter	22.23-25.40mm (.875-1.000")
Color - Grommet	N/A
Gender	Male
Material - Body	Stainless Steel
Material - Grip	Stainless Steel
Mesh Length	N/A
Number of Holes	1
Thread Size	1" NPT

**Material Info**

Engineering Number 5560MSS

**Reference - Drawing Numbers**

Sales Drawing SD-130097-102

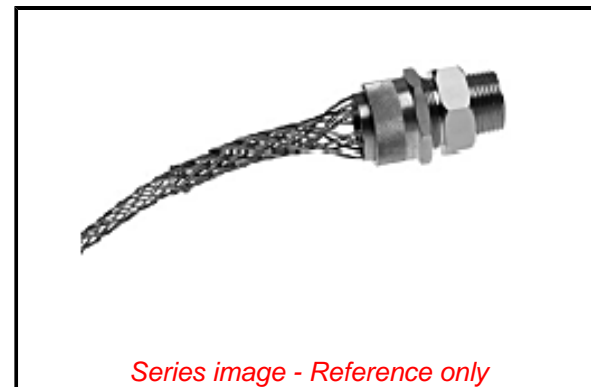

*Series image - Reference only*

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[130097 Series](#)