

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1300980037](#)  
**Status:** **Active**  
**Overview:** [Strain-Relief Cord Grips](#)  
**Description:** MAX-LOC Strain Relief Cord-Sealing Grip, 1/2" NPT, Straight Male, Cable Diameter 1.57-3.18mm (.062-.125"), Stainless Steel

**Documents:**

[RoHS Certificate of Compliance \(PDF\)](#)

[Product Literature \(PDF\)](#)

**General**


Product Family	Cable Grips
Series	<a href="#">130098</a>
Exclude SD Check	Yes
Eye Type	N/A
NEMA Rating	NEMA 3R
O-Ring	No
Overview	<a href="#">Strain-Relief Cord Grips</a>
Product Literature Order No	987651-6081
Product Name	MAX-LOC
Type	Strain Relief Grip
UPC	78678835896
Use With	1/2" NPT MAX-LOC Lock Nut <a href="#">1300990143</a> , MAX-LOC O-Ring, 1/2" NPT <a href="#">1301800314</a> , 1/2" NPT MAX-LOC Gasket <a href="#">1300990149</a>

**Physical**

Approximate Break Strength	N/A
Bale Length	N/A
Body Style	Straight
Cable Diameter	1.57-3.18mm (.062-.125")
Color - Grommet	Black
Gender	Male
Material - Body	Stainless Steel
Material - Grip	Stainless Steel
Mesh Length	N/A
Number of Holes	1
Thread Size	1/2" NPT

**Material Info**

Engineering Number	5518SS
--------------------	--------

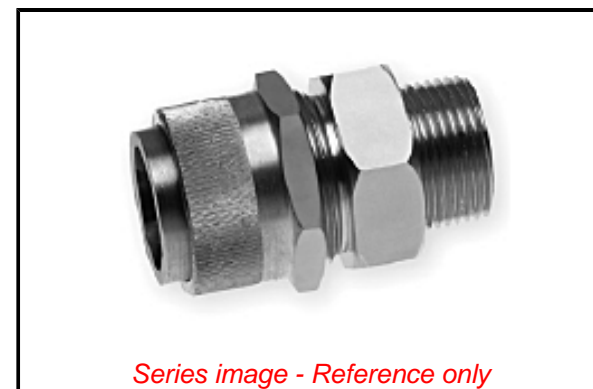

*Series image - Reference only*

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[130098](#) Series

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**