

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1301280115](#)
Status: **Active**
Overview: [Outlet Boxes](#)
Description: Woodhead FD Gray Glass-Filled Polyester Box, (2) 19.05mm (.750") Threaded Knock-out Openings

Documents:

[RoHS Certificate of Compliance \(PDF\)](#) [Product Literature \(PDF\)](#)

Agency Certification

UL E117594

General

Product Family	Power Distribution
Series	130128
Enclosure Rating	N/A
Exclude SD Check	Yes
GFCI Reset	N/A
Mounting Style	Permanent
Open Neutral Relay	N/A
Overview	Outlet Boxes
Product Literature Order No	987650-7737
Product Name	Woodhead
Receptacle Type	N/A
Type	FD Box - Industrial Duty
UPC	78678872453

Physical


Cord Diameter	N/A
Cord Grip Body Size	N/A
Cord Length	N/A
Feed-Thru	Yes
Flip Lid	No
Material - Housing	PBT Glass-Filled
Number of Receptacles	0
Packaging Type	Carton

Electrical

Cord Type	N/A
Current - Maximum per Contact	N/A
GFCI	No
Ground Continuity Monitor	No
NEMA Configuration	N/A
Voltage - Maximum	N/A

Material Info

Engineering Number 453

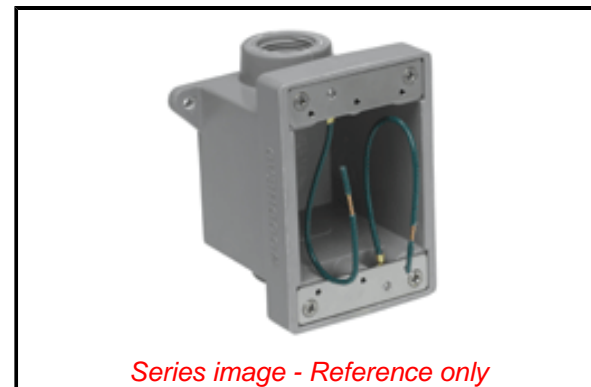

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130128 Series](#)