

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1301460050](#)
Status: **Active**
Overview: [Watertite Wet-Location Wiring Solutions](#)
Description: Watertite Extreme Connector, 3 Pole/3 Wire, Non-NEMA, 15A/125V, 10A/250V, Cord Grip Body Size F2, Silicone Husk

Documents:

[Drawing \(PDF\)](#) [Product Literature \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837

General

Product Family Wiring Devices
 Series [130146](#)
 Exclude SD Check Yes
 IP Rating IP69K
 NEMA Configuration Non-NEMA
 Overview [Watertite Wet-Location Wiring Solutions](#)
 Product Literature Order No 987651-9322
 Product Name Watertite Extreme
 Receptacle Type Single
 Specialty N/A
 Type Connector
 UPC 78678871180

Physical

Cord Grip Body Size F2 1/2"
 Flange No
 Flip Lid No
 Gender Female
 Length N/A
 Locking Blade No
 Poles 3-pole/3-wire

Electrical


Cord Type N/A
 Current - Maximum per Contact 15.0A
 GFCI No
 Lighted Connector No
 Voltage - Maximum 250V

Material Info

Engineering Number 15W07

Reference - Drawing Numbers

Sales Drawing 1301460050-000

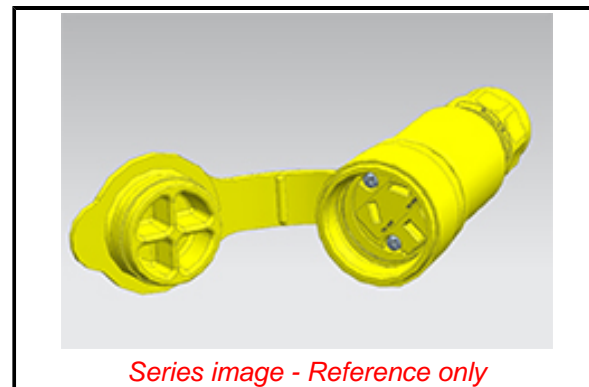

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130146 Series](#)