

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1301460091](#)
Status: **Active**
Overview: [Watertite Wet-Location Wiring Solutions](#)
Description: Watertite Extreme Connector for Male Receptacle with Locking Blade, 2 Pole/2 Wire, NEMA L1-15, 125V, F2, Silicone Husk

Documents:

[Drawing \(PDF\)](#) [Product Literature \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837

General

Product Family Wiring Devices
 Series [130146](#)
 Exclude SD Check Yes
 IP Rating IP69K
 NEMA Configuration NEMA L1-15
 Overview [Watertite Wet-Location Wiring Solutions](#)
 Product Literature Order No 987651-9322
 Product Name Watertite Extreme
 Receptacle Type Single
 Specialty N/A
 Type Connector
 UPC 78678871182

Physical

Cord Grip Body Size F2 1/2"
 Flange No
 Flip Lid No
 Gender Female
 Length N/A
 Locking Blade Yes
 Poles 2-pole/2-wire

Electrical


Cord Type N/A
 Current - Maximum per Contact 15.0A
 GFCI No
 Lighted Connector No
 Voltage - Maximum 125V

Material Info

Engineering Number 25W04MB

Reference - Drawing Numbers

Sales Drawing 1301460091-000

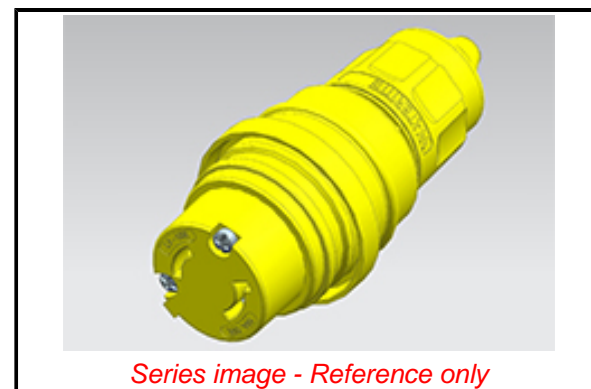

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130146 Series](#)