

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1301460101](#)
Status: **Active**
Overview: [Watertite Wet-Location Wiring Solutions](#)
Description: Watertite Extreme Ground Fault Monitoring Connector with Locking Blade 2 Pole/3 Wire, NEMA L5-15, 125V, Cord Grip Body Size F2, Silicone Husk

Documents:

[Drawing \(PDF\)](#) [Product Literature \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837
 UL E10176

General

Product Family [Wiring Devices](#)
 Series [130146](#)
 Exclude SD Check Yes
 IP Rating IP69K
 NEMA Configuration NEMA L5-15
 Overview [Watertite Wet-Location Wiring Solutions](#)
 Product Literature Order No 987651-9322
 Product Name Watertite Extreme
 Receptacle Type Single
 Specialty Monitoring
 Type Connector
 UPC 78678802588

Physical

Cord Grip Body Size F2 1/2"
 Flange No
 Flip Lid No
 Gender Female
 Length N/A
 Locking Blade Yes
 Poles 2-pole/3-wire

Electrical


Cord Type N/A
 Current - Maximum per Contact 15.0A
 GFCI No
 Lighted Connector Yes
 Voltage - Maximum 125V

Material Info

Engineering Number 25W47GCM

Reference - Drawing Numbers

Sales Drawing 1301460101-000

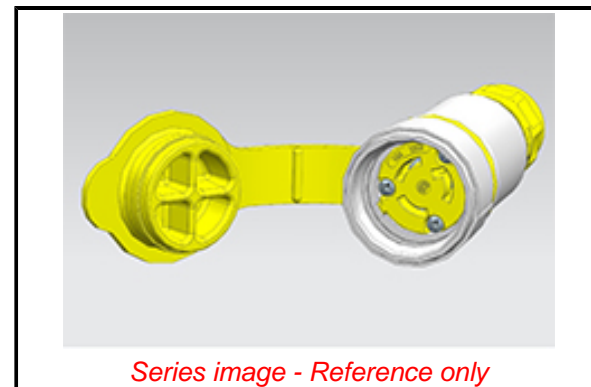

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130146 Series](#)