

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

130008-0033

Status:

Active

Overview:

Brad® Mini-Change® Connectors

Description:

Mini-Change® C-Size Single-Ended Cordset, 10 Poles, Female (Straight) to Pigtail, 16 AWG, PVC Cable, 6.10m (20.0') Length

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

CSA

LR6837

UL

E152210

General

Product Family

Industrial Cordsets

Series

130008

Connector End A

Mini-Change®

Connector End B

Pigtail

IP Rating

IP67

Overview

Brad® Mini-Change® Connectors

Product Name

Mini-Change®

Protocol

N/A

Region

America

Type

Single Ended

UPC

78678844088

Physical

Cable Diameter

16.76mm (.660")

Cable Length

6.10m (20.0')

Color - Cable Jacket

Yellow

Coupling Style

Threaded

Gender

Female-Pigtail

Keyway

Single

LED Indicator

No

Material - Cable Jacket

PVC

Material - Connector Body

PVC

Material - Contact

Brass

Material - Coupling Nut

Black Epoxy Coated Zinc

Material - Plating Mating

Gold

Orientation

Straight

Poles

10

Temperature Range - Operating

-20°C to +105°C

Wire Size AWG

16

Wire/Cable Type

STOOW

Electrical

Current - Maximum per Contact

7A

Voltage - Maximum

600V

Material Info


Old Part Number

301000A01F200

Reference - Drawing Numbers

Sales Drawing

SD-130008-013

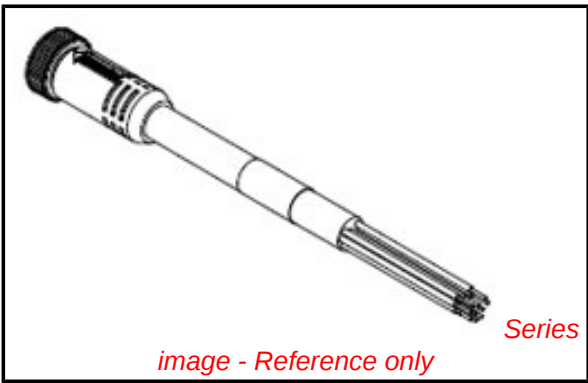

EU RoHS

RoHS Compliant by Exemption

REACH SVHC

Not Reviewed

Low-Halogen Status

Not Reviewed

China RoHS

50

Pb

Need more information on product environmental compliance?

Email productcompliance@molex.com

For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

130008Series

This document was generated on 10/14/2014

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION