

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [130099-0129](#)
Status: **Active**
Overview: [Strain-Relief Cord Grips](#)
Description: MAX-LOC® Strain Relief Cord-Sealing Grip, 1" NPT, 90° Angle Male, Cable Diameter 19.05-22.23mm (.750-.875"), Stainless Steel Mesh

Documents:

[Drawing \(PDF\)](#) [Product Literature \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR32159

General

Product Family	Cable Grips
Series	130099
Eye Type	N/A
NEMA Rating	NEMA 3R
O-Ring	No
Overview	Strain-Relief Cord Grips
Product Literature Order No	987650-8064
Product Name	MAX-LOC®
Type	Strain Relief Grip
UPC	78678855574
Use With	MAX-LOC® Lock Nut 1" NPT 130099-0145 , MAX-LOC® Gasket Sealing Ring 1" NPT 130099-0151 , MAX-LOC® O-Ring, 1" NPT 130180-0334
Woodhead	Yes

Physical

Approximate Break Strength	N/A
Bale Length	N/A
Body Style	90° Angle
Cable Diameter	19.05-22.23mm (.750-.875")
Color - Grommet	N/A
Gender	Male
Material - Body	Nylon
Material - Grip	Stainless Steel
Mesh Length	N/A
Number of Holes	1
Thread Size	1" NPT

Material Info

Old Part Number 5557M

Reference - Drawing Numbers

Sales Drawing SD-130099-004

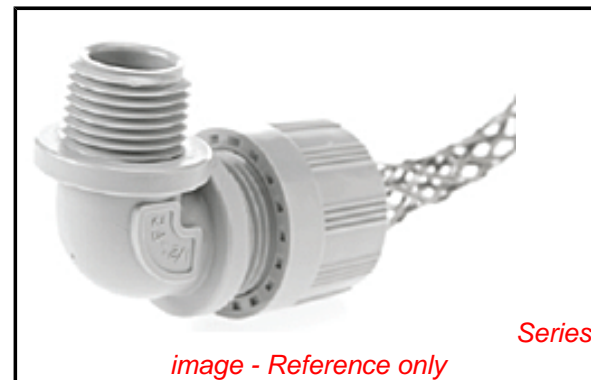


image - Reference only

EU RoHS

**ELV and RoHS
Compliant**

**REACH SVHC
Not Reviewed**

**Low-Halogen Status
Not Reviewed**

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

[130099Series](#)