

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [130008-0073](#)
Status: **Active**
Overview: Brad® Mini-Change® Connectors
Description: Mini-Change® B-Size Single-Ended Cordset, 10 Poles, Female (Straight) to Pigtail, 22 AWG, PVC Cable, 5.0m (16.40') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837

General

Product Family	Industrial Cordsets
Series	130008
Connector End A	Mini-Change®
Connector End B	Pigtail
IP Rating	IP67
Overview	Brad® Mini-Change® Connectors
Product Name	Mini-Change®
Protocol	N/A
Region	America
Type	Single Ended
UPC	78678844522

Physical

Cable Diameter	6.10mm (.240")
Cable Length	5.0m (16.40')
Color - Cable Jacket	Yellow
Coupling Style	Push to Lock
Gender	Female-Pigtail
Keyway	Single
LED Indicator	No
Material - Cable Jacket	PVC
Material - Connector Body	PVC
Material - Contact	Brass
Material - Coupling Nut	Black Epoxy Coated Zinc
Material - Plating Mating	Gold
Orientation	Straight
Poles	10
Temperature Range - Operating	-20°C to +75°C
Wire Size AWG	22
Wire/Cable Type	STOOW

Electrical


Current - Maximum per Contact	2.5A
Voltage - Maximum	600V

Material Info

Old Part Number	301000A04M050
-----------------	---------------

Reference - Drawing Numbers

Sales Drawing	SD-130008-019
---------------	---------------

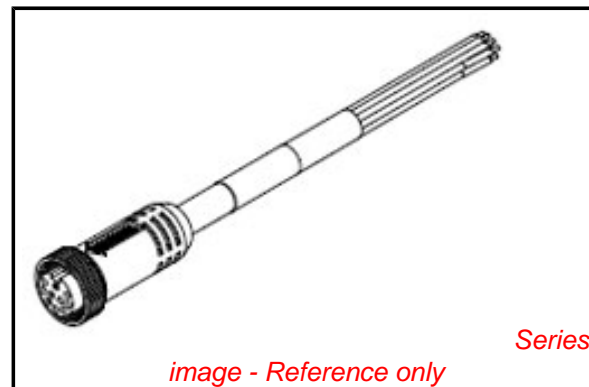

EU RoHS

**ELV and RoHS
Compliant**
**REACH SVHC
Not Reviewed**
**Low-Halogen Status
Not Reviewed**

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of
 Compliance, [click here](#)

Please visit the [Contact Us](#) section for any
 non-product compliance questions.

Search Parts in this Series

130008Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION