

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300940444](#)
Status: **Active**
Overview: [Support Grips](#)
Description: Heavy Duty Support Grip, Double Eye, Double Weave, Closed Mesh, Cable Diameter 31.75-37.85mm (1.250-1.490"), Approximate Break Strength 2140.96kg (4720 lbs)

Documents:

[RoHS Certificate of Compliance \(PDF\)](#) [Product Literature \(PDF\)](#)

Agency Certification


CSA LR32159

General

Product Family	Cable Grips
Series	130094
Eye Type	Double
O-Ring	N/A
Overview	Support Grips
Product Literature Order No	987650-8065
Product Name	Heavy Duty
Type	Support Grip
UPC	78678835427
Woodhead	Yes
Physical	
Approximate Break Strength	2140.96kg (4720 lbs)
Bale Length	0.254m (10.00")
Body Style	Straight
Cable Diameter	31.75-37.85mm (1.250-1.490")
Color - Grommet	N/A
Gender	N/A
Material - Body	N/A
Material - Grip	Non-magnetic Tin Bronze Wire
Mesh Length	0.787m (31.00")
Number of Holes	N/A
Thread Size	N/A

Material Info

Engineering Number 35427

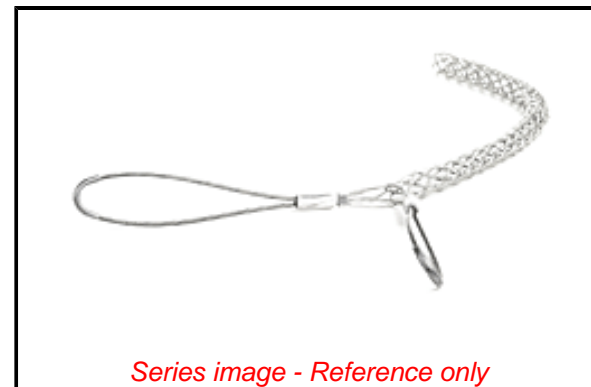

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

[130094 Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION