

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1300068139](#)  
**Status:** **Active**  
**Overview:** Brad® Mini-Change® Connectors  
**Description:** Mini-Change® Single-Ended Cordset, 5 Poles, Male (Straight) to Pigtail, 16 AWG, PUR Cable, 5.0m (16.40') Length

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Industrial Cordsets
Series	<a href="#">130006</a>
Connector End A	Mini-Change®
Connector End B	Pigtail
IP Rating	IP67
Material - Contact	Copper Alloy
Overview	<a href="#">Brad® Mini-Change® Connectors</a>
Product Name	Mini-Change®
Region	Europe
Type	Single Ended
UPC	887191260655

**Physical**

Cable Diameter	12.70mm (.500")
Cable Length	5.0m (16.40')
Color - Cable Jacket	Gray
Coupling Style	Threaded
Gender	Male-Pigtail
Keyway	Single
LED Indicator	No
Material - Cable Jacket	PUR
Material - Connector Body	PUR
Material - Coupling Nut	Black Epoxy Coated Zinc
Material - Plating Mating	Gold over Nickel
Orientation	Straight to Pigtail
Poles	5
Temperature Range - Operating	-20°C to +80°C
Wire Size AWG	16
Wire/Cable Type	UL 20233

**Electrical**


Current - Maximum per Contact	8.0A
Voltage - Maximum	300V AC/DC

**Material Info**

Engineering Number	105006B21M050
--------------------	---------------

**Reference - Drawing Numbers**

Sales Drawing	SD-130006-045
---------------	---------------

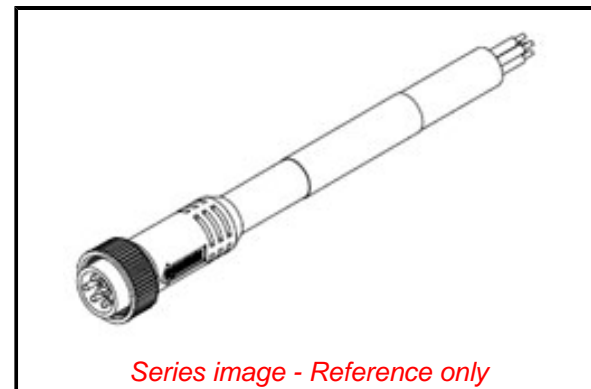

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

**Need more information on product environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

**Search Parts in this Series**

[130006](#) Series